


JTPQ00R (MS27497) — crimp wall mounting receptacle (back panel mounting)

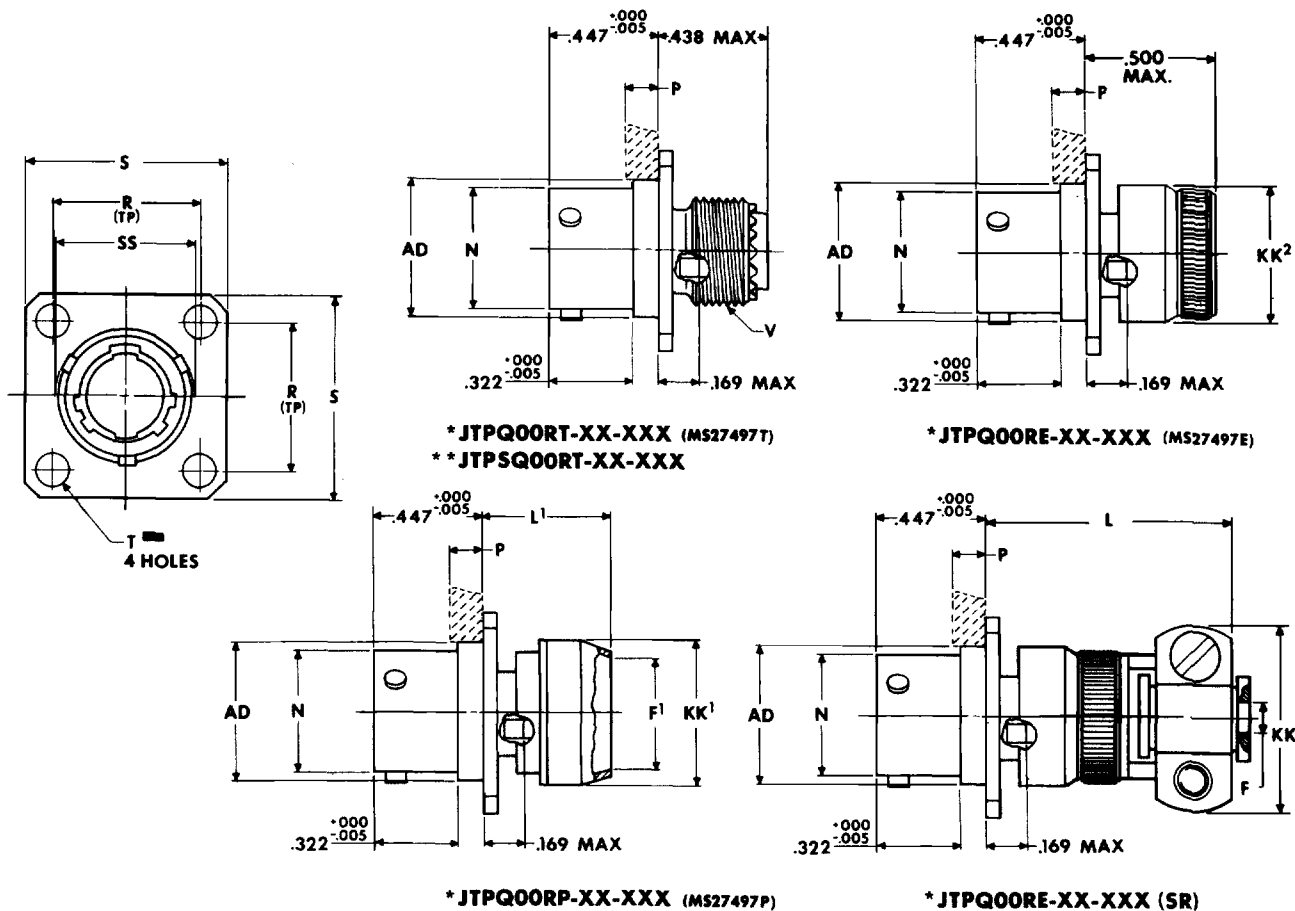

⌀ .005 DIA (M)

* To complete order number see page 47.

** High temperature version, to complete order number see page 47.

Shell Size	F Dia. $+.010$ $-.025$	F ¹ Dia. $+.010$ $-.010$	L Max.	L ¹ Max.	N Dia. $+.001$ $-.005$	P Max. Panel Thickness	R (TP)	S $±.016$	T Dia. $±.005$	V Thread UNEF Class 2A (Plated)	AD Dia. $±.005$	KK Max.	KK ¹ Dia. Max.	KK ² Dia. Max.	SS Dia. $+.000$ $-.016$
8	.125	.444	1.140	.468	.473	.142	.594	.812	.120	.4375-28	.516	.781	.625	.578	.563
10	.188	.558	1.140	.468	.590	.142	.719	.938	.120	.5625-24	.633	.844	.750	.703	.680
12	.312	.683	1.140	.468	.750	.142	.812	1.031	.120	.6875-24	.802	.969	.875	.828	.859
14	.375	.808	1.375	.468	.875	.142	.906	1.125	.120	.8125-20	.927	1.094	1.000	.953	.984
16	.500	.909	1.375	.468	1.000	.142	.969	1.219	.120	.9375-20	1.052	1.154	1.125	1.078	1.108
18	.625	1.034	1.375	.468	1.125	.142	1.062	1.312	.120	1.0625-18	1.177	1.406	1.250	1.203	1.233
20	.625	1.159	1.375	.468	1.250	.142	1.156	1.438	.120	1.1875-18	1.302	1.406	1.375	1.328	1.358
22	.750	1.284	1.516	.468	1.375	.142	1.250	1.562	.120	1.3125-18	1.427	1.594	1.500	1.453	1.483
24	.800	1.409	1.500	.540	1.500	.142	1.375	1.688	.147	1.4375-18	1.552	1.688	1.625	1.578	1.610

All dimensions for reference only.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Amphenol:

[MS27497T22A21SA](#) [MS27497T8A98PA](#) [MS27497T12A3S](#) [MS27497T10A35P](#) [MS27497T8A35PA](#)
[MS27497T16A8S](#) [MS27497T24A4S](#) [MS27497T24A4SA](#) [MS27497T14A5S](#) [MS27497T10A99P](#) [MS27497T14A35SB](#)
[MS27497T16A35PB](#) [MS27497T16A35PA](#) [MS27497T10A35SB](#) [MS27497T16A6P](#) [MS27497T10A35S](#)
[MS27497T10A35SA](#) [MS27497T10A99S](#) [MS27497T12A35P](#) [MS27497T12A35PA](#) [MS27497T12A35S](#)
[MS27497T12A4P](#) [MS27497T12A98P](#) [MS27497T14A18S](#) [MS27497T14A35P](#) [MS27497T14A35S](#)
[MS27497T14A35SA](#) [MS27497T16A26P](#) [MS27497T16A26S](#) [MS27497T16A26SA](#) [MS27497T16A35P](#)
[MS27497T16A35S](#) [MS27497T16A35SA](#) [MS27497T18A35P](#) [MS27497T18A35S](#) [MS27497T22A21S](#)
[MS27497T8A35P](#) [MS27497T8A35S](#) [MS27497T8A98P](#) [MS27497T14A5P](#) [MS27497T14A97S](#) [MS27497T10A35PB](#)
[MS27497T10A99SA](#) [MS27497T12A35SA](#) [MS27497T12A3P](#) [MS27497T12A8S](#) [MS27497T14A18SA](#)
[MS27497T18A35SA](#) [MS27497T24A29SA](#) [MS27497T14A35SD](#) [MS27497T8A98S](#) [MS27497T20A35SA](#)
[MS27497T16A8SA](#) [MS27497T10A35PA](#) [MS27497T12A98S](#) [MS27497T24A29S](#) [MS27497T22A35P](#)
[MS27497T14A35SC](#) [MS27497T22A21P](#) [MS27497T14A18P](#) [MS27497T14A97P](#) [MS27497T18A32PA](#)
[MS27497T22A55SA](#) [MS27497T18A32S](#) [MS27497T16A99P](#) [MS27497T22A35SA](#) [MS27497T22A55S](#)
[MS27497T10A5P](#) [MS27497T16A35SC](#) [MS27497T22A35S](#) [MS27497T12A8P](#) [MS27497T18A32P](#) [MS27497T10A98P](#)
[MS27497T18A28P](#) [MS27497T18A32SA](#) [MS27497T14A15P](#) [MS27497T18A11P](#) [MS27497T22A55P](#)
[MS27497T18A35PA](#) [MS27497T12A98PB](#) [MS27497T10A99SC](#) [MS27497T12A35PB](#) [MS27497T20A41SC](#)
[MS27497T12A35PC](#) [MS27497T10A35SD](#) [MS27497T24A35SA](#) [MS27497T20A35S](#) [MS27497T14A35PA](#)
[MS27497T12A8PC](#) [MS27497T8A98PD](#) [MS27497T18A35SB](#) [MS27497T16A99PB](#) [MS27497T22A35PA](#)
[MS27497T8A35SD](#) [MS27497T12A35SB](#) [MS27497T8A35PD](#) [MS27497T24A29P](#) [MS27497T20A41P](#)
[MS27497T12A4S](#) [MS27497T10A35SC](#)