 
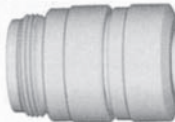
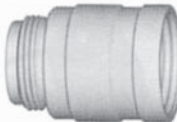


ECTA 133 Metal Circular Push-Pull IP67 Connector System Accessories

Backshell IP67				IP67 Backshell				
	Part Number	Shell	Cable Ø (mm)		Part Number	Shell	Cable Ø (mm)	
	1330 0 P2	0	4.5~6		1330 1 P3	1	9~12.5	
	1330 1 P1	1	5~6.5		1330 2 P3	2	11.5~14.5	
	1330 1 P2	1	6.5~9		1330 3 P2	3	12.5~15	
	1330 2 P1	2	8~10		1330 3 P3	3	15~18	
	1330 2 P2	2	10~13.5		1330 4 P1	4	15~18	
	1330 3 P1	3	10.5~12.5		1330 4 P2	4	18~21	
Backshell IP67 with Braid Clamping and Cable Clamp				Backshell IP67 with Braid Clamping				
	Part Number	Shell	Cable Ø (mm)		Part Number	Shell	Cable Ø (mm)	
	1330 1 PES 1	1	5.5~9		1330 0 PEM	0	2.5~5	
	1330 1 PES 2	1	9~12		1330 1 PEM	1	8~13	
	1330 2 PES 1	2	5.5~9		1330 2 PEM	2	8~13	
	1330 2 PES 2	2	9~12		1330 3 PEM	3	13~18	
	1330 3 PES 1	3	10~18		1330 4 PEM	4	13~ 18	
	1330 4 PES 1	4	10~ 18					
Adapter with Metric Thread				Backshell IP30 with Cable Clamp				
 The PM Adapter is designed for use on any standard backshell with metric thread (to IP67)	Part Number	Shell	Thread		Part Number	Shell	Cable Ø (mm)	
	1330 0 PM 12	0	M12 x 1,5		1330 1 DS 1	1	2~6	
	1330 1 PM 16	1	M16 x 1,5		1330 1 DS 2	1	7~10	
	1330 1 PM 20	1	M20 x 1,5		1330 1 DS 3	1	10~13	
	1330 2 PM 16	2	M16 x 1,5		1330 2 DS 2	2	10.5~14	
	1330 2 PM 20	2	M20 x 1,5		1330 2 DS 3	2	14~17.5	
	1330 3 PM 20	3	M20 x 1,5		1330 3 DS 1	3	12.5~14.5	
	1330 3 PM 25	3	M25 x 1,5		1330 3 DS 2	3	14.5~18	
	1330 4 PM 20	4	M20 x 1,5		1330 4 DS 0	4	11.75~15.5	
	1330 4 PM 25	4	M25 x 1,5		1330 4 DS 1	4	15.5~18	
	1330 5 PM 25	5	M25 x 1,5		1330 4 DS 2	4	18~ 21.5	
	1330 6 PM 32	6	M32 x 1,5		Also available: 90°Adapter for plug and cable-cable plug extension			
	1330 7 PM 50	7	M50 x 1,5					
Metal Cap for All Receptacles (IP67)			Metal Cap for Plug (IP67)			Flange Seal		
	Part Number	Shell		Part Number	Shell		Part Number	Shell
	1330 0 BE	0		1330 0 BM	0		1330 0 JE	0
	1330 1 BE	1		1330 1 BM	1		1330 1 JE	1
	1330 2 BE	2		1330 2 BM	2		1330 2 JE	2
	1330 3 BE	3		1330 3 BM	3		1330 3 JE	3
	1330 4 BE	4		1330 4 BM	4		1330 4 JE	4
	1330 5 BE	5		1330 5 BM	5		1330 5 JE	5
Also available upon request, a single hole fixing bulkhead with pressure differentials up to 5 bars. The technical characteristics are identical to those of standard connectors.						1330 6 JE	6	
						1330 7 JE	7	

Also available upon request, a single hole fixing bulkhead with pressure differentials up to 5 bars.
The technical characteristics are identical to those of standard connectors.

SOCAPEX™ SL61 19 Contact Lighting Connectors

Amphenol's SOCAPEX connector is accepted as a worldwide standard in the Lighting Industry

Materials

Body - Aluminium Alloy
Inserts - Alkyde
Contacts - Machined Gold Plated

Electrical

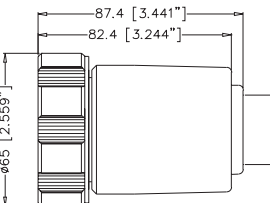
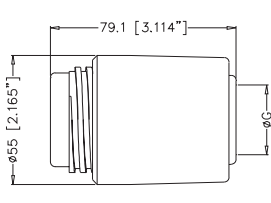
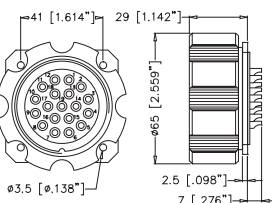
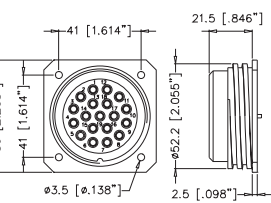
Working Voltage - 400V
Current - 25A

Configuration

Number of Contacts - 19
Coupling Nut - Threaded
Backshell - Two Piece
Cable Clamp - Adaptable
Termination - Solder
Temperature Range - -40°C ~ 85°C

Also Available

- Right Angle Versions
- Various Shell Sizes and Contacts
- Cap Accessories
- Crimp Versions
- Earth Protection
- Cadmium-Free Versions

Part Number	SLFMD419AR	SLFFDR419AR	SLEME419AR	SLEF419AR
Description	Cable Pin Plug	In-Line Socket Receptacle	Panel Pin Plug	Panel Socket Receptacle
Representation				
Diagram				

AIRLB/ASF-T

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Amphenol:](#)

[13303P2](#) [13300PM12](#) [13300PEM](#)