
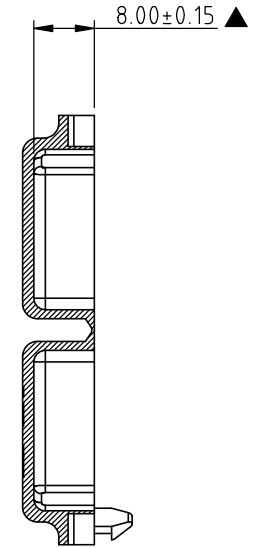
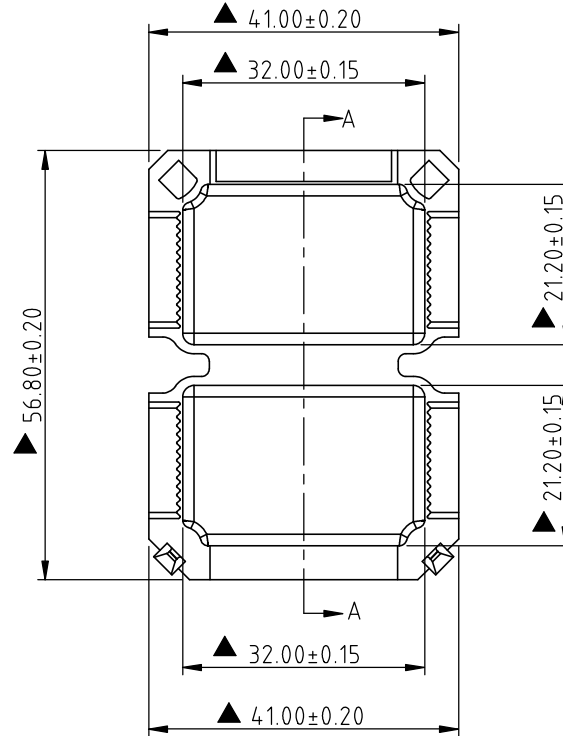
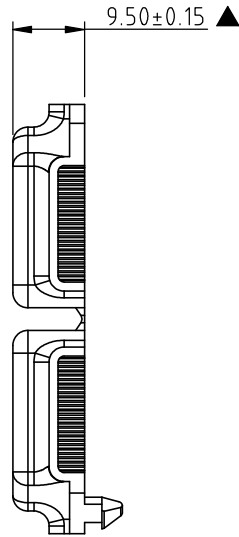


RoHS Compliant

REV	SIGN	DATE	DESCRIPTION	APPROVER
A0		2021.01.07	Initial Release	LENA
THIS IS CAD DRAWING, DO NOT REVISE MANUALLY!!!				

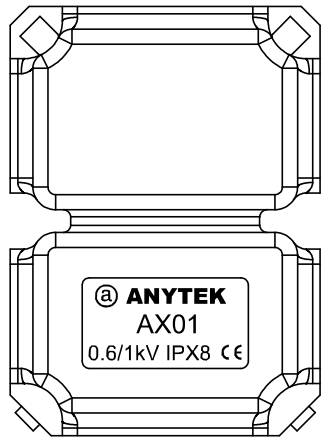

Section A-A

Part No. AX0100x00000G

Small Size

Color:

- 0 Black (RAL9005)
- 2 Red (RAL3001/D)
- 3 Orange(RAL2011/P)
- 4 Yellow(RAL1018/A)
- 5 Green(RAL6018/T)
- 6 Blue (RAL5015/A)
- 8 Grey(RAL7004)
- 9 White(RAL1102)
- C Multiple Colors

RoHS compliant
(lead<4%)
In copper Alloy

Notes:
1.Rated Voltage : IEC 50393 0.6/1kV
2.Operation Temperature : -40℃~+50℃.

Amphenol
ANYTEK

CUSTOMER COPY

ALL RIGHTS RESERVED. REPRODUCTION OR ISSUE TO THIRD PARTIES IN ANY FORM WHATEVER IS NOT PERMITTED WITHOUT WRITTEN AUTHORITY FROM THE PROPRIETOR. PROPERTY OF ANYTEK TECHNOLOGY CO., LTD

TITLE	AX01 Series ,waterproof box,small size						
PART NO.	AX0100x00000G			DWG NO.	8AX0001		
APPROVED	CHECKED	DESIGNED	DRAWN	CUST NO.	Tolerance		
		LENA 2021.01.07	LENA 2021.01.07		UNIT: mm	X.	±0.50
					SCALE: 1:1	X.X	±0.30
					REV.: A0	X.XX	±0.10
				SHEET: 01/01		X°	±1°

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Amphenol:](#)

[AX0100300000G](#)