




BECN TV XX XX

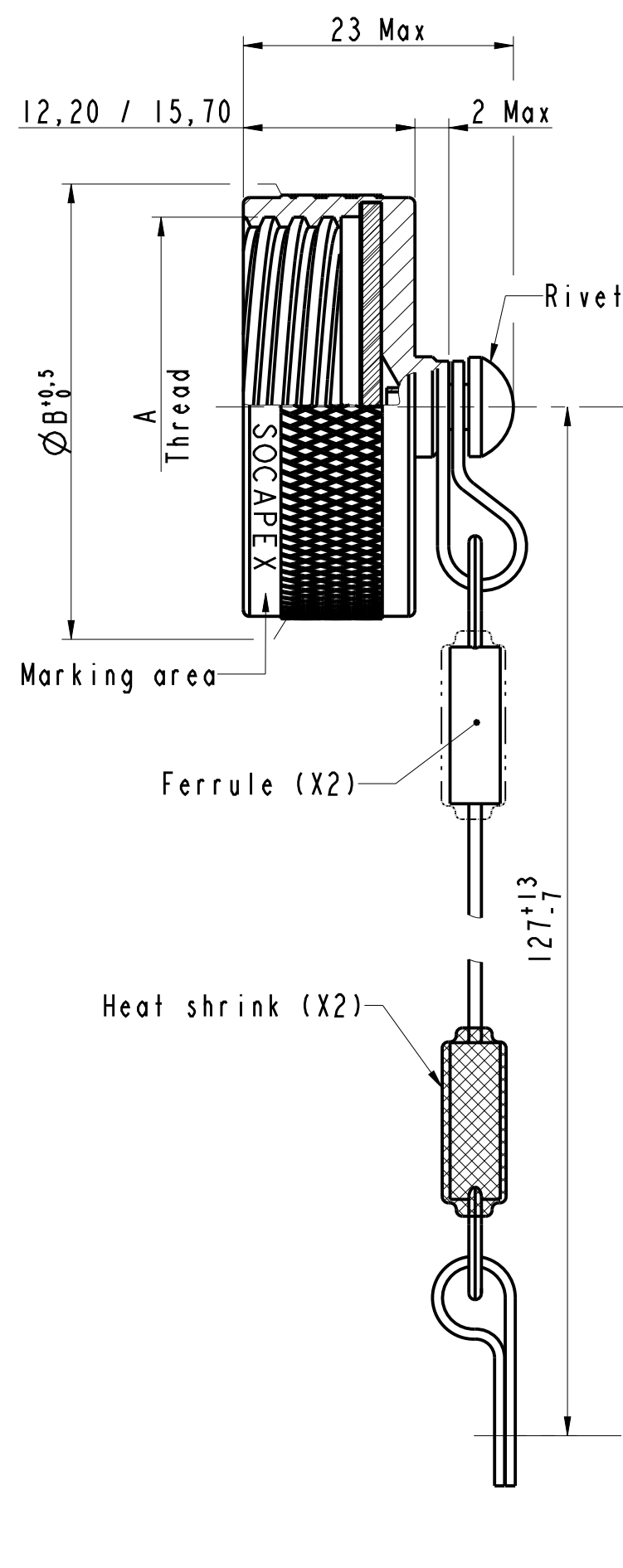

BERN TV XX XX

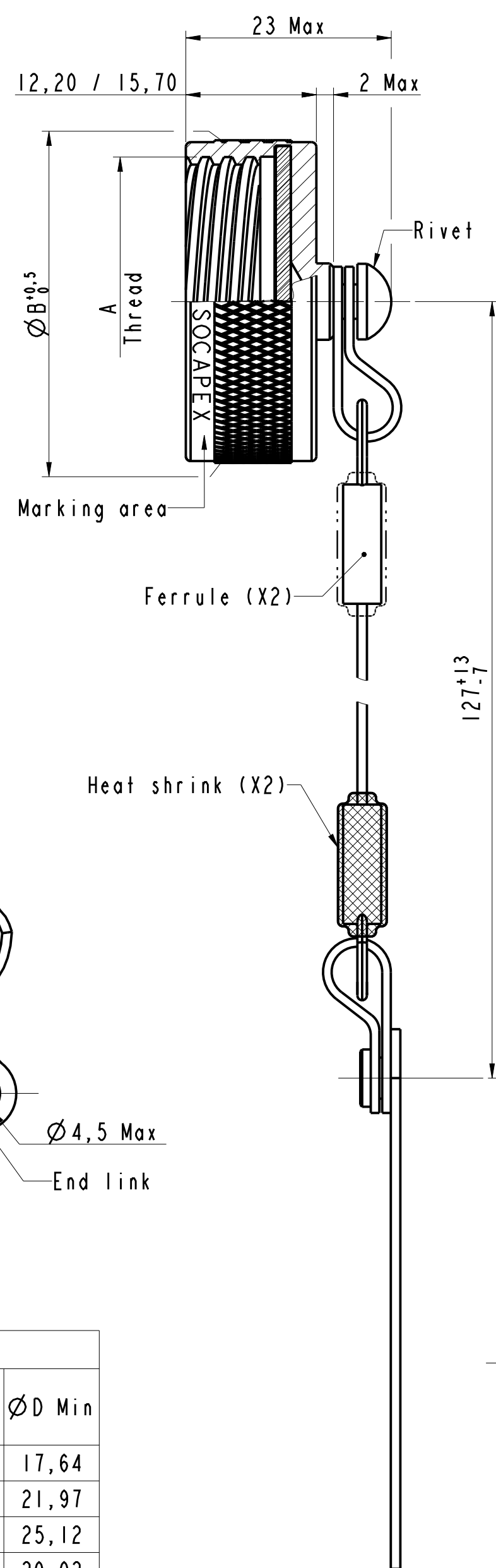

BFN TV XX XX

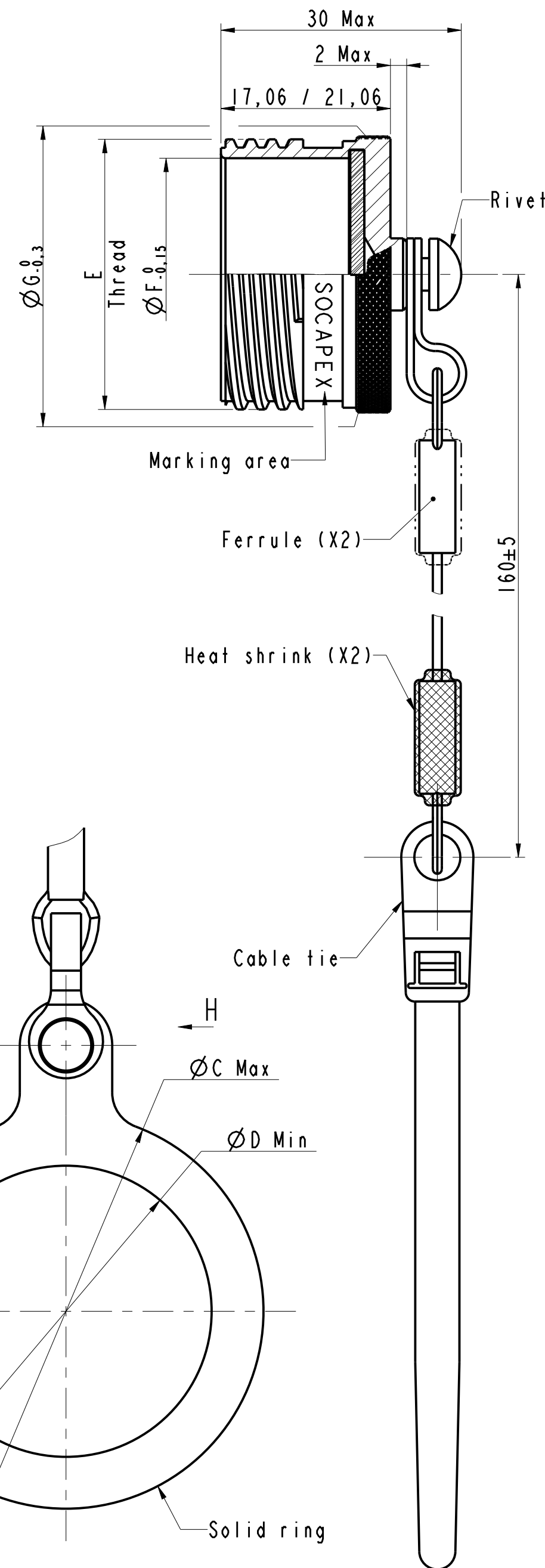

BFN TV XX XX			
Size	E Thread	$\varnothing G_{-0,3}^0$ After Knurling	$\varnothing F_{-0,15}^0$
9	0.625-2A-0.1P-0.3L-TS	17,20	12,50
11	0.750-2A-0.1P-0.3L-TS	20,50	15,75
13	0.875-2A-0.1P-0.3L-TS	24,30	19,53
15	1.000-2A-0.1P-0.3L-TS	27,40	22,71
17	1.1875-2A-0.1P-0.3L-TS	30,60	25,88
19	1.250-2A-0.1P-0.3L-TS	33,25	28,55
21	1.375-2A-0.1P-0.3L-TS	36,40	31,72
23	1.500-2A-0.1P-0.3L-TS	39,70	34,90
25	1.625-2A-0.1P-0.3L-TS	42,80	38,07

BECN/BERN TV XX XX				
Size	A Thread	$\varnothing B_{+0,5}^0$ After Knurling	$\varnothing C$ Max	$\varnothing D$ Min
9	0.625-2B-0.1P-0.3L-TS	19,40	27,0	17,64
11	0.750-2B-0.1P-0.3L-TS	22,60	32,0	21,97
13	0.875-2B-0.1P-0.3L-TS	25,75	37,0	25,12
15	1.000-2B-0.1P-0.3L-TS	28,90	40,0	29,92
17	1.1875-2B-0.1P-0.3L-TS	33,80	44,0	32,00
19	1.250-2B-0.1P-0.3L-TS	35,40	46,0	36,27
21	1.375-2B-0.1P-0.3L-TS	38,60	49,0	38,25
23	1.500-2B-0.1P-0.3L-TS	41,70	54,0	42,62
25	1.625-2B-0.1P-0.3L-TS	44,90	56,0	44,45

Note:

1. All attachments (Ferrule, Rivet, End links & Solid ring) are stainless steel passivated.

Commercial designation:

BXXN TV XX XX

Connector shell size:
(09/11/13/15/17/19/21/23/25)Finish:
F: Nickel
W: Olive drab cadmium
B: Marine bronze
Z: Green zinc cobalt
ZN: Black zinc nickelConnector type
MIL-DTL-38999 series III connectorAttachment type:
N: Nylon ropeProtective cap type:
EC: For square flange receptacle
ER: For jam nut receptacle
F: For plug

DRAWN BY : B Mane		UPDATED BY: A Mali		LAST APPROVED BY: R Reddy	
ALL DIMENSIONS ARE IN MM	AMPHENOL SOCAPEX			ORIGINAL DRAWING DATE : 03/03/11	CONFIGURATION DATA ARE AVAILABLE IN PDM
				REV : E	PAGE : 1/1
SCALE : 2	B.P. 29 74311 THYEZ CEDEX			173-PLC-978-00	

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Amphenol:](#)

[BERNTVB13](#) [BERNTVB25](#)