


Hybrid Connectors

Coax Cable Connectors

Right-Angle Solder-to-Board and
Straight Mini Coax Housings

Crimp-to-Wire
Mini Coax Assembly

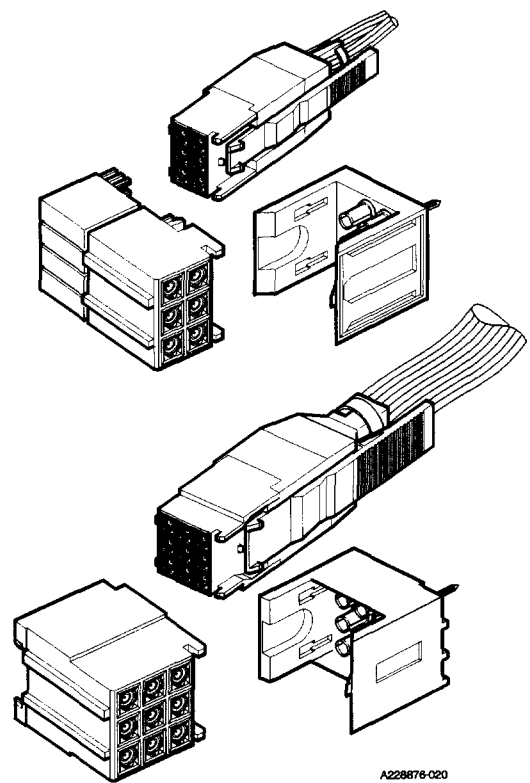

A228876-020


Features


- Modular design guarantees flexibility.
- Stackable end-to-end without loss of positions.
- Stackable with other METRAL™ function modules (e.g., signal, power).
- Polarization.
- Stable high-strength PCB attachment.
- Termination without soldering.
- High signal density:
 - ▶ 6-position: 50 contacts/100 mm board length.
 - ▶ 9-position: 75 contacts/100 mm board length.

Mating Data

Berg Electronics	Page
▪ 6-position Mini Coax Application Guide	10-53
▪ 9-position Mini Coax Application Guide	10-55

Approvals and Certifications

 File no. E66906

 File no. LR46923

Application Equipment

Berg Electronics Products	Page
▪ MT-120 single riveting hand tool	10-82
▪ MT-130 multiple riveting machine	10-83
▪ MT-310 Press-fit insertion press	10-88
▪ MT-320 Press-fit semi-automatic air press	10-89
▪ Press-fit straight header tooling sets	10-90
▪ MT-510 insertion bench press ..	10-96
▪ MT-511 insertion air press	10-97
▪ Press-fit right-angle tooling sets	10-98

Technical Data

Materials

- Straight and Right-Angle Housings Glass filled LCP (UL 94-VO)
 - ▶ Color Natural
 - ▶ Applicable soldering processes..... Wave, IR, vapor phase
- Cable housing..... Glass filled thermoplastic polyester (UL 94-VO)
 - ▶ Color Natural
- Cable cover..... Glass filled thermoplastic polyester (UL 94-VO)
 - ▶ Color Black
- Cable latch..... Polyetherimide (UL 94 V-O)
 - ▶ Color Black

Environmental Properties

- Temperature range..... -55°C to + 105°C

Electrical Performance

- Insulation resistance..... $5 \times 10^3 \text{ M}\Omega$ min initially; $1 \times 10^3 \text{ M}\Omega$ after environmental testing
- Withstanding voltage..... 1000 V rms (sea level)


Packaging (Order in multiples of quantity shown)

- Bags..... 100


Customer Support Materials

Description	Order No.	Description	Order No.
Customer Product Drawings.....	By Part No.	Product Samples.....	Upon Request

6-Position Mini Coax Applications

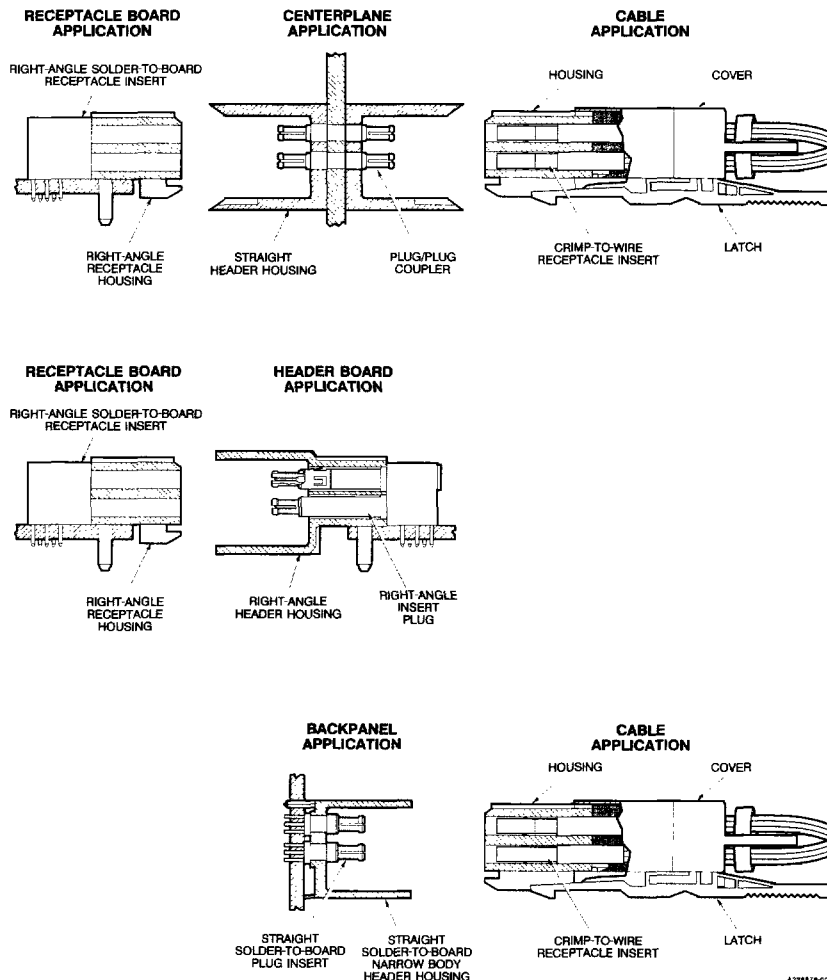


9-Position Mini Coax Applications

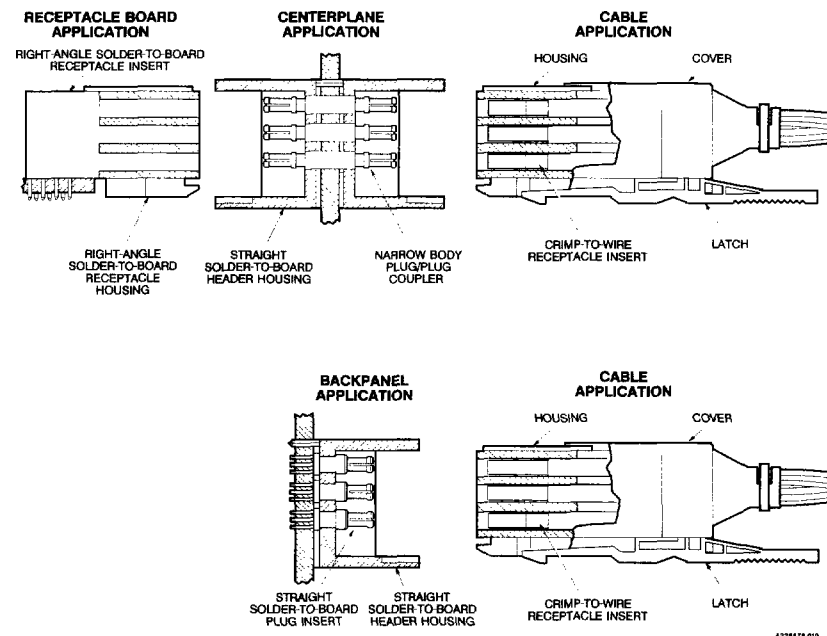

Description and Ordering Data

Wide Body Centerplane Application
6-Position Straight Wide Body Housing
Part Number 88913-101

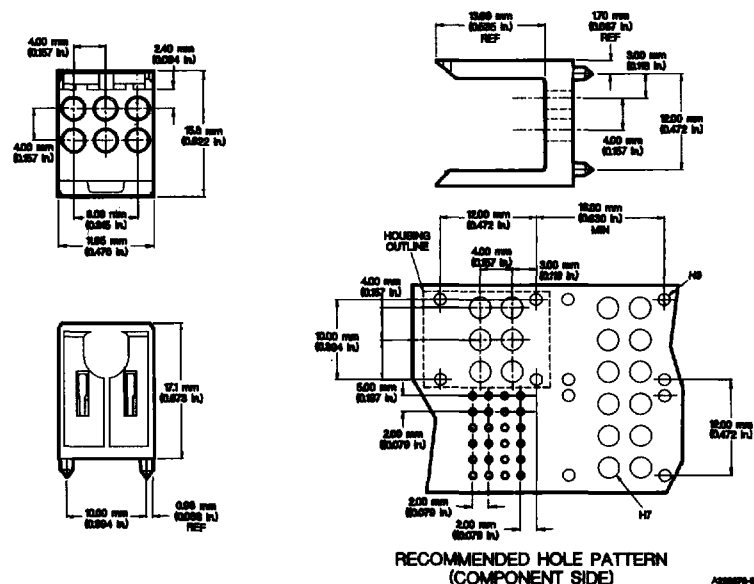

For "H" hole specifications, see page 10-99.

Ordering data shown is for our standard product offering. For non-standard or custom products, contact your authorized Berg Electronics representative.


Description and Ordering Data

Narrow Body Centerplane and Backplane Applications

6-Position Straight Narrow Body Housing

Part Number 70243-101 (Solder-to-Board)


Part Number 70243-111 (Press-Fit)

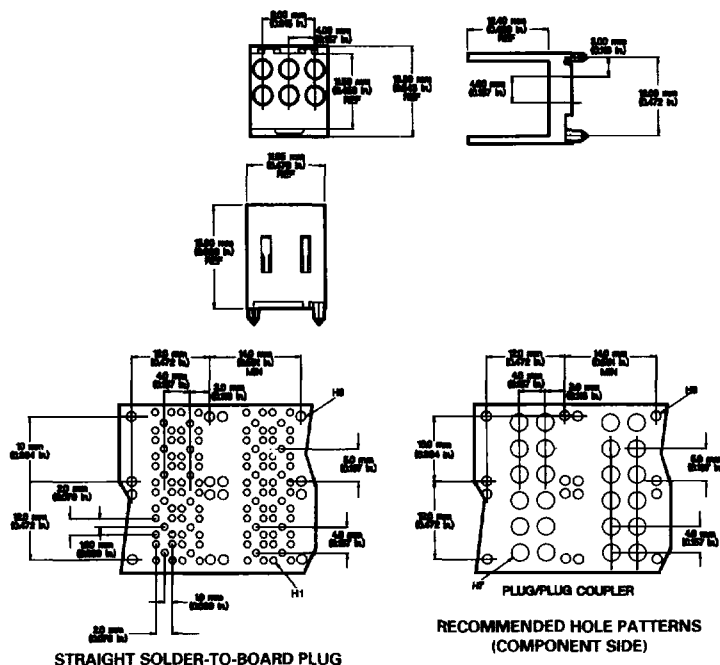

For "H" hole specifications, see page 10-99.

Ordering data shown is for our standard product offering. For non-standard or custom products, contact your authorized Berg Electronics representative.

Description and Ordering Data Centerplane and Backpanel Applications 9-Position Straight Solder-to-Board Narrow Body Housing Part Number 88973-101

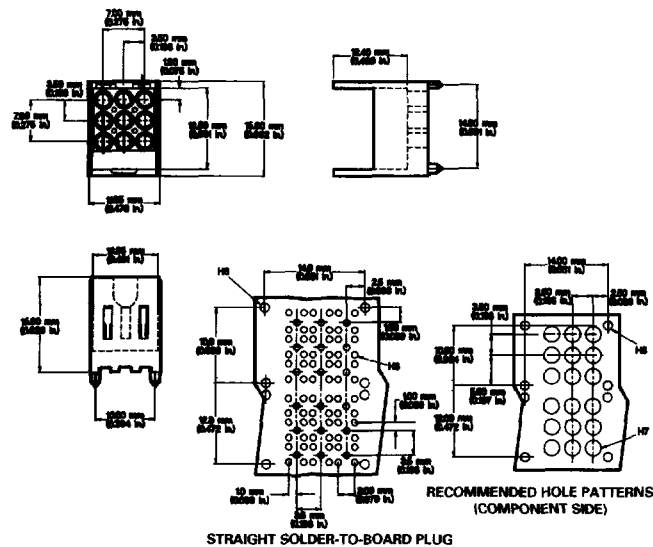


STRAIGHT SOLDER-TO-BOARD PLUG

For "H" hole specifications, see page 10-99.

Ordering data shown is for our standard product offering. For non-standard or custom products, contact your authorized Berg Electronics representative.

Description and Ordering Data Header Board Application 6-Position Right-Angle Header Housing Part Number 88982-101 (Heat Stake Peg) Part Number 88982-102 (Press Peg)

Heat Stake Version Shown

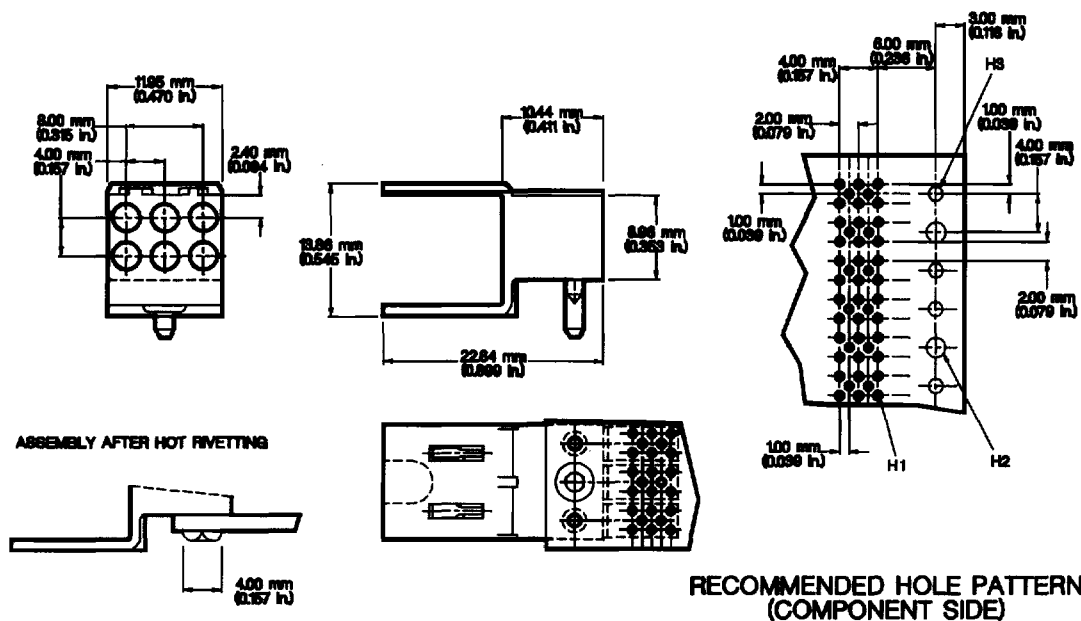

RECOMMENDED HOLE PATTERN
(COMPONENT SIDE)

A228670-044

For "H" hole specifications, see page 10-99.

Ordering data shown is for our standard product offering. For non-standard or custom products, contact your authorized Berg Electronics representative.

Description and Ordering Data


Receptacle Board Application

6-Position Right-Angle Receptacle Housing

Part Number 70244-101 (Heat Stake Peg)

Part Number 70244-102 (Press Peg)

Heat Stake Version Shown

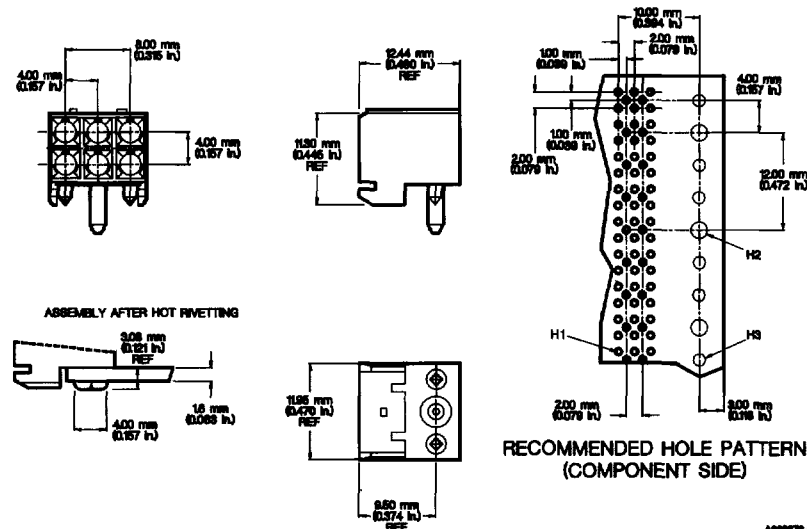

For "H" hole specifications, see page 10-99.


Ordering data shown is for our standard product offering. For non-standard or custom products, contact your authorized Berg Electronics representative.

Description and Ordering Data

Receptacle Board Application



9-Position Right-Angle Solder-to-Board Receptacle Housing

Part Number 88974-101

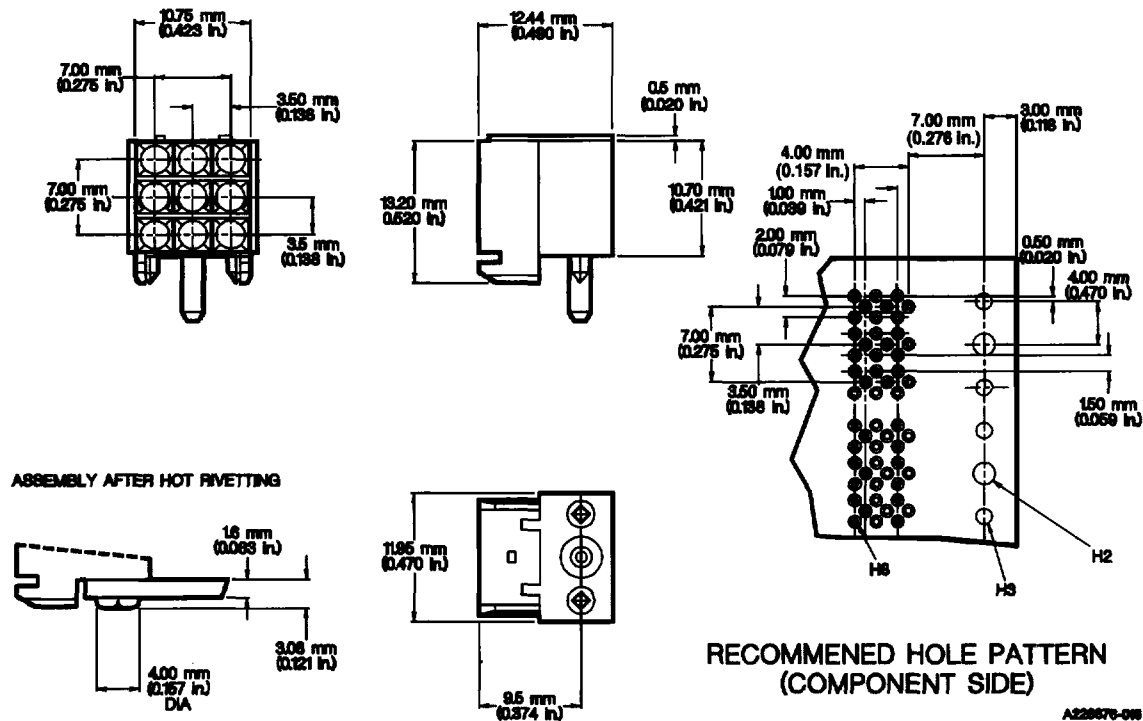

For "H" hole specifications, see page 10-99.

Ordering data shown is for our standard product offering. For non-standard or custom products, contact your authorized Berg Electronics representative.

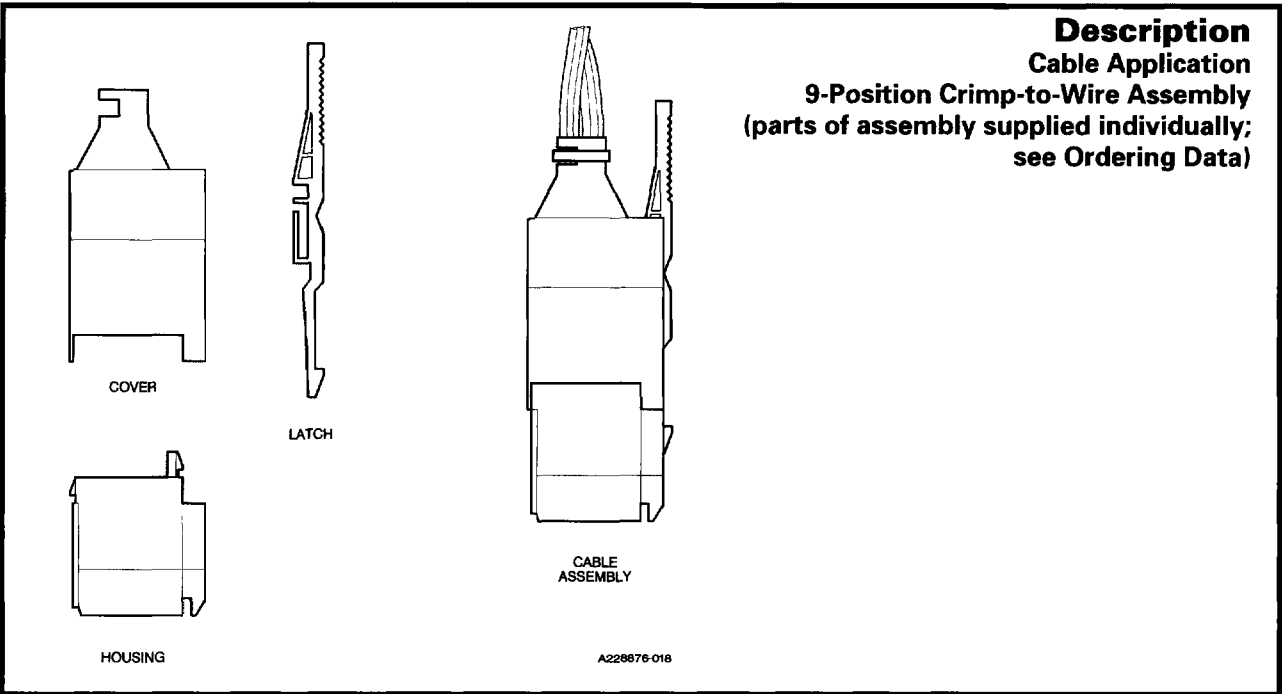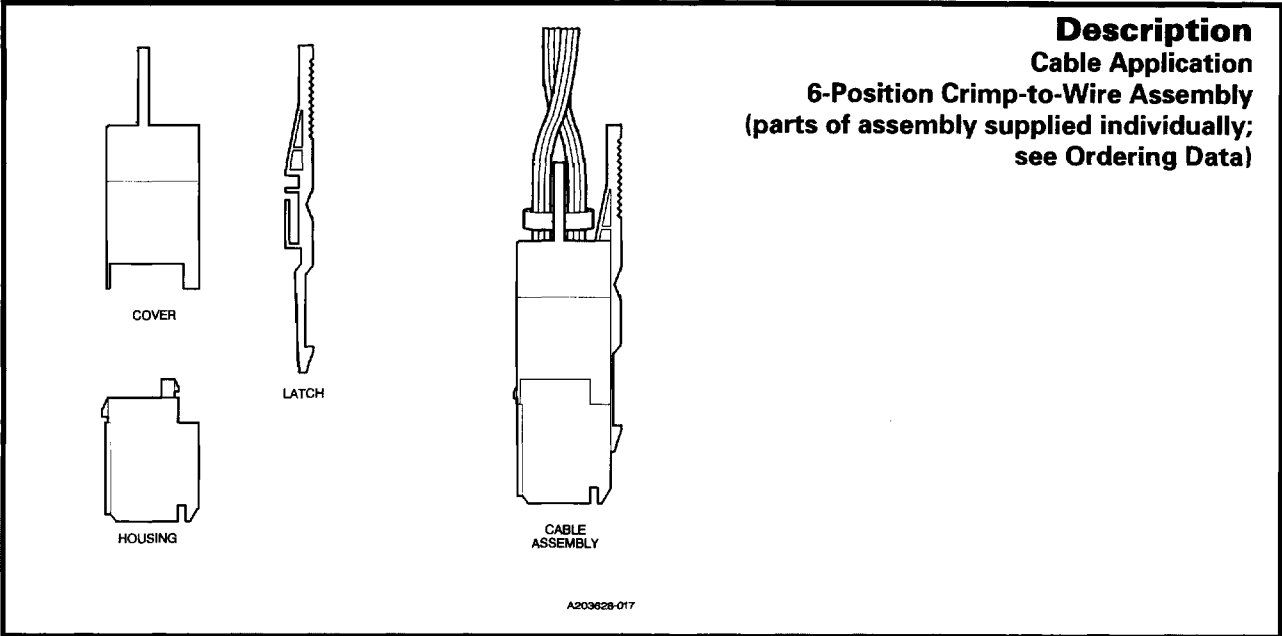

10

Ordering Data Cable Application 6- and 9-Position Crimp-to-Wire Assembly (parts of assembly supplied individually)	
6-position Parts of Assembly (order 1 of each)	Part Number
Housing	70245-101
Cover	70246-001
Latch	70289-001
9-position Parts of Assembly (order 1 of each)	Part Number
Housing	88975-101
Cover	88976-001
Latch	70289-001
Ordering data shown is for our standard product offering. For non-standard or custom products, contact your authorized Berg Electronics representative.	

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[FCI / Amphenol:](#)

[70243-101](#)