

VALVE CONNECTORS DT-SERIES

Nomenclature

DT06 - 2 S L - A / K1 / 0.75 / 2m

Type

DT06 = Housing for socket contacts
DT04 = Housing for plug contacts

No of pos.

2 = 2-pos.
3 = 3-pos.
4 = 4-pos.
6 = 6-pos.
8 = 8-pos. A-coding
12 = 12-pos. A-coding

Type

S = Socket contacts/Plug housing
P = Plug contacts/Receptacle housing

Cable style

= Cable
L = Single wire (only 2-pos. version)

Termination protection tube

= Standard
G = Thread M12x1

Protection circuit

A = without protection circuit
B = with protection circuit Suppressor diode max. 12 V AC/24 V DC
E = with protection circuit Varistor max. 24 V AC/30 V DC
F = with protection circuit Freewheeling diode max. 32 V DC
G = with protection circuit Suppressor diode max. 22 V AC/32 V DC

Material cable

K1 = TPU, black, highflexible, halogenfree, UL
A1 = PVC single wire

Wire cross section

0.75 = 0.75 mm²
other types upon request

Cable length

2m = 2 meter
5m = 5 meter
10m = 10 meter

VALVE CONNECTORS DT-SERIES

Product specification

 



Basic material	
Contact	Copper alloy
Contact plating	Ni
Contact carrier	Thermoplast
Overmould	TPU, UL94, translucent
Sealing	Silicone
Technical Data	
Rated voltage	with LED and protection circuit [B]: max. 12 V AC/ 24 V DC with LED and protection circuit [E]: max. 24 V AC/30 V DC with LED and protection circuit [F]: max. 32 V DC with LED and protection circuit [G]: max. 22 V AC/32 V DC without protection circuit: 10 - 230 AC/DC
Current rating	max. 8 A at 40 °C [2-, 3-pos.] 7 A at 40 °C [4-pos.] 6 A at 40 °C [6-, 8-pos.] 5 A at 40 °C [12-pos.]
Degree of protection	IP67 / IP69K in mated condition
Temperature range connectors	-40 °C to +85 °C
Temperature range cable	Fixed installation: -40 °C to +80 °C Flexible installation: -25 °C to +80 °C
Temperature range single wire	Fixed installation: -40 °C to +105 °C Flexible installation: -10 °C to +105 °C
Terminal cross section	0.75 mm ² /AWG 18
Housing	Deutsch DT06/DT04
Protection circuit	Suppressor diode + 2x LED yellow Varistor + 2x LED yellow Freewheeling diode + LED yellow

VALVE CONNECTORS DT-Series

DT06, 2-pos. Socket contacts

LED-protection circuit

Contact assignment

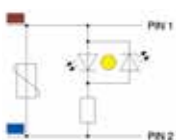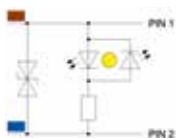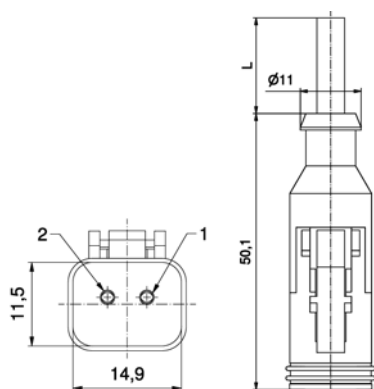





No. of poles	Type of protection circuit	Rated voltage [A]	Current rating [A]	Cable length = L [m]	Cable quality	Wire cross section [mm ²]	Description	Part No.
2	B	12 V AC / 24 V DC	8	2	PUR 2 x 0,75		DT06-2S-B/K1/0.75/2m	55-00376
				5			DT06-2S-B/K1/0.75/5m	55-00377
				10			DT06-2S-B/K1/0.75/10m	55-00378
	G	8 - 22 V AC / 32 V DC		2			DT06-2S-G/K1/0.75/2m	55-00760
				5			DT06-2S-G/K1/0.75/5m	55-00761
				10			DT06-2S-G/K1/0.75/10m	55-00762
	E	8 - 24 V AC / 30 V DC	4	2			DT06-2S-E/K1/0.75/2m	55-00687
				5			DT06-2S-E/K1/0.75/5m	55-00688
				10			DT06-2S-E/K1/0.75/10m	55-00689
	F	10 - 32 V DC		2			DT06-2S-F/K1/0.75/2m	55-00690
				5			DT06-2S-F/K1/0.75/5m	55-00691
				10			DT06-2S-F/K1/0.75/10m	55-00692

Types of protection circuit DT06 (2-, 3-pos.):

- B/G= Suppressordiode + 2x LED yellow
- E= Varistor + 2x LED yellow
- F= Freewheeling Diode + LED yellow

Technical information look at page 56 + 57

LED-protection circuit, M12 thread

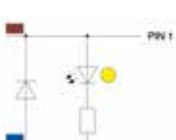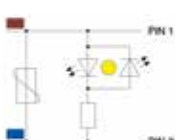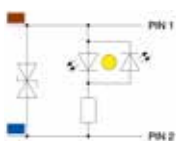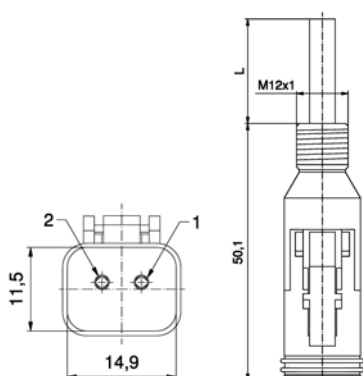


2	B	12 V AC / 24 V DC	8	2	PUR 2 x 0,75		DT06-2SG-B/K1/0.75/2m	55-00379
				5			DT06-2SG-B/K1/0.75/5m	55-00380
				10			DT06-2SG-B/K1/0.75/10m	55-00381
	G	8 - 22 V AC / 32 V DC		2			DT06-2SG-G/K1/0.75/2m	55-00763
				5			DT06-2SG-G/K1/0.75/5m	55-00764
				10			DT06-2SG-G/K1/0.75/10m	55-00765
	E	8 - 24 V AC / 30 V DC	4	2			DT06-2SG-E/K1/0.75/2m	55-00700
				5			DT06-2SG-E/K1/0.75/5m	55-00701
				10			DT06-2SG-E/K1/0.75/10m	55-00702
	F	10 - 32 V DC		2			DT06-2SG-F/K1/0.75/2m	55-00703
				5			DT06-2SG-F/K1/0.75/5m	55-00704
				10			DT06-2SG-F/K1/0.75/10m	55-00705

VALVE CONNECTORS DT-Series


DT06, 2-pos.
Socket contacts

Without LED-protection circuit

Contact assignment

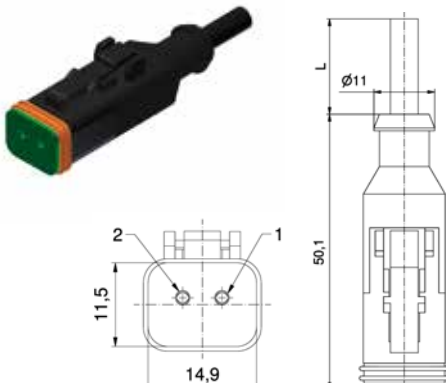		No. of poles	Rated voltage [A]	Current rating [A]	Cable length = L [m]	Cable quality	Wire cross section [mm²]	Description	Part No.
	PIN 1  PIN 2 	2	10 - 230 V AC/ DC	8	5	PUR	2 x 0,75	DT06-2S-A/K1/0.75/2m	55-00388
								DT06-2S-A/K1/0.75/5m	55-00389
								DT06-2S-A/K1/0.75/10m	55-00390

Without LED-protection circuit, M12 thread


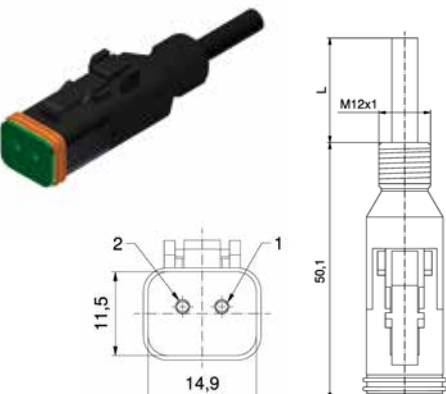
	PIN 1  PIN 2 	2	10 - 230 V AC/ DC	8	5	PUR	2 x 0,75	DT06-2SG-A/K1/0.75/2m	55-00391
								DT06-2SG-A/K1/0.75/5m	55-00392
								DT06-2SG-A/K1/0.75/10m	55-00393

VALVE CONNECTORS DT-Series

DT06, 2-pos.
Socket contacts, single wire

LED-protection circuit

Contact assignment

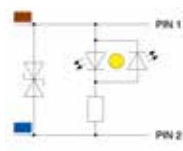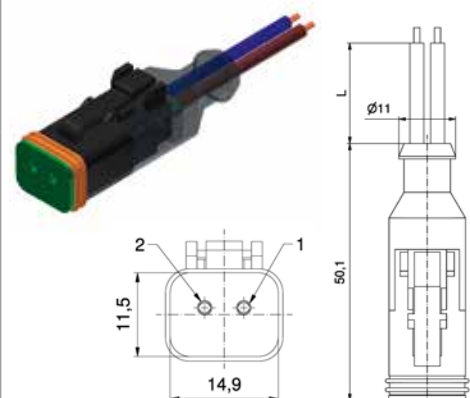

No. of poles	Type of protection circuit	Rated voltage [A]	Current rating [A]	Wire length = L [m]	Wire quality	Wire cross section [mm²]	Type of protection circuit DT06 2-pos. single wire: • B= Suppressordiode + 2x LED yellow Additional types of protection circuit upon request Technical information look at page 56 + 57	
							Description	Part No.
2	B	12 V AC / 24 V DC	8	0.5	PVC	2 x 0,75	DT06-2SL-B/A1/0.75/0,5m	55-00560
							DT06-2SL-B/A1/0.75/2m	55-00482
				5			DT06-2SL-B/A1/0.75/5m	55-00561
2	B	12 V AC / 24 V DC	8	0.5	PVC	2 x 0,75	DT06-2SLG-B/A1/0.75/0,5m	55-00562
							DT06-2SLG-B/A1/0.75/2m	55-00483
				5			DT06-2SLG-B/A1/0.75/5m	55-00563


Type of protection circuit DT06 2-pos.
single wire:
• B= Suppressordiode + 2x LED yellow
Additional types of protection circuit upon
request
Technical information look at page 56 + 57

VALVE CONNECTORS DT-Series


DT06, 2-pos.
Socket contacts, single wire

Without LED-protection circuit

Contact assignment

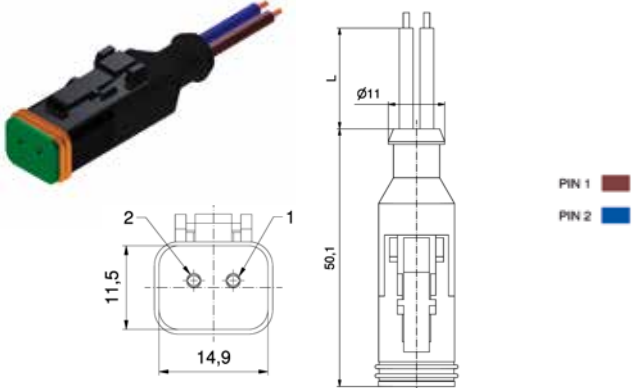		No. of poles	Rated voltage [A]	Current rating [A]	Wire length = L [m]	Wire quality	Wire cross section [mm²]	Description	Part No.
	2	10 - 230 V AC/ DC	8	2	PVC	2 x 0,75		DT06-2SL-A/A1/0.75/0,5m	55-00564
								DT06-2SL-A/A1/0.75/2m	55-00565
								DT06-2SL-A/A1/0.75/5m	55-00566



Without LED-protection circuit, M12 thread

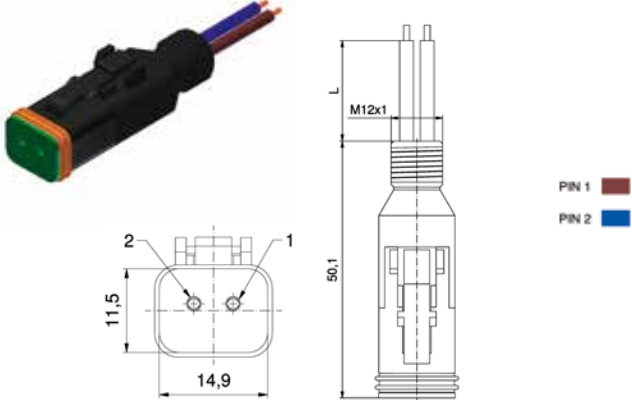	2	10 - 230 V AC/ DC	8	2	PVC	2 x 0,75		DT06-2SLG-A/A1/0.75/0,5m	55-00567
								DT06-2SLG-A/A1/0.75/2m	55-00568
								DT06-2SLG-A/A1/0.75/5m	55-00569

VALVE CONNECTORS DT-Series

DT04, 2-pos. Plug contacts

Protection circuits DT04 (2-, 3-pos.) upon request
Technical information look at page 56 + 57

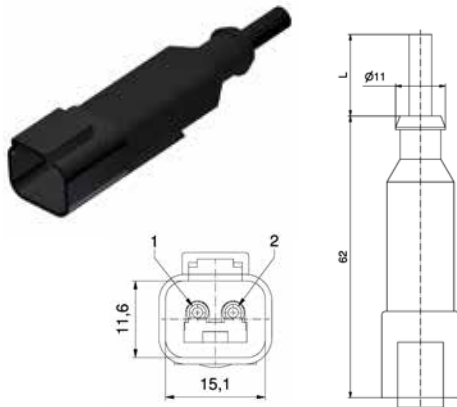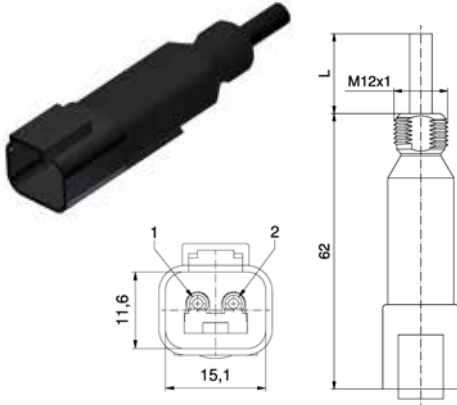
Without LED-protection circuit		Contact assignment	No.	Rat.	Cur	Cal	Cal	Wir	Description	Part No.
			2	10 - 230 V AC/ DC	8	5	PUR	2 x 0,75	DT04-2P-A/K1/0.75/2m	55-00448
									DT04-2P-A/K1/0.75/5m	55-00449
									DT04-2P-A/K1/0.75/10m	55-00450
Without LED-protection circuit, M12 thread										
			2	10 - 230 V AC/ DC	8	5	PUR	2 x 0,75	DT04-2PG-A/K1/0.75/2m	55-00451
									DT04-2PG-A/K1/0.75/5m	55-00452
									DT04-2PG-A/K1/0.75/10m	55-00453

VALVE CONNECTORS **DT-Series**


DT04, 2-pos.
Plug contacts, single wire

Without LED-protection circuit

Contact assignment

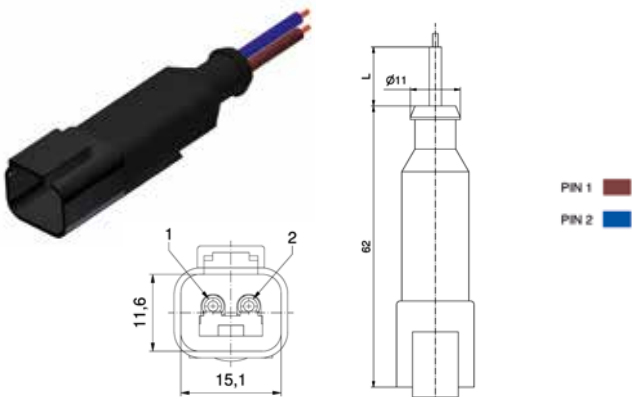Description		Part No.
	DT04-2PL-A/A1/0.75/0,5m	55-00576
	DT04-2PL-A/A1/0.75/2m	55-00577
	DT04-2PL-A/A1/0.75/5m	55-00578






Without LED-protection circuit, M12 thread




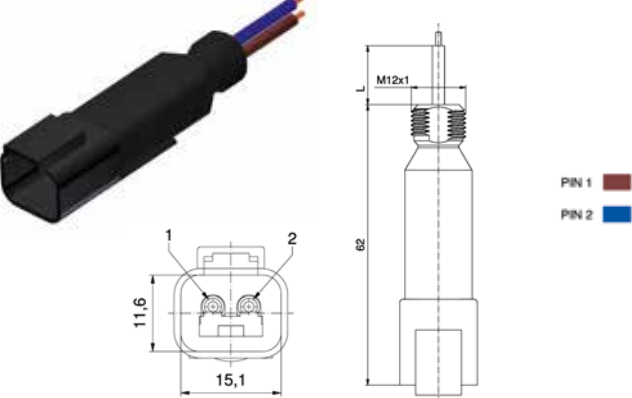
	DT04-2PLG-A/A1/0.75/0,5m	55-00579
	DT04-2PLG-A/A1/0.75/2m	55-00580
	DT04-2PLG-A/A1/0.75/5m	55-00581

Protection circuits DT04 (2-, 3-pos.) upon request
Technical information look at page 56 + 57

VALVE CONNECTORS DT-Series

DT06, 3-pos. Socket contacts

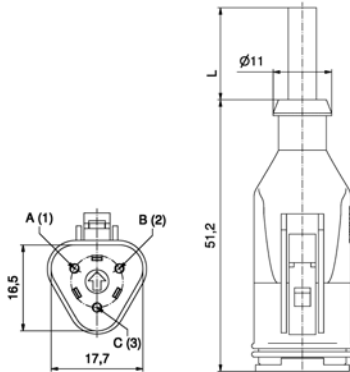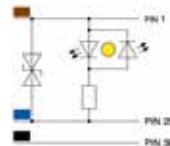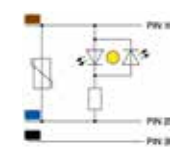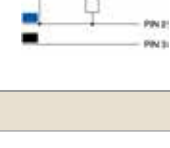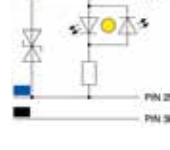LED-protection circuit			Contact assignment	No.	Type	Rated voltage	Current	Cable	Cable	Wire	Description	Part No.
 	   	3	B	12 V AC / 24 V DC	8	2	PUR	3 x 0,75	DT06-3S-B/K1/0.75/2m	55-00850		
						5			DT06-3S-B/K1/0.75/5m	55-00851		
						10			DT06-3S-B/K1/0.75/10m	55-00852		
			G	8 - 22 V AC / 32 V DC	4	2			DT06-3S-G/K1/0.75/2m	55-00772		
						5			DT06-3S-G/K1/0.75/5m	55-00773		
						10			DT06-3S-G/K1/0.75/10m	55-00774		
			E	8 - 24 V AC / 30 V DC	4	2			DT06-3S-E/K1/0.75/2m	55-00720		
						5			DT06-3S-E/K1/0.75/5m	55-00721		
						10			DT06-3S-E/K1/0.75/10m	55-00722		
			F	10 - 32 V DC	4	2			DT06-3S-F/K1/0.75/2m	55-00751		
						5			DT06-3S-F/K1/0.75/5m	55-00752		
						10			DT06-3S-F/K1/0.75/10m	55-00753		

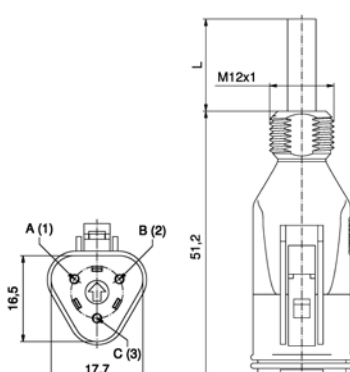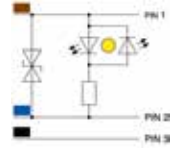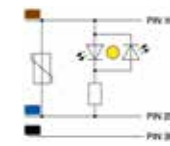 LED-protection circuit, M12 thread												
 	   	3	B	12 V AC / 24 V DC	8	2	PUR	3 x 0,75	DT06-3SG-B/K1/0.75/2m	55-00853		
						5			DT06-3SG-B/K1/0.75/5m	55-00854		
						10			DT06-3SG-B/K1/0.75/10m	55-00855		
			G	8 - 22 V AC / 32 V DC	4	2			DT06-3SG-G/K1/0.75/2m	55-00775		
						5			DT06-3SG-G/K1/0.75/5m	55-00776		
						10			DT06-3SG-G/K1/0.75/10m	55-00777		
			E	8 - 24 V AC / 30 V DC	4	2			DT06-3SG-E/K1/0.75/2m	55-00723		
						5			DT06-3SG-E/K1/0.75/5m	55-00724		
						10			DT06-3SG-E/K1/0.75/10m	55-00725		
			F	10 - 32 V DC	4	2			DT06-3SG-F/K1/0.75/2m	55-00754		
						5			DT06-3SG-F/K1/0.75/5m	55-00755		
						10			DT06-3SG-F/K1/0.75/10m	55-00756		

Types of protection circuit DT06 (2-, 3-pos.):

- B/G= Suppressordiode + 2x LED yellow
- E= Varistor + 2x LED yellow
- F= Freewheeling Diode + LED yellow


Technical information look at page 56 + 57

VALVE CONNECTORS DT-Series

DT06, 3-pos. Socket contacts


Without LED-protection circuit

Contact assignment

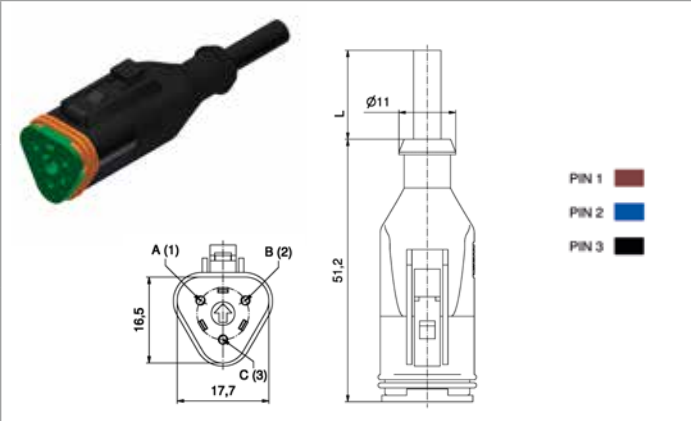

No. of poles	Rated voltage [A]	Current rating [A]	Cable length = L [m]	Cable quality	Wire cross section [mm²]	Description	Part No.
3	10 - 230 V AC/ DC	8	2	PUR	3 x 0,75	DT06-3S-A/K1/0.75/2m	55-00826
			5			DT06-3S-A/K1/0.75/5m	55-00827
			10			DT06-3S-A/K1/0.75/10m	55-00828

Without LED-protection circuit, M12 thread

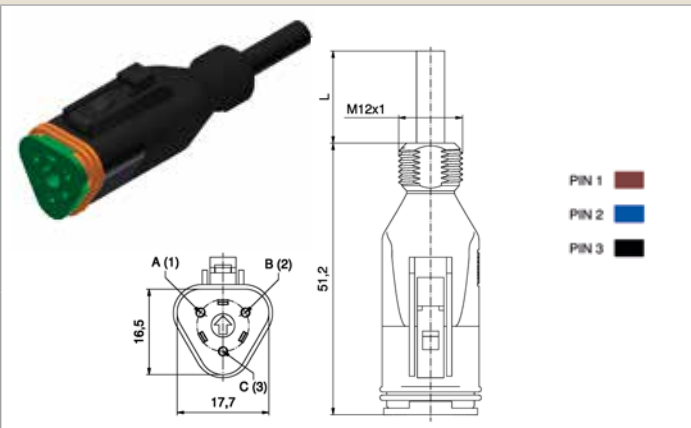


3	10 - 230 V AC/ DC	8	2	PUR	3 x 0,75	DT06-3SG-A/K1/0.75/2m	55-00829
			5			DT06-3SG-A/K1/0.75/5m	55-00830
			10			DT06-3SG-A/K1/0.75/10m	55-00831

VALVE CONNECTORS DT-Series


DT04, 3-pos. Plug contacts

Without LED-protection circuit

Contact assignment

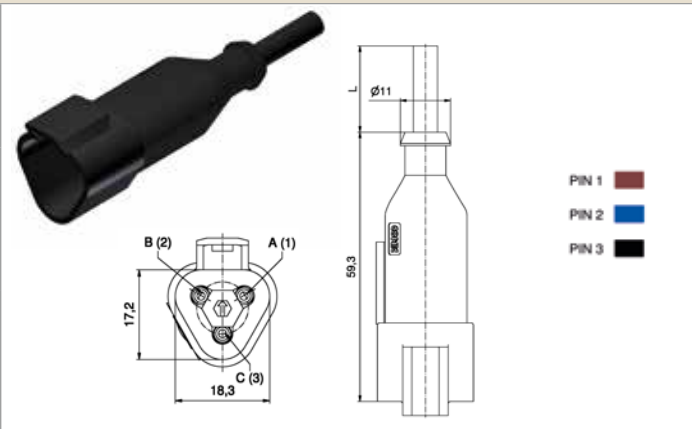

Without LED-protection circuit, M12 thread

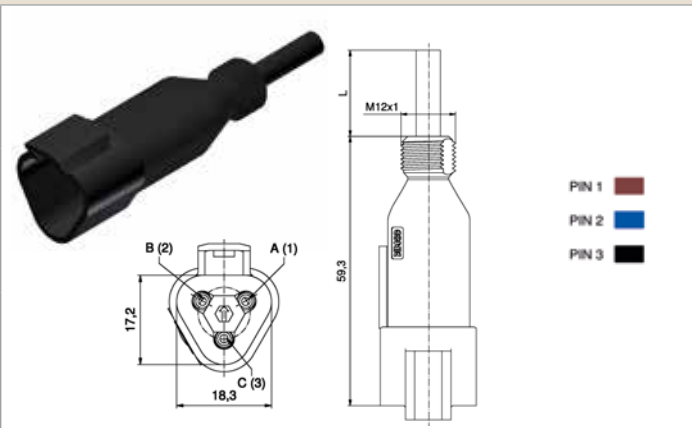

Protection circuits DT04 (2-, 3-pos.) upon request
Technical information look at page 56 + 57


No. of poles	Rated voltage [A]	Current rating [A]	Cable length = L [m]	Cable quality	Wire cross section [mm²]	Description	Part No.
3	10 - 230 V AC/ DC	8	2	PUR	3 x 0,75	DT04-3P-A/K1/0.75/2m	55-00832
			5			DT04-3P-A/K1/0.75/5m	55-00833
			10			DT04-3P-A/K1/0.75/10m	55-00834
3	10 - 230 V AC/ DC	8	2	PUR	3 x 0,75	DT04-3PG-A/K1/0.75/2m	55-00835
			5			DT04-3PG-A/K1/0.75/5m	55-00836
			10			DT04-3PG-A/K1/0.75/10m	55-00837

VALVE CONNECTORS DT-Series

DT06, 4-pos. Socket contacts


Without LED-protection circuit

Contact assignment

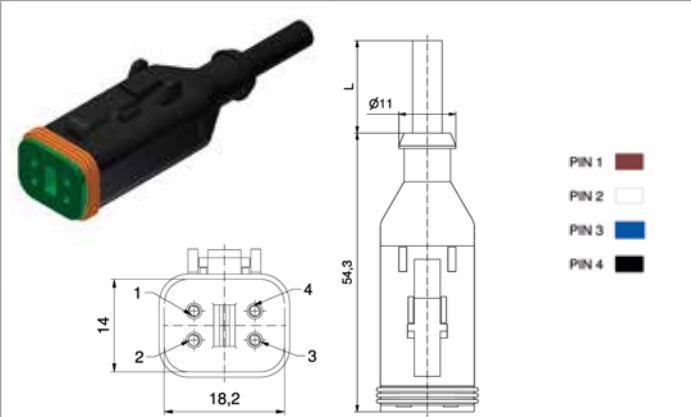

No. of poles	Rated voltage [A]	Current rating [A]	Cable length = L [m]	Cable quality	Wire cross section [mm²]	Description	Part No.
4	10 - 230 V AC/ DC	7	2	PUR	4 x 0,75	DT06-4S-A/K1/0.75/2m	55-00838
			5			DT06-4S-A/K1/0.75/5m	55-00839
			10			DT06-4S-A/K1/0.75/10m	55-00840

Without LED-protection circuit, M12 thread

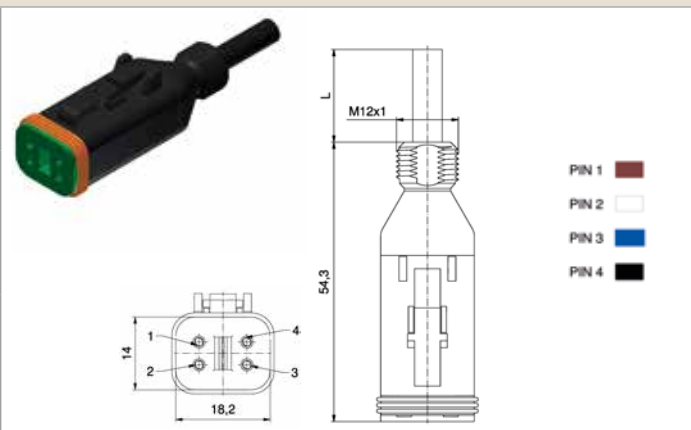


4	10 - 230 V AC/ DC	7	2	PUR	4 x 0,75	DT06-4SG-A/K1/0.75/2m	55-00841
			5			DT06-4SG-A/K1/0.75/5m	55-00842
			10			DT06-4SG-A/K1/0.75/10m	55-00843

VALVE CONNECTORS DT-Series

DT04, 4-pos.
Plug contacts


Without LED-protection circuit

Contact assignment

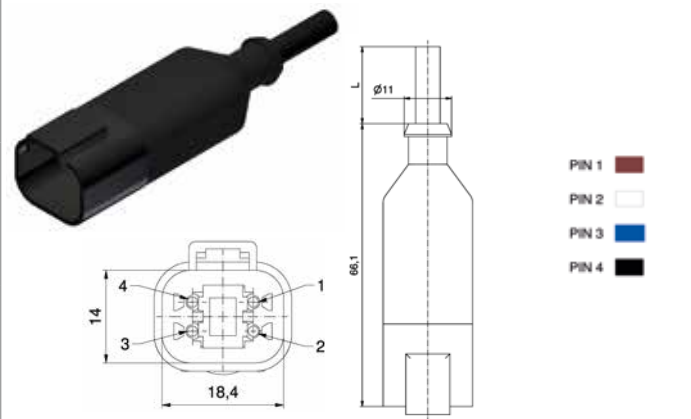

No. of poles	Rated voltage [A]	Current rating [A]	Cable length = L [m]	Cable quality	Wire cross section [mm²]	Description	Part No.
4	10 - 230 V AC/ DC	7	2	PUR	4 x 0,75	DT04-4P-A/K1/0.75/2m	55-00844
			5			DT04-4P-A/K1/0.75/5m	55-00845
			10			DT04-4P-A/K1/0.75/10m	55-00846

Without LED-protection circuit, M12 thread

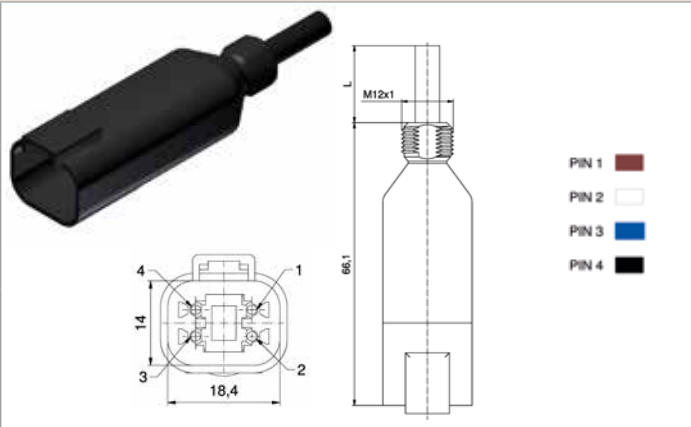


4	10 - 230 V AC/ DC	7	2	PUR	4 x 0,75	DT04-4PG-A/K1/0.75/2m	55-00847
			5			DT04-4PG-A/K1/0.75/5m	55-00848
			10			DT04-4PG-A/K1/0.75/10m	55-00849

VALVE CONNECTORS DT-Series


DT06, 6-pos. Socket contacts

Without LED-protection circuit

Contact assignment

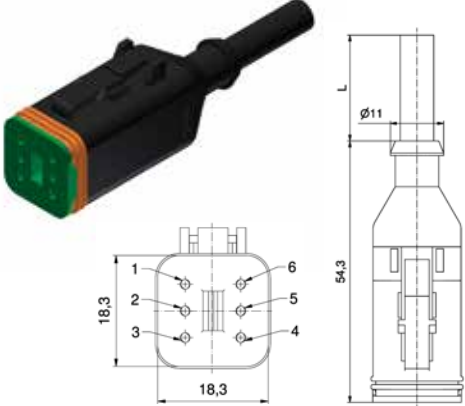		No. of poles	Rated voltage [A]	Current rating [A]	Cable length = L [m]	Cable quality	Wire cross section [mm²]	Description	Part No.
		6	10 - 230 V AC/ DC	6	2	PUR	6 x 0,75	DT06-6S-A/K1/0.75/2m	55-00501
					5			DT06-6S-A/K1/0.75/5m	55-00502
					10			DT06-6S-A/K1/0.75/10m	55-00503

Without LED-protection circuit, M12 thread

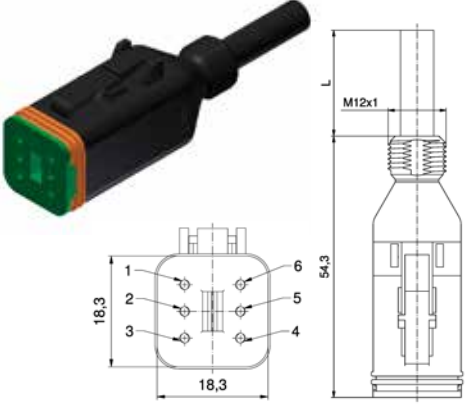
		6	10 - 230 V AC/ DC	6	2	PUR	6 x 0,75	DT06-6SG-A/K1/0.75/2m	55-00504
					5			DT06-6SG-A/K1/0.75/5m	55-00505
					10			DT06-6SG-A/K1/0.75/10m	55-00506

VALVE CONNECTORS DT-Series

DT04, 6-pos. Plug contacts


Without LED-protection circuit

Contact assignment

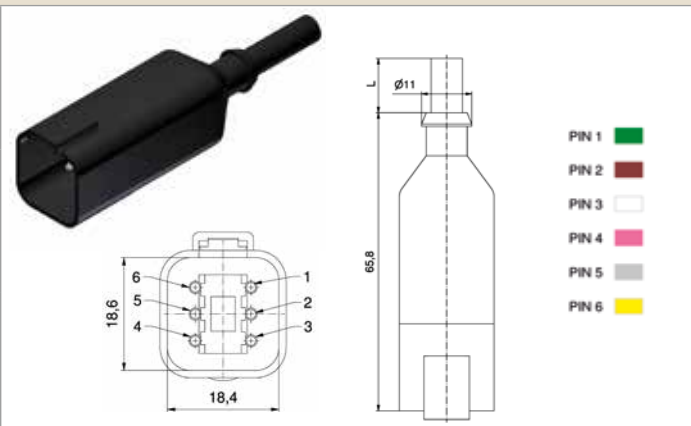

No. of poles	Rated voltage [A]	Current rating [A]	Cable length = L [m]	Cable quality	Wire cross section [mm²]	Description	Part No.
6	10 - 230 V AC/ DC	6	2	PUR	6 x 0,75	DT04-6P-A/K1/0.75/2m	55-00507
			5			DT04-6P-A/K1/0.75/5m	55-00508
			10			DT04-6P-A/K1/0.75/10m	55-00509

Without LED-protection circuit, M12 thread

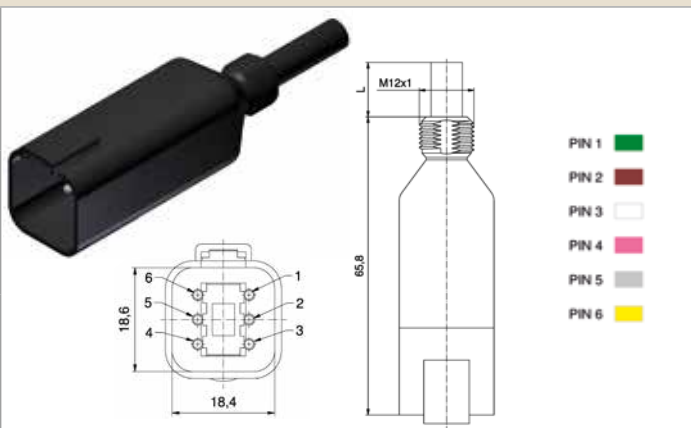


6	10 - 230 V AC/ DC	6	2	PUR	6 x 0,75	DT04-6PG-A/K1/0.75/2m	55-00510
			5			DT04-6PG-A/K1/0.75/5m	55-00511
			10			DT04-6PG-A/K1/0.75/10m	55-00512

VALVE CONNECTORS DT-Series

DT06, 8-pos. Socket contacts


Without LED-protection circuit

Contact assignment

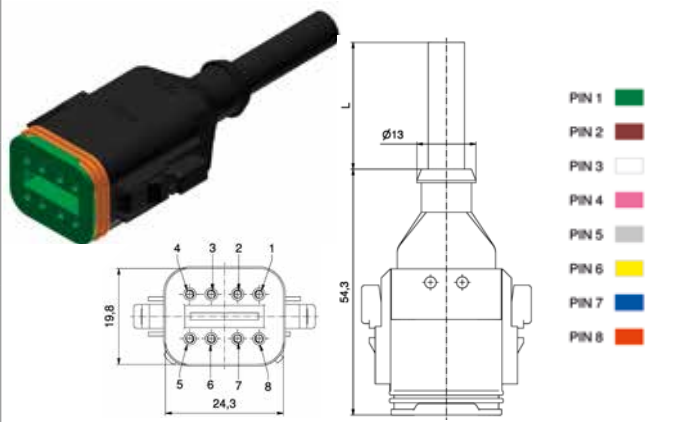

No. of poles	Rated voltage [A]	Current rating [A]	Cable length = L [m]	Cable quality	Wire cross section [mm²]	Description	Part No.
8	10 - 230 V AC/ DC	6	2	PUR	8 x 0,75	DT06-8AS-A/K1/0.75/2m	55-00526
			5			DT06-8AS-A/K1/0.75/5m	55-00527
			10			DT06-8AS-A/K1/0.75/10m	55-00528

Without LED-protection circuit, M12 thread

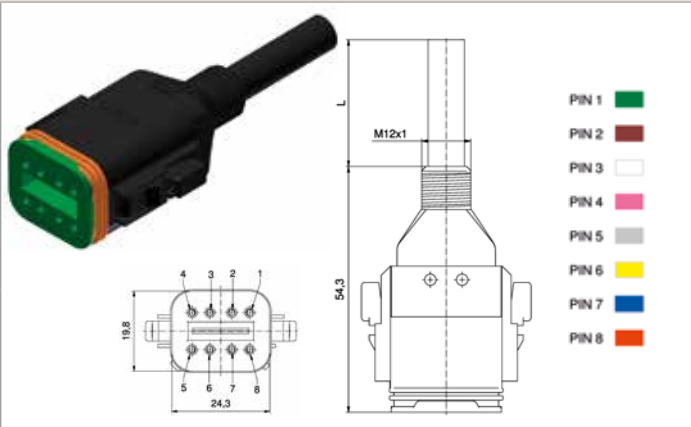

8	10 - 230 V AC/ DC	6	2	PUR	8 x 0,75	DT06-8ASG-A/K1/0.75/2m	55-00532
			5			DT06-8ASG-A/K1/0.75/5m	55-00533
			10			DT06-8ASG-A/K1/0.75/10m	55-00534

VALVE CONNECTORS DT-Series



DT04, 8-pos. Plug contacts

Without LED-protection circuit

Contact assignment

No. of poles	Rated voltage [A]	Current rating [A]	Cable length = L [m]	Cable quality	Wire cross section [mm²]	Description	Part No.
8	10 - 230 V AC/ DC	6	2	PUR	8 x 0,75	DT04-8AP-A/K1/0.75/2m	55-00529
			5			DT04-8AP-A/K1/0.75/5m	55-00530
			10			DT04-8AP-A/K1/0.75/10m	55-00531

Without LED-protection circuit, M12 thread

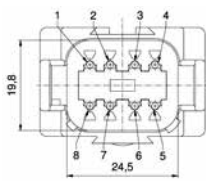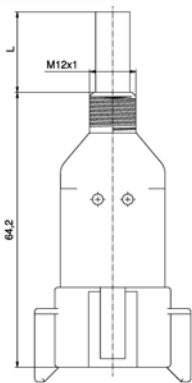  	8	10 - 230 V AC/ DC	6	5	PUR	8 x 0,75	DT04-8APG-A/K1/0.75/2m	55-00535
							DT04-8APG-A/K1/0.75/5m	55-00536
							DT04-8APG-A/K1/0.75/10m	55-00537


VALVE CONNECTORS DT-Series

DT06, 12-pos. Socket contacts

Without LED-protection circuit


Contact assignment

No. of poles	Rated voltage [A]	Current rating [A]	Cable length = L [m]	Cable quality	Wire cross section [mm²]	Description	Part No.
12	10 - 230 V AC/ DC	5	2	PUR	12 x 0,75	DT06-12AS-A/K1/0.75/2m	55-00553
			5			DT06-12AS-A/K1/0.75/5m	55-00554
		10	10			DT06-12AS-A/K1/0.75/10m	55-00555

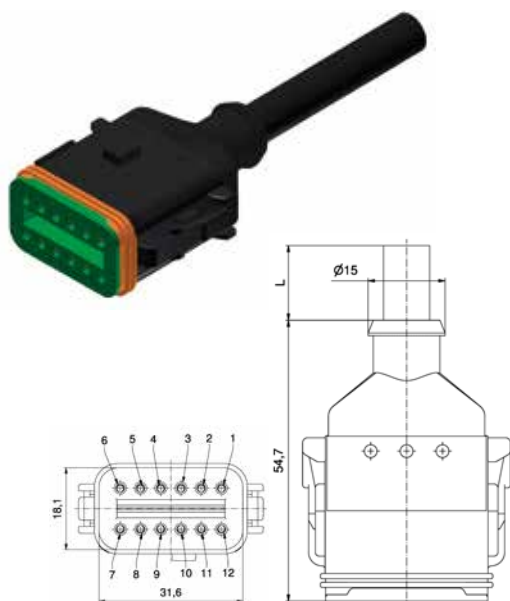

DT04, 12-pos. Plug contacts

Without LED-protection circuit

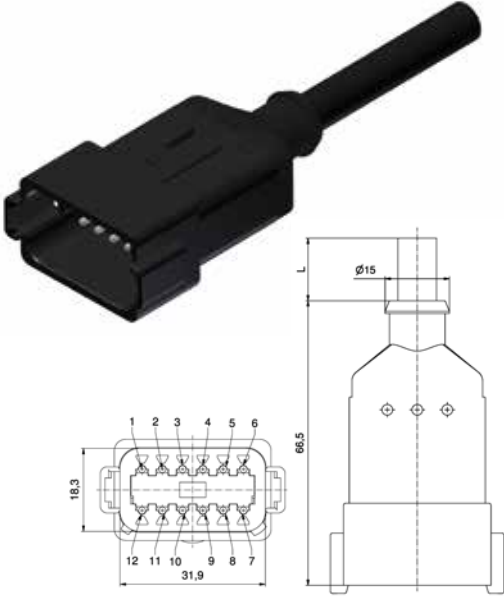	12	10 - 230 V AC/ DC	5	PUR	12 x 0,75	DT04-12AP-A/K1/0.75/2m	55-00556
						DT04-12AP-A/K1/0.75/5m	55-00557
			10			DT04-12AP-A/K1/0.75/10m	55-00558

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Amphenol:](#)

[55-00501](#) [55-00507](#)