
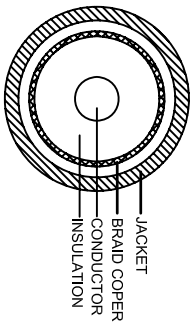


THE INFORMATION CONTAINED IN THIS DRAWING IS THE SOLE PROPERTY OF AMPHENOL CABLES ON DEMAND. ANY REPRODUCTION OR DISCLOSURE TO THIRD PARTIES, IN PART OR WHOLE, WITHOUT THE EXPRESS WRITTEN PERMISSION OF AMPHENOL CABLES ON DEMAND IS PROHIBITED.

REVISIONS			
REV.	DESCRIPTION	DATE	APPROVED
A	NEW RELEASE	17Sep/09	
A1	ADD L=1FT	22Oct/09	
A2	ADD L=10 INCH	20May/10	
A3	ADD L=2FT 1.14FT 1.6FT	8Oct/15	
A4	ADD L=410mm	13Sep/2017	

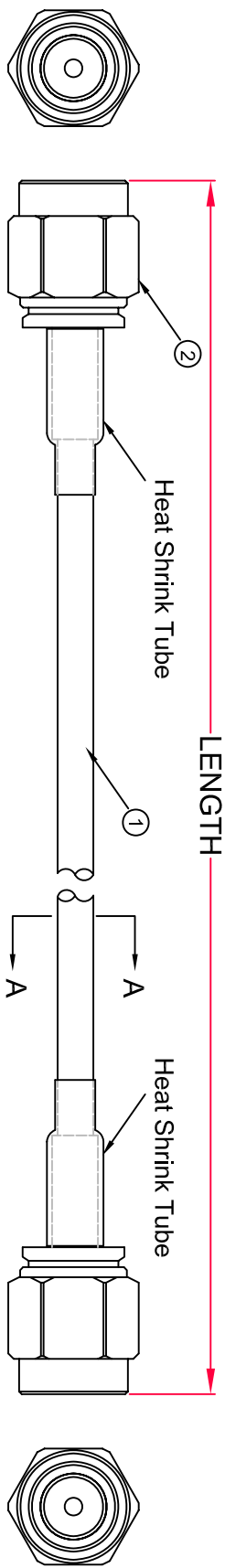

SECTION A-A

NOTES:

- 1.CABLE:[26AWG(7/0.16±0.008mm)*1C +BRAID(16*4/0.12±0.008mm)]TINNEE COPPER INSULATION;PE OD= 1.52±0.07mm ;COLOR:TRANSPARENT JACKET:HALF MATTE PVC LOW TOXIC;OD=Ø2.54±0.10mm COLOR:UL813 BLACK.
 - 2.CONNECTOR:SMA Male GOLD-PLATING
 - 3.OPEN/SHORT MISS WIRE TEST 100%
 - 4.CONDUCTOR RESISTANCE ≤150Ω/km
 - 5.INSULATION RESISTANCE ≥2MΩ DC300V 0.01Sec
- ALL MATERIALS SHOULD ACCORD WITH RoHS STANDARD.

LENGTH & P/N Table

LENGTH	P/N
6 INCH(152±15mm)	CO-174SMAAX200-000.6
8 INCH(203±15mm)	CO-174SMAAX200-000.8
10 INCH(254±15mm)	CO-174SMAAX200-000.10
1FT(305±20mm)	CO-174SMAAX200-001
2FT(610±30mm)	CO-174SMAAX200-002
3FT(914±30mm)	CO-174SMAAX200-003
4FT(1219±30mm)	CO-174SMAAX200-004
5FT(1524±30mm)	CO-174SMAAX200-005
7FT(2134±40mm)	CO-174SMAAX200-007
7.5FT(2286±40mm)	CO-174SMAAX200-007.5
10FT(3048±40mm)	CO-174SMAAX200-010
12FT(3658±50mm)	CO-174SMAAX200-012
14FT(4267±50mm)	CO-174SMAAX200-014
16FT(4877±50mm)	CO-174SMAAX200-016
410±20mm	

PIN OUT:

CENTER	CENTER
SHELL	SHELL



UNLESS OTHERWISE SPECIFIED DIMENSIONS ARE IN INCHES TOLERANCES ARE:				Amphenol Cables on Demand 20 VALLEY ST. ENDCOTT, NY 13760			
DIMENS		ANGS		APPROVALS		DATE	
X	±.X	±.X°		DRAWN	LF	8/0CT/15	
.XX	±.XX			CHECKED	BA	8/0CT/15	
.XXX	±.XXX			RESP ENG			
THIRD ANGLE PROJECTION				MPG ENG			
				SIZE	DWG. NO.	CO-174SMAAX200-XXX	REV. A4
				A			

NOTES: UNLESS OTHERWISE SPECIFIED

4

3

4

2

1

SCALE

SHEET

OF

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Amphenol:](#)

[CO-174SMAX200-007](#) [CO-174SMAX200-003](#) [CO-174SMAX200-000.6](#) [CO-174SMAX200-001](#) [CO-174SMAX200-005](#) [CO-174SMAX200-010](#) [CO-174SMAX200-004](#) [CO-174SMAX200-002](#)