



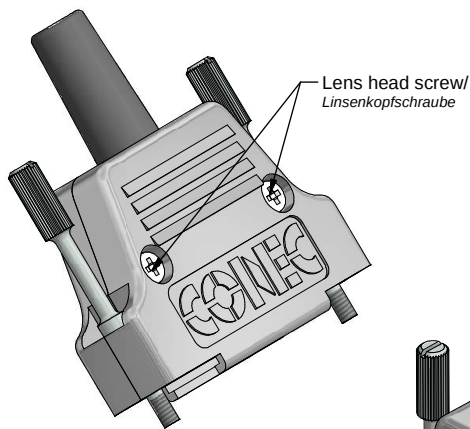

Lens head screw/
Linsenkopfschraube

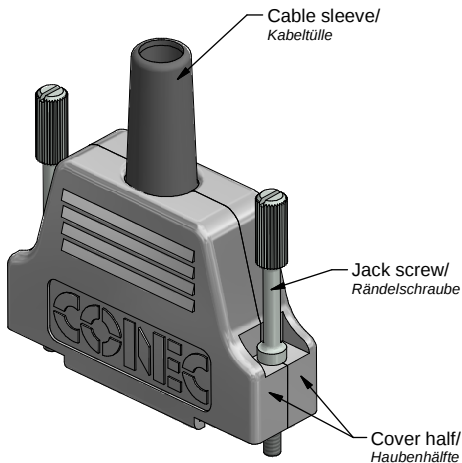

Cable sleeve/
Kabeltülle

Jack screw/
Rändelschraube

Cover half/
Haubenhälfte

b) Technical specification:

Technische Daten:

Temperature range/
Temperaturbereich: - 35 °C ... + 90 °C

Materials/ Werkstoffe:

Cover half/
Haubenhälfte: GD-Zn, Ni

Cable strain relief/
Kabel Zugentlastung: Steel, Ni


Cable sleeve/
Kabeltülle: Rubber

Jack screw/
Rändelschraube: Steel, Ni

Lens head screw/
Linsenkopfschraube: Steel, Ni

Installation specification/ Montagedaten:

Cable outlet/
Kabelausgang: straight/ gerade

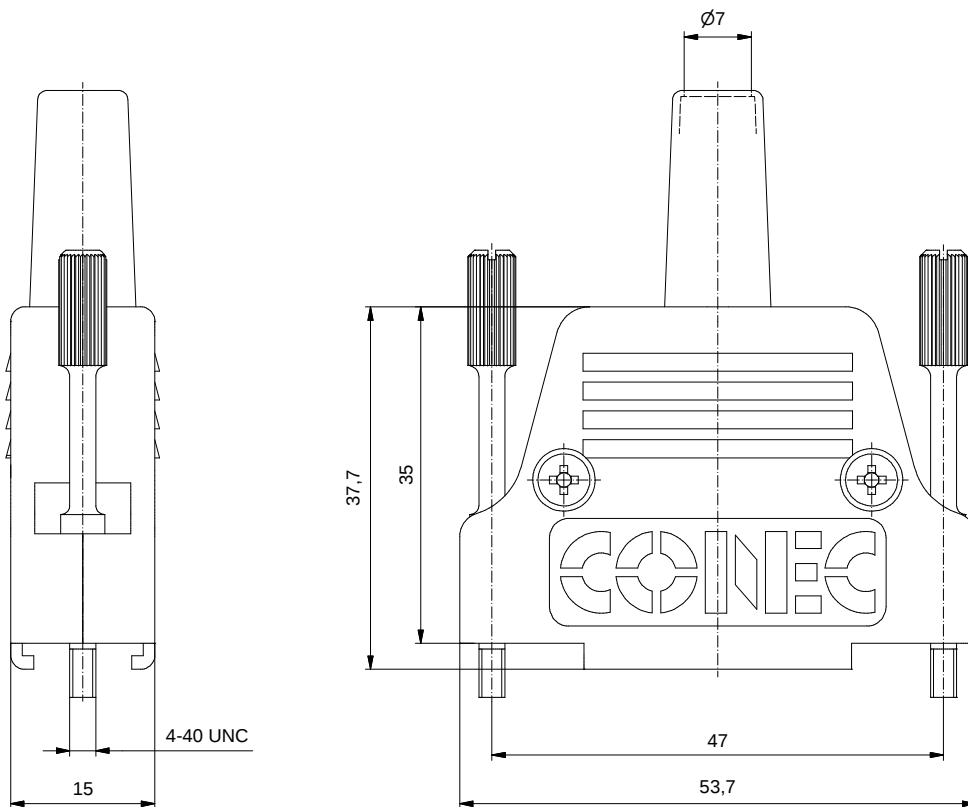

Part no./ Art.-Nr.	
165X17329X	Bulk package/ Massenverpackung
165X17329XE	Single package/ Einzelverpackung

		dim. in mm	Full metal hood 25pos. with straight cable exit Vollmetallhaube 25pol. mit gradem Kabelausgang	
		Date/Datum	Name	
Index: b Ä7223 16.04.18 L.U.	Scale/Maßstab: 2:1	drawn/ gez. 16.04.2018	Unkrüer	dwg no / Z.-nr.: 16K1A4048
		appd./ gepr. 17.04.2018	Schmidt	
Status: InBearbeitung		CONEC®		DIN-A3
RoHS compliant/ konform				1 / 1

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Amphenol:](#)

[165X17329X](#)