
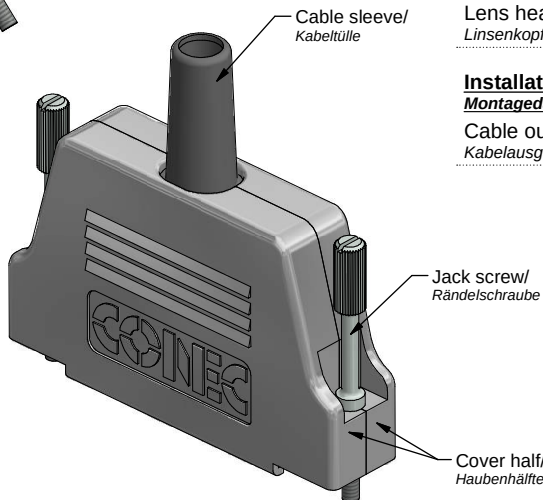


F I E D C B A

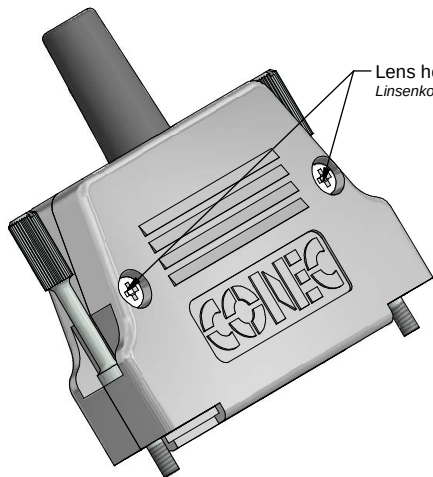

(b) **Technical specification:**

Technische Daten:

Temperature range/ - 35 °C ... + 90 °C
Temperaturbereich:

Materials/

Werkstoffe:

Cover half/ GD-Zn, Ni
Haubenhälfte:

Cable strain relief/ Steel, Ni
Kabel Zugentlastung:

Cable sleeve/ Rubber
Kabeltülle:



Jack screw/ Steel, Ni
Rändelschraube:

Lens head screw/ Steel, Ni
Linsenkopfschraube:

Installation specification/

Montagedaten:

Cable outlet/ straight/ gerade
Kabelausgang:

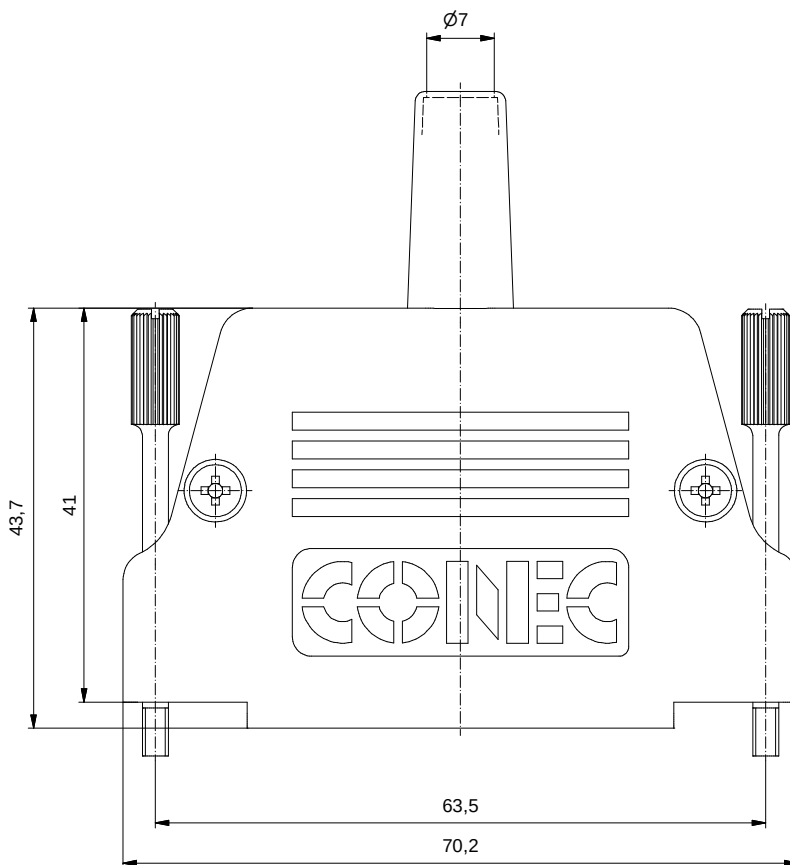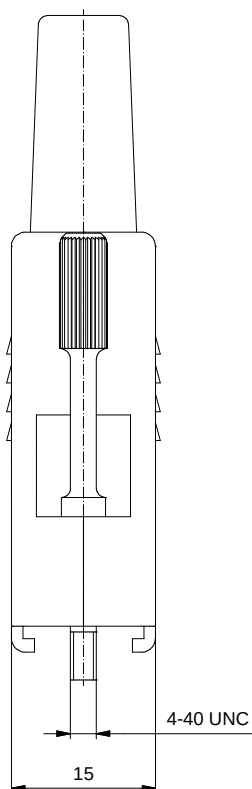

Part no./ Art.-Nr.	
165X17339X	Bulk package/ Massenverpackung
165X17339XE	Single package/ Einzelverpackung

				dim. in mm		Full metal hood 37pos. with straight cable exit Vollmetallhaube 37pol. mit gradem Kabelausgang	
		drawn/ gez.	Date/Datum	Name			
		appd./ gepr.	16.04.2018	Unkrüer			
			17.04.2018	Schmidt			
Index: b Ä7223 16.04.18 L.U.	Scale/Maßstab: 2:1			dwg no / Z.-nr.:		16K1A4049	DIN-A3
Status: InBearbeitung							
RoHS compliant/ konform							1 / 1

F I E D C B A

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Amphenol:](#)

[165X17339X](#)