

(b) **Technical specification:**

Technische Daten:

Temperature range/ - 35 °C ... + 90 °C
Temperaturbereich:

Materials/

Werkstoffe:

Cover half/ GD-Zn, Ni
Haubenhälfte:

Cable strain relief/ Steel, Ni
Kabel Zugentlastung:

Cable sleeve/ Rubber
Kabeltülle:


Jack screw/ Steel, Ni
Rändelschraube:

Lens head screw/ Steel, Ni
Linsenkopfschraube:


Installation specification/

Montagedaten:

Cable outlet/ straight/ gerade
Kabelausgang:

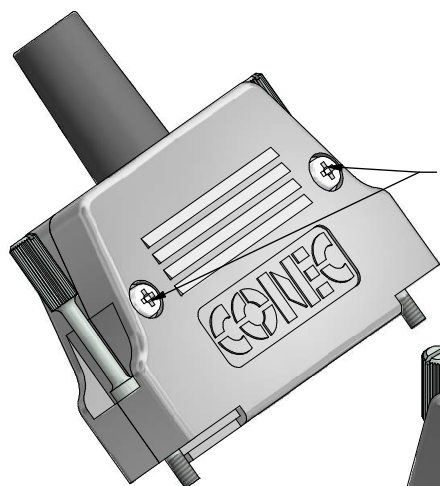



Lens head screw/
Linsenkopfschraube

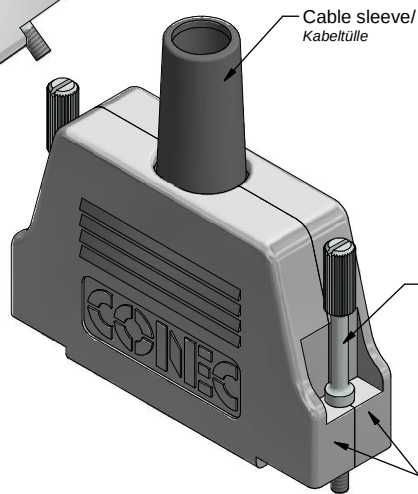

Cable sleeve/
Kabeltülle

Jack screw/
Rändelschraube

Cover half/
Haubenhälfte

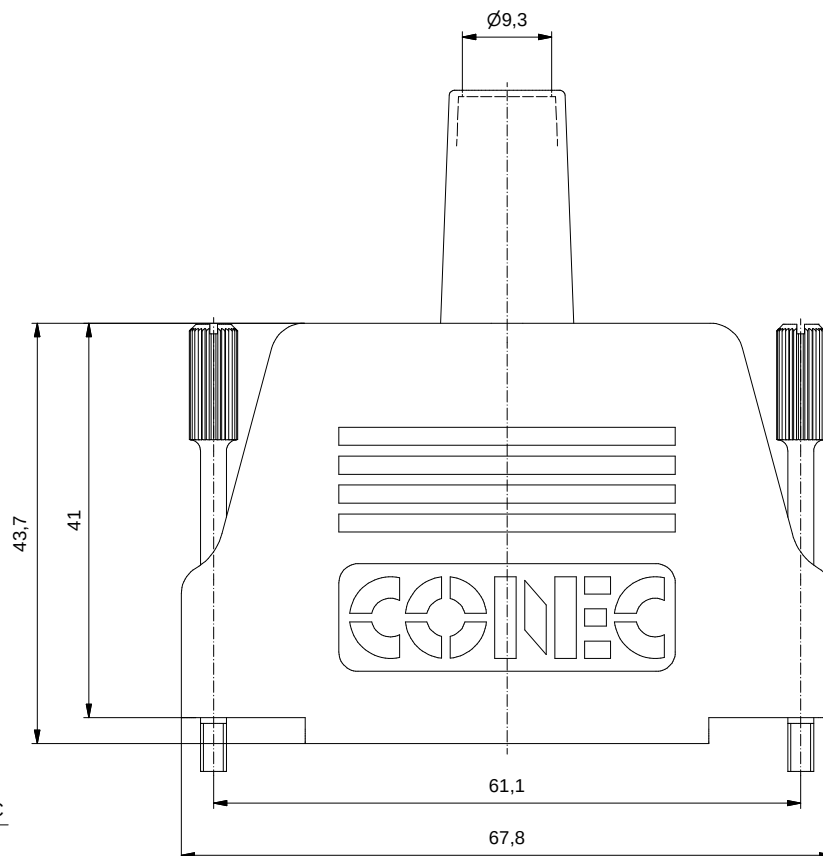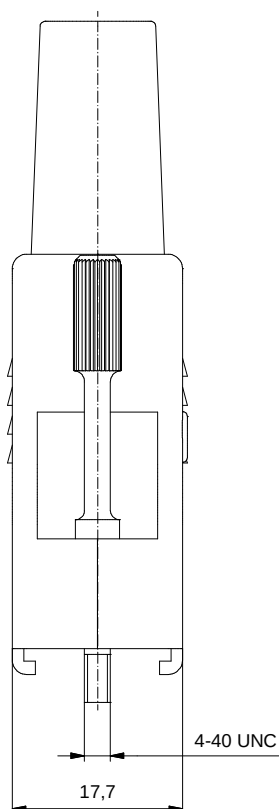

Part no./ Art.-Nr.	
165X17349X	Bulk package/ Massenverpackung
165X17349XE	Single package/ Einzelverpackung

		dim. in mm	Full metal hood 50pos. with straight cable exit Vollmetallhaube 50pol. mit gradem Kabelausgang	
		Date/Datum	Name	
		16.04.2018	Unkrüer	
		17.04.2018	Schmidt	
Index: b Ä7223 16.04.18 L.U.	scale/Maßstab:	dwg no / Z.-nr.: 16K1A4050		DIN- A3
Status: InBearbeitung	2:1	CONEC®		1 / 1
RoHS compliant/ konform				

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Amphenol:](#)

[165X17349X](#) [165X17349XE](#)