


ROHS COMPLIANT

PRODUCT DATA DRAWING

REVISION HISTORY			
REV	DESCRIPTION	DATE	APPROVED
01	PRELIMINARY	03/14	STW
-	NRN 38795	05/14	STW

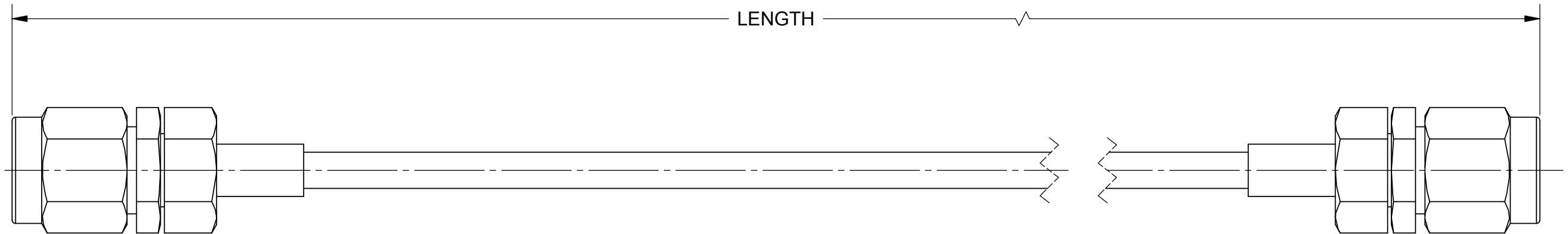

MATERIAL:

CONNECTORS: 2X SF1511-60030 (SVK STR MALE, 2.92 mm)

CABLE: 200-70-139 (TFLEX 405)

SHRINK TUBING: M23053/5

PERFORMANCE:

IMPEDANCE: 50 OHMS
FREQ. RANGE: DC TO 40.0 GHz
VSWR: 1.5:1 MAX.
INSERTION LOSS: SEE TABLE

SV PART NUMBER	LENGTH	TOLERANCE	LOSS(dB MAX)
7015-0615	12.000	±.125	1.97
7015-0616	24.000	±.250	3.71
7015-0617	36.000	±.250	5.45

MATERIAL:	SEE NOTES	DIMENSIONS ARE IN INCHES TOLERANCES:	UNLESS OTHERWISE SPECIFIED		SV Microwave, Inc. 2400 Centrepark West Drive, Suite 100 West Palm Beach, FL 33409		
FINISH:	SEE NOTES	FRACTIONAL: ±1/64 ANGULAR: X° ±1°0' 					

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Amphenol:](#)

[7015-0617](#)