


PRODUCT DATA DRAWING

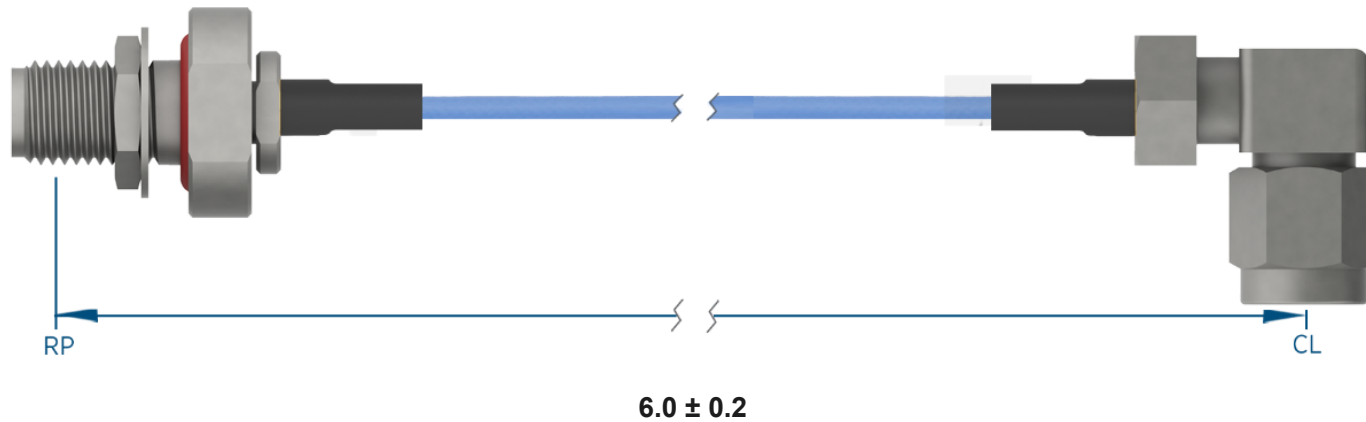

MATERIAL

CONNECTORS: 2.92mm Bulkhead Female (SF1521-60045)
SMA R/A Male (2912-61002)

CABLE: Ø.047 Flexible Coax

SHRINK TUBING: M23053/5

PERFORMANCE

IMPEDANCE: 50 Ohms

FREQ. RANGE: DC to 18 GHz

VSWR: 1.4:1 Max, DC to 18.0 GHz
1.6:1 Max, 18.0 + GHz

INSERTION LOSS: 1.30 dB Max

NOTES

1. See individual data drawings for connector specifications
2. Dimensions shown are in inches



TITLE:

2.92mm Bulkhead Female to SMA R/A Male 6" Cable
Assembly for Ø.047 Flexible Coax

DWG. NO.

FB292-047-MRSMA-060

DRAWN

2022-10-14 14:03:21

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Amphenol:](#)

[FB292-047-MRSMA-060](#)