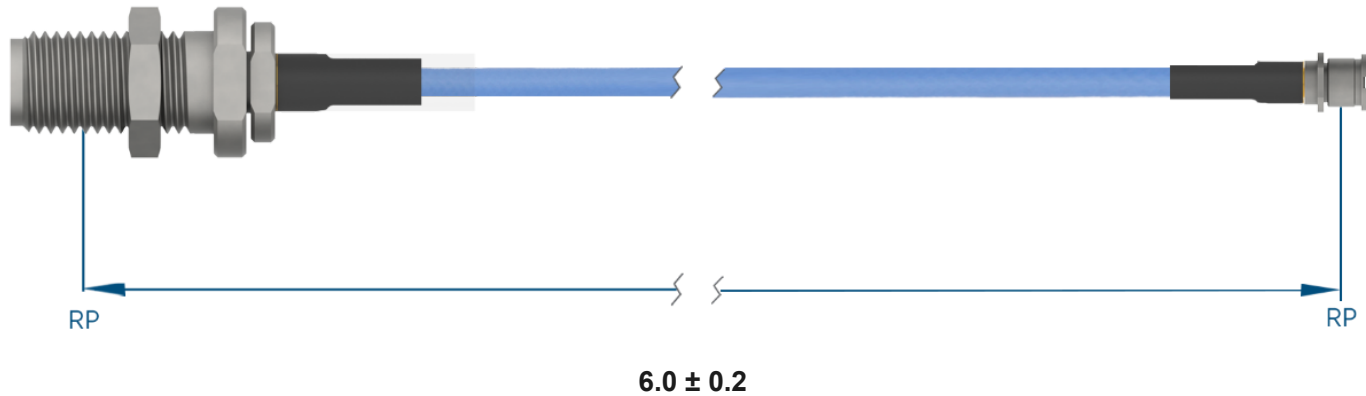


PRODUCT DATA DRAWING

**MATERIAL**

CONNECTORS: 2.92mm Bulkhead Female (SF1521-60025)
SMP Male Bulkhead (SF1211-6061)

CABLE: Ø.085 Flexible Coax

SHRINK TUBING: M23053/5

PERFORMANCE

IMPEDANCE: 50 Ohms

FREQ. RANGE: DC to 26.5 GHz

VSWR: 1.4:1 Max, DC to 18.0 GHz
1.6:1 Max, 18.0 + GHz

INSERTION LOSS: 1.01 dB Max

NOTES

1. See individual data drawings for connector specifications
2. Dimensions shown are in inches

**TITLE:**

2.92mm Bulkhead Female to SMP Male Bulkhead 6"
Cable Assembly for Ø.085 Flexible Coax

DWG. NO.

FB292-085-MBSMP-060

DRAWN

2022-10-17 11:58:38

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Amphenol:](#)

[FB292-085-MBSMP-060](#)