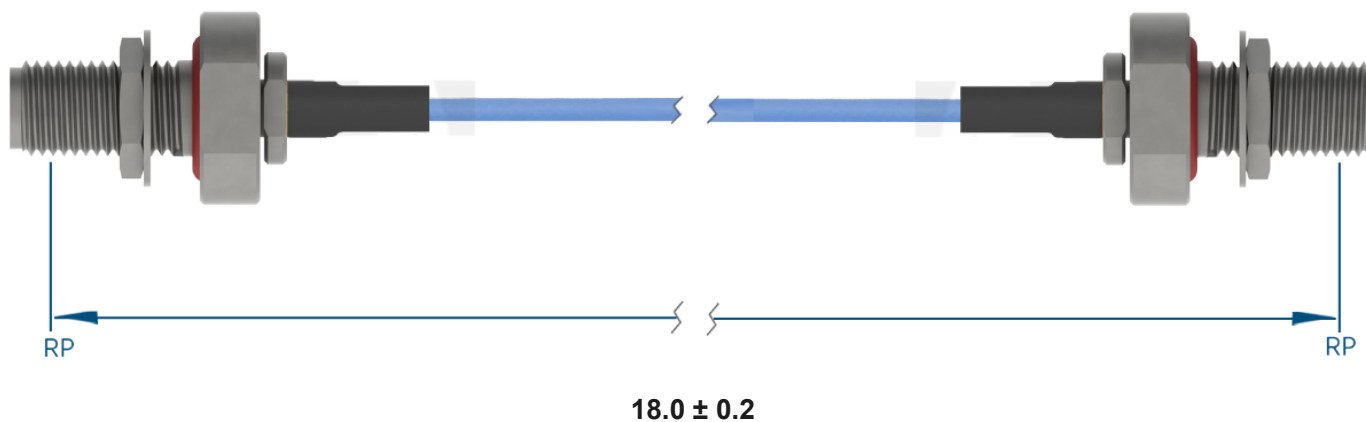


PRODUCT DATA DRAWING

**MATERIAL**

CONNECTORS: SMA Bulkhead Female (2944-6001)
SMA Bulkhead Female (2944-6001)

CABLE: Ø.047 Flexible Coax

SHRINK TUBING: M23053/5

PERFORMANCE

IMPEDANCE: 50 Ohms

FREQ. RANGE: DC to 18 GHz

VSWR: 1.3:1 Max, DC to 18.0 GHz
1.5:1 Max, 18.0 + GHz

INSERTION LOSS: 3.22 dB Max

NOTES

1. See individual data drawings for connector specifications
2. Dimensions shown are in inches

**TITLE:**

SMA Bulkhead Female to SMA Bulkhead Female 18"
Cable Assembly for Ø.047 Flexible Coax

DWG. NO.

FBSMA-047-FBSMA-180

DRAWN

2022-10-17 12:06:52

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Amphenol:](#)

[FBSMA-047-FBSMA-180](#)