


PRODUCT DATA DRAWING

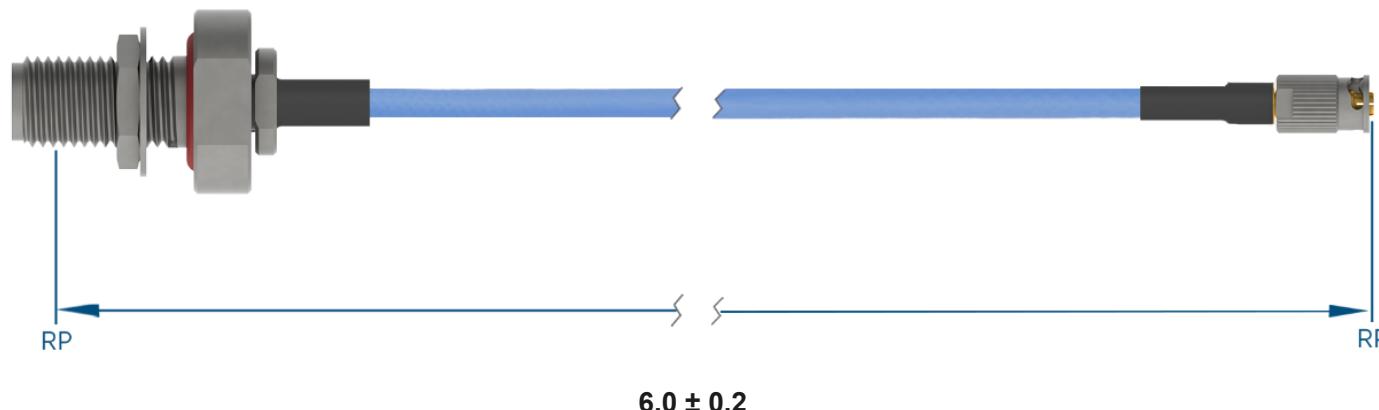

MATERIAL

CONNECTORS: SMA Bulkhead Female ([2946-6012](#))
SMPM Female QB ([3221-60004](#))

CABLE: Ø.085 Flexible Coax

SHRINK TUBING: M23053/5

PERFORMANCE

IMPEDANCE: 50 Ohms

FREQ. RANGE: DC to 18 GHz

VSWR: 1.4:1 Max, DC to 18.0 GHz
1.6:1 Max, 18.0 + GHz

INSERTION LOSS: 0.82 dB Max

NOTES

1. See individual data drawings for connector specifications
2. Dimensions shown are in inches



TITLE:
SMA Bulkhead Female to SMPM Female QB 6" Cable
Assembly for Ø.085 Flexible Coax

DWG. NO.
[FBSMA-085-FQSMPM-060](#)

DRAWN
2022-10-17 12:24:47

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Amphenol:](#)

[FBSMA-085-FQSMPM-060](#)