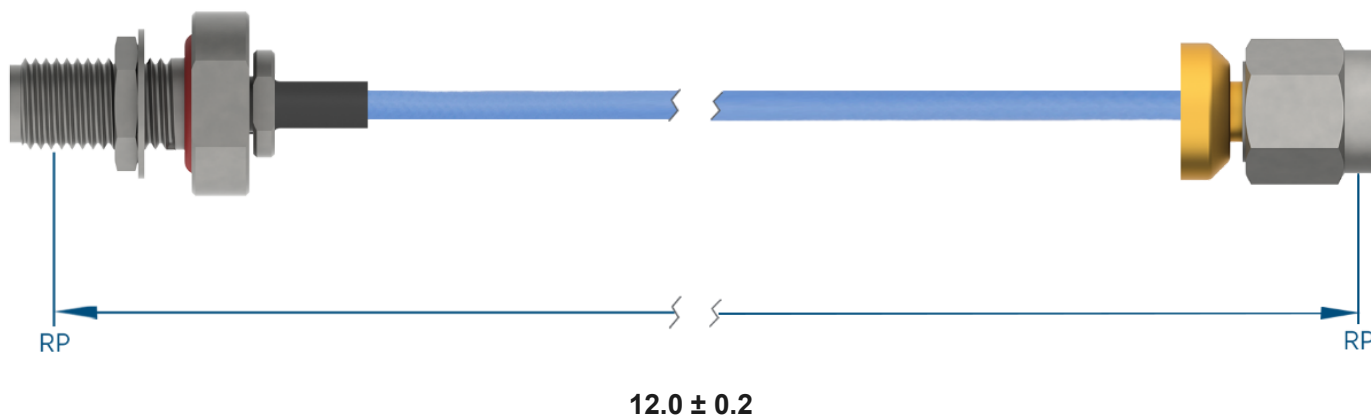


PRODUCT DATA DRAWING

**MATERIAL**

CONNECTORS: SMA Bulkhead Female (2946-6012)
SMA Low Profile Male (2911-61000)

CABLE: Ø.085 Flexible Coax

SHRINK TUBING: M23053/5

PERFORMANCE

IMPEDANCE: 50 Ohms

FREQ. RANGE: DC to 18 GHz

VSWR: 1.3:1 Max, DC to 18.0 GHz
1.5:1 Max, 18.0 + GHz

INSERTION LOSS: 1.30 dB Max

NOTES

1. See individual data drawings for connector specifications
2. Dimensions shown are in inches

**TITLE:**

SMA Bulkhead Female to SMA Low Profile Male 12"
Cable Assembly for Ø.085 Flexible Coax

DWG. NO.

FBSMA-085-MSLPSMA-120

DRAWN

2022-10-17 12:27:40

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Amphenol:](#)

[FBSMA-085-MSLPSMA-120](#)