
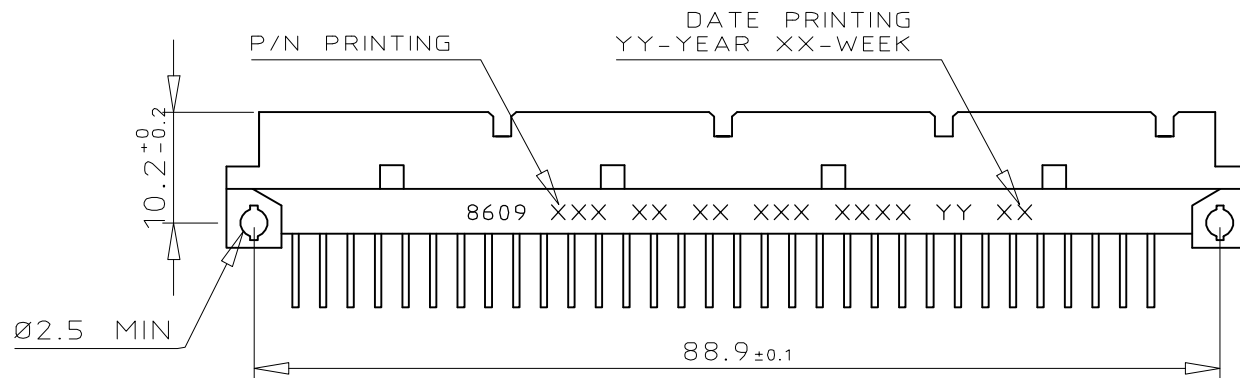
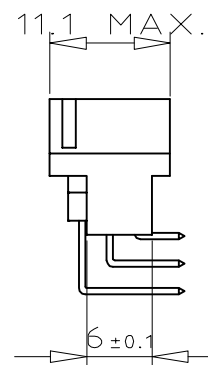
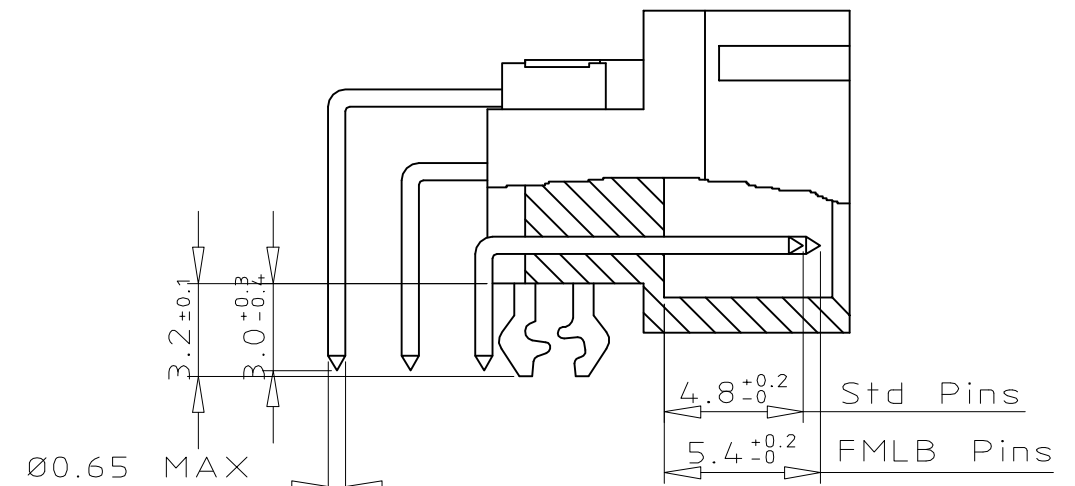


# DIMENSIONS


# TERMINATION

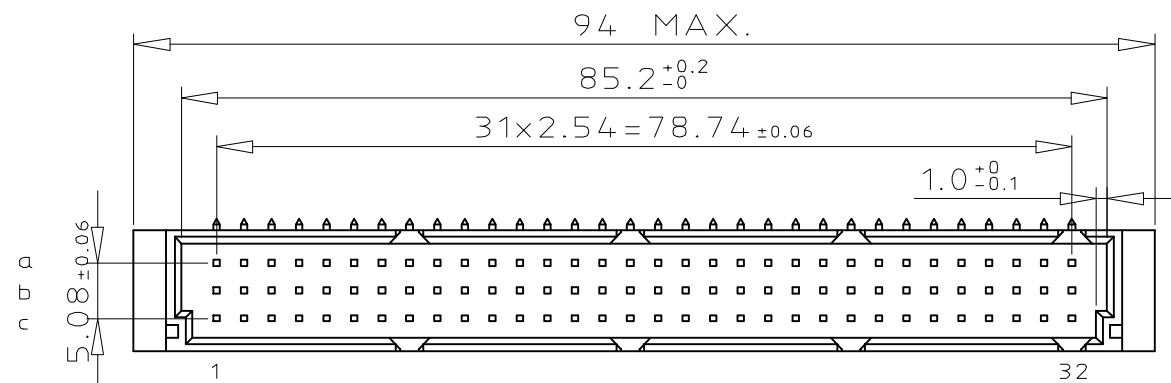

# ORDERING INFORMATION

SERIES	8609	3	96	7	1	13	7	5	5	NQLF		
ROWS FITTED WITH CONTACTS												
ROW a	b	c									3	96
NO. OF CONTACTS												
TYPE OF INSULATOR												
3 ROW MALE INSULATOR . . . . . 7												
METHOD OF MOUNTING												
STANDARD MOUNTING - STYLE C . . . . . 1												
TERMINATION												
ANGLED SPILL . . . . . 13												
OPTIONS												
NO OPTION . . . . . 7												
WITH HARPOONS . . . . . H												
PERFORMANCE CLASS												
DIN 41612 CLASS 3 . . . . . 4												
DIN 41612 CLASS 2 . . . . . 5												
DIN 41612 CLASS 1 . . . . . 6												
AS PER MIL C 55302 / JSS 50808 . . . . . 8												
PITCH PER ROW												
2.54mm PITCH . . . . . 5												
LEAD FREE VERSION SPL CONTACTS LOADING . . . . . NQLF												

# PCB LAYOUT

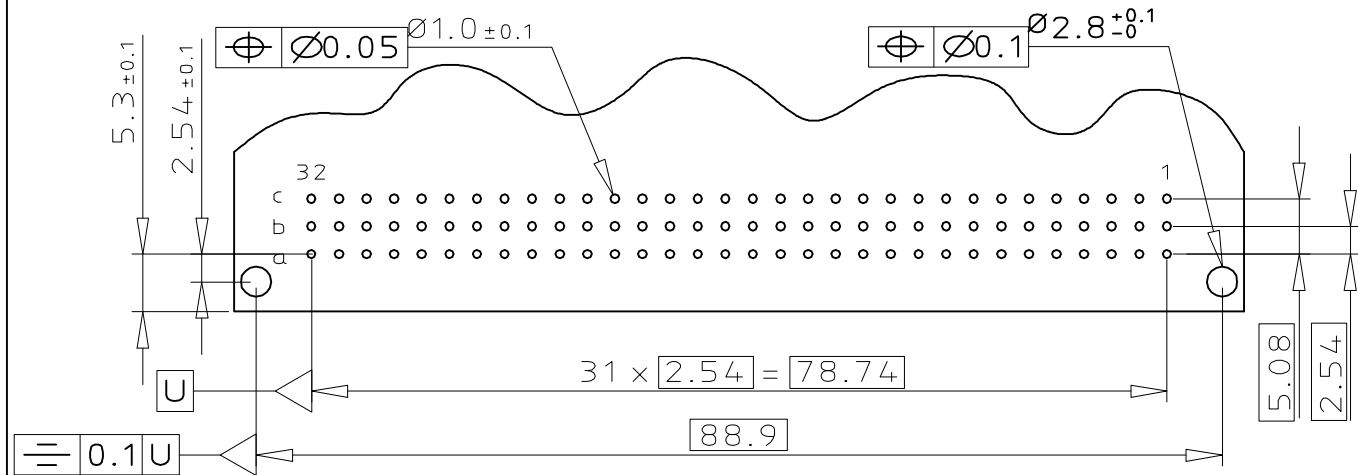

# CONTACT ARRANGEMENT

	1	2	3	4	5	6	7	8	9	10	11	12	13	14	15	16	17	18	19	20	21	22	23	24	25	26	27	28	29	30	31	32		
a	✓	×	×	×	×	×	×	×	×	×	×	×	×	×	×	×	×	×	×	×	×	×	×	×	×	×	×	×	×	×	×	×	×	✓
b	×	×	×	×	×	×	×	×	×	×	×	×	×	×	×	×	×	×	×	×	×	×	×	×	×	×	×	×	×	×	×	×	×	×
c	×	×	×	×	×	×	×	×	×	×	×	×	×	×	×	×	×	×	×	×	×	×	×	×	×	×	×	×	×	×	×	×	×	×

STANDARD CONTACT  
  EMPTY CAVITY  
  FMLB CONTACT  
  LMEB CONTACT

GENERAL CHARACTERISTICS & RoHS INFO  
REFER DRAWING C-8609-0000A

mat'l. code	surface	tolerance	projection	product family
SEE DRAWING C-8609-0000A	ISO 1302 ✓	ISO 406 ISO 1101		8609
ltr	ecn no	dr	date	title
A	109-0265	KR	2009-11-19	DIN STANDARD HEADER ANGLED SPILL DIN 41612 STYLE C
angles				mm
linear				scale 3:2
0°±2°				
dr	MINI K V	2006-06-01	dwg no                      sheet 1 of 1 size C-8609-2084              A3 type Product Customer Drawing	
enr	RAKHEE G	2006-06-01		
chr	KESAVAN R	2009-11-19		
appd	KESAVAN R	2009-11-19		
sheet index	revision sheet	A	1	



Copyright FCI

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[FCI / Amphenol:](#)

[86093967113755NQLF](#)