


REFERENCE FOR REEL ACCORDING TO FEEDING DIRECTION

GAUGE		REEL OF 5000 FEMALE CONTACTS		REEL OF 10000 FEMALE CONTACTS		GAUGE		REEL OF 5000 PIN CONTACTS		REEL OF 10000 PIN CONTACTS	
# 24-28	-	-	-	86566540064	86566540064LF	# 24-28	-	-	-	86564540064	86564540064LF
# 20-24	-	-	-	-	-	# 20-24	-	-	-	-	-
# 24-28	86566510065	86566510065LF	86566540065	86566540065LF	86566540065LF	# 24-28	86564510065	86564510065LF	86564540065	86564540065LF	86564540065LF
# 20-24	86566520065	86566520065LF	86566530065	86566530065LF	86566530065LF	# 20-24	86564520065	86564520065LF	86564530065	86564530065LF	86564530065LF
# 24-28	86566510067	86566510067LF	86566540067	86566540067LF	86566540067LF	# 24-28	86564510067	86564510067LF	86564540067	86564540067LF	86564540067LF
# 20-24	86566520067	86566520067LF	86566530067	86566530067LF	86566530067LF	# 20-24	86564520067	86564520067LF	86564530067	86564530067LF	86564530067LF

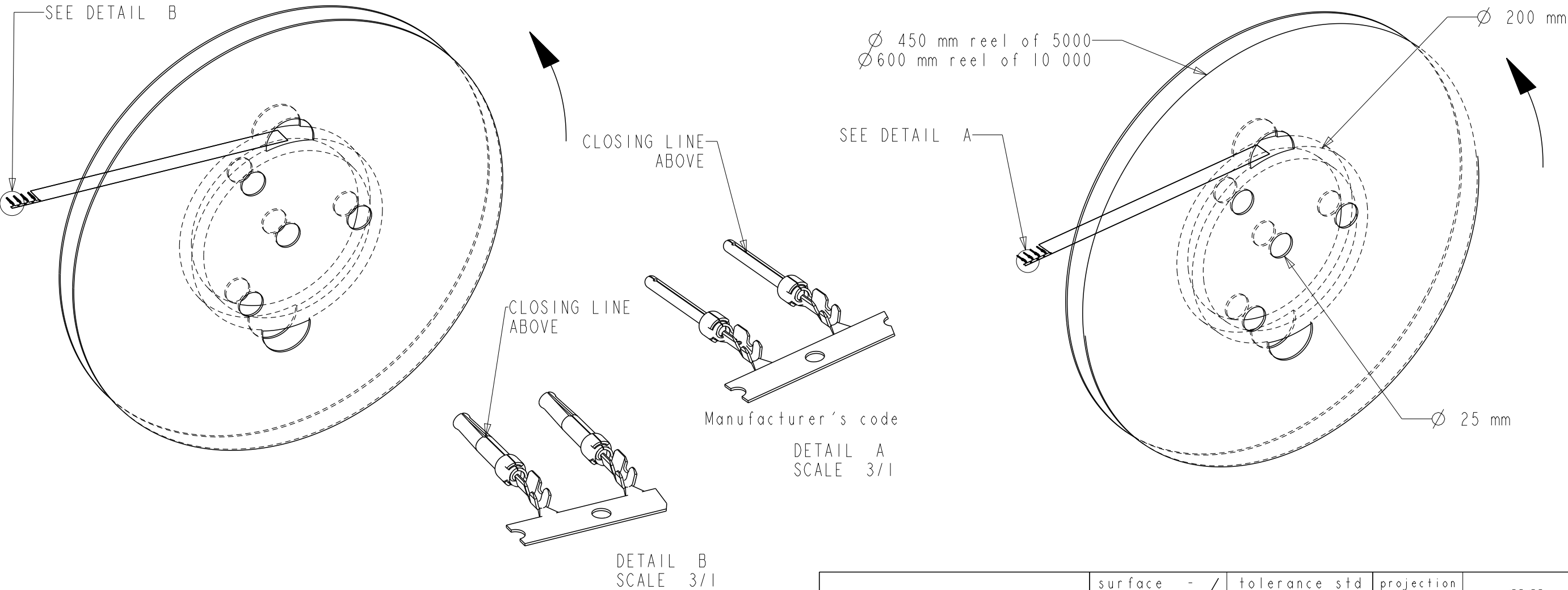

NOTE : ROHS INFORMATION
The LF products meet European union directives and other country regulations as described in GS-22-008
Terminations plating spec : 2um Nickel min + 2um Sn min
Packaging Spec : see GS-14-920

rev	ecn no	dr	date
K	111-0003	AMR	2011-01-06
-	-	-	-
E	LS06-196	MPE	27/11/2006
F	LS08-0096	MPE	2008/04/04
G	LS08-0127	MPE	2008/05/13
H	109-0152	AMR	2009-07-27
J	110-0070	AMR	2010-03-09

www.fciconnect.com			surface - ☒ ISO 1302	tolerance std ☒ ISO 406 ☒ ISO 1101	projection	mm
			TOLERANCES UNLESS OTHERWISE SPECIFIED			
Dr	CJARRY	11/07/03	ANGULAR	LINEAR	0.X ±0.3	size A3
Eng	-	-	0° ±2°		0.XX ±0.1	Scale 5/1
Chr	-	-			0.XXX ±0.05	ECN 111-0003
Appr	-	-	Product family		8656	Spec ref -
			CRIMP CONTACTS			Rev. K
			catalog no			customer
						sheet 1 of 2

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Amphenol:](#)

[86564510067LF](#) [86566510067LF](#) [86566520067LF](#)