
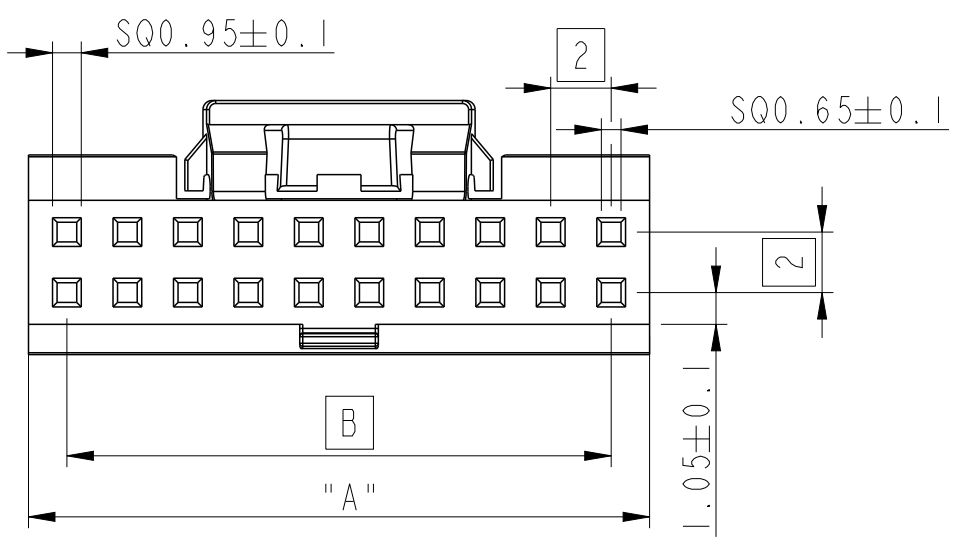
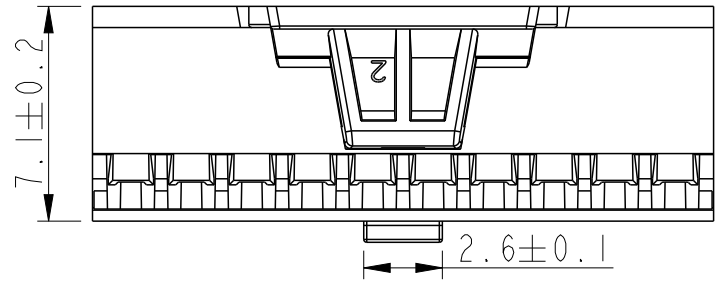


A

B

C

D

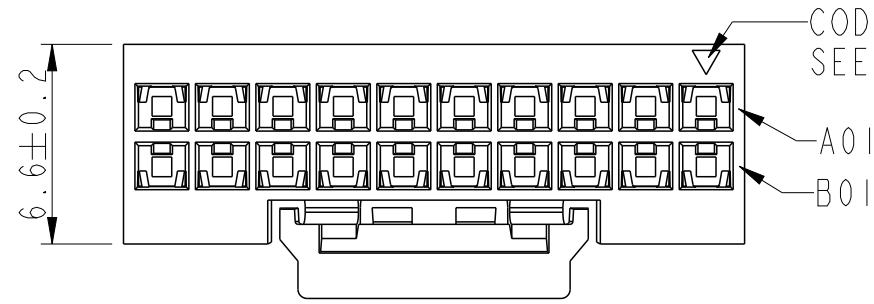



10118940-YXX-ZZZLF

NOTE 6 & 8


POLARIZATION CODE (OPTIONAL) SEE NOTE 9

TOTAL NB OF POSITIONS


0 : COLOR BLACK
1 : COLOR CREAM

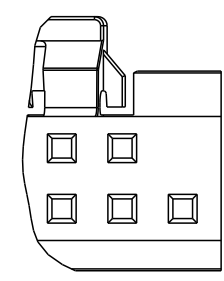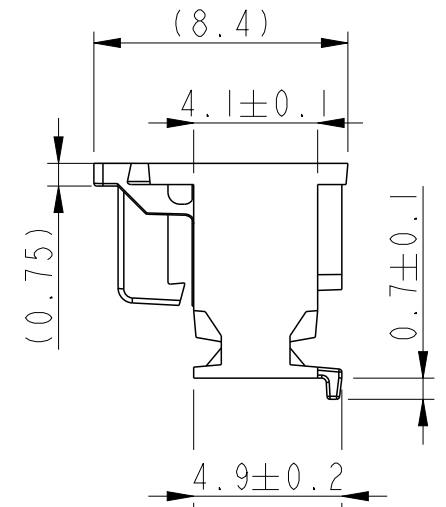

CAVITY FILLED EXAMPLE (...-BO1LF) SEE NOTE 7

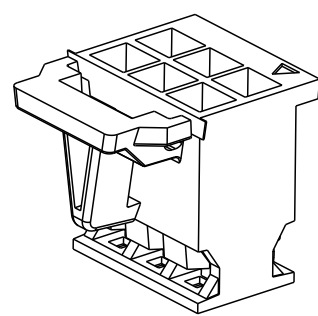


DESIGN FOR 10118940-006LF & 10118940-008LF ONLY

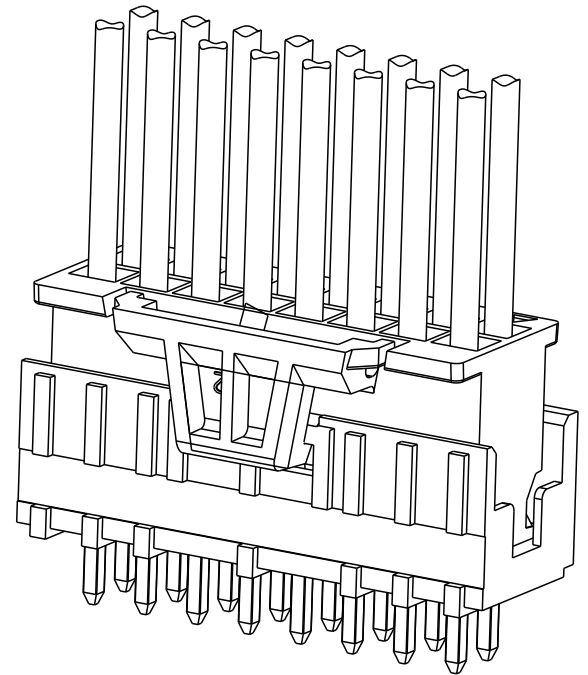

APPLICATION SEE NOTE 2 & 3

- NOTES :
- 1 - MATERIAL : PA6.6 25% GLASSFILLED, UL-94V-0 MEETS GWT 900°C-960°C.
 - 2 - FOR USE WITH MINITEK CTW CONTACTS: AWG 26-30, SERIE 77138 AWG 22-24 SERIE 10044403
 - 3 - TO BE MATED WITH MINITEK HEADERS SERIES 98414 / 98416 / 98417 / 98424 AND 10075025.
 - 4 - PRODUCT SPECIFICATIONS : GS-12-415
 - 5 - PACKAGING BULK.
 - 6 - RoHS COMPLIANT, THE PRODUCT IS NOT INTENDED TO BE EXPOSED TO ANY SOLDER PROCESS.
 - 7 - THE TRIANGLE INDICATES THE FIRST POSITION
 - 8 - PRODUCT MEETS EUROPEAN UNION DIRECTIVES AND OTHERS COUNTRY REGULATIONS AS PER GS-022-008.
 - 9 - FOR POLARIZATION, NUMBER THE CAVITY NUMBER TO BE SPECIFIED. EXAMPLE: -B01 = CAVITY 01 UNFILLED. OMIT FROM PART NUMBER IS FEATURE NOT APPLICABLE.

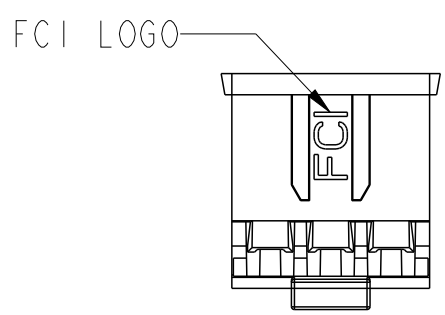

spec ref		-		dr		Benoit Vernier		2015/10/23		projection		mm		size		A3		scale		4:1							
tolerance std		TOLERANCES UNLESS OTHERWISE SPECIFIED		eng		Marty Glass		2015/10/29						ecn no		-											
ISO 406				chr		-		-						product family		rel level		Released									
ISO 1101				appr		-		-								rev		E									
surface				linear		0.X		±0.3				title		MINITEK CTW HOUSING		dwg no		10118940		rev		E					
ISO 1302																								0.XX		±0.10	
ISO 1302																								0.XXX		±0.05	
angular		0°		±2°		www.fci.com		cat. no.		Product - Customer Drw		sheet 1 of 1															

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

FCI / Amphenol:

<u>10118940-124LF</u>	<u>10118940-014LF</u>	<u>10118940-008LF</u>	<u>10118940-016LF</u>	<u>10118940-114LF</u>	<u>10118940-122LF</u>
<u>10118940-108LF</u>	<u>10118940-020LF</u>	<u>10118940-112LF</u>	<u>10118940-018LF</u>	<u>10118940-134LF</u>	<u>10118940-012LF</u>
<u>10118940-024LF</u>	<u>10118940-120LF</u>	<u>10118940-110LF</u>	<u>10118940-130LF</u>	<u>10118940-030LF</u>	<u>10118940-022LF</u>
<u>10118940-116LF</u>	<u>10118940-034LF</u>	<u>10118940-106LF</u>	<u>10118940-010LF</u>	<u>10118940-026LF</u>	