


PRODUCT DATA DRAWING

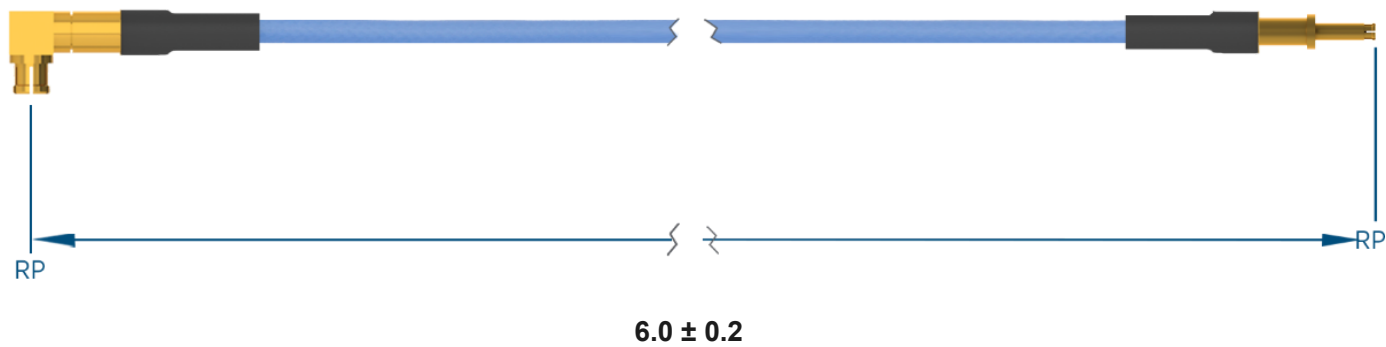

MATERIAL

CONNECTORS: SMPM R/A Female (3222-40020)
SMPS Size 16 Pin (9921-40001)

CABLE: Ø.047 Flexible Coax

SHRINK TUBING: M23053/5

PERFORMANCE

IMPEDANCE: 50 Ohms

FREQ. RANGE: DC to 40 GHz

VSWR: 1.4:1 Max, DC to 18.0 GHz
1.6:1 Max, 18.0 + GHz

INSERTION LOSS: 1.89 dB Max

NOTES

- 1. See individual data drawings for connector specifications
- 2. Dimensions shown are in inches



TITLE:

SMPM R/A Female to SMPS Size 16 Pin 6" Cable
Assembly for Ø.047 Flexible Coax

DWG. NO.

FRSMPM-047-P16DSMPS-060

DRAWN

2022-10-18 15:29:54

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Amphenol:](#)

[FRSMPM-047-P16DSMPS-060](#)