


PRODUCT DATA DRAWING

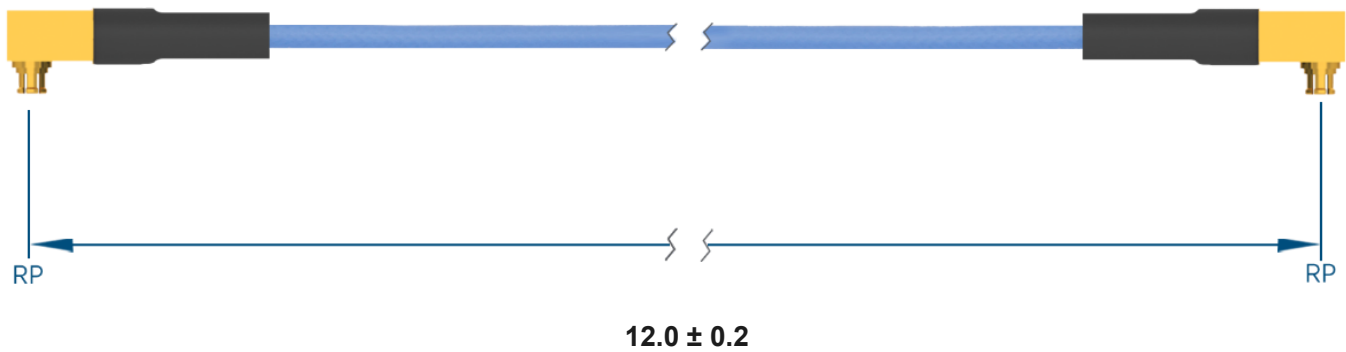

MATERIAL

- CONNECTORS: SMPS R/A Female (3822-40001)  
SMPS R/A Female (3822-40001)
- CABLE: Ø.047 Flexible Coax
- SHRINK TUBING: M23053/5

PERFORMANCE

- IMPEDANCE: 50 Ohms
- FREQ. RANGE: DC to 40 GHz
- VSWR: 1.3:1 Max, DC to 18.0 GHz  
1.5:1 Max, 18.0 + GHz
- INSERTION LOSS: 3.27 dB Max

NOTES

1. See individual data drawings for connector specifications
2. Dimensions shown are in inches



TITLE:  
SMPS R/A Female to SMPS R/A Female 12" Cable  
Assembly for Ø.047 Flexible Coax

DWG. NO.  
FRSMPS-047-FRSMPS-120

DRAWN  
2022-10-19 15:27:53

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Amphenol:](#)

[FRSMPS-047-FRSMPS-120](#)