


PRODUCT DATA DRAWING

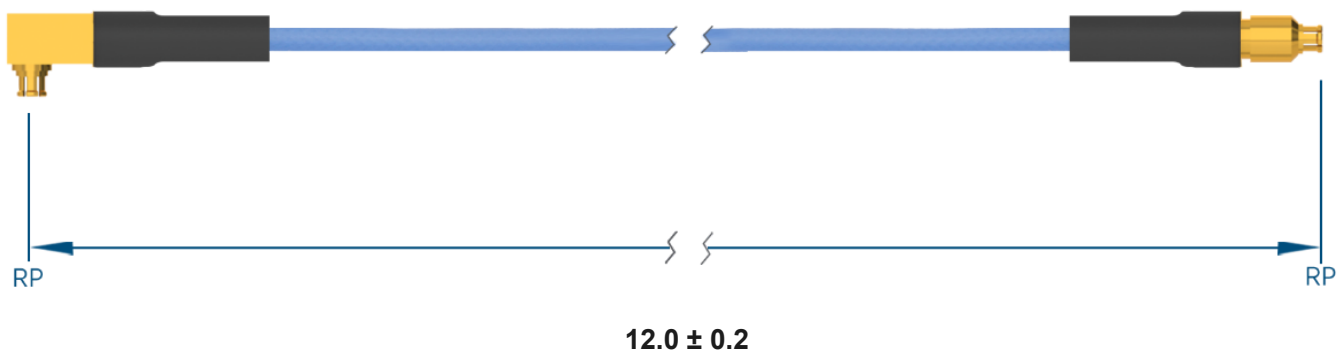

MATERIAL

CONNECTORS: SMPS R/A Female (3822-40001)  
SMPS Straight Female (3821-40029)

CABLE: Ø.047 Flexible Coax

SHRINK TUBING: M23053/5

PERFORMANCE

IMPEDANCE: 50 Ohms

FREQ. RANGE: DC to 40 GHz

VSWR: 1.3:1 Max, DC to 18.0 GHz  
1.5:1 Max, 18.0 + GHz

INSERTION LOSS: 3.27 dB Max

NOTES

1. See individual data drawings for connector specifications
2. Dimensions shown are in inches



TITLE:  
SMPS R/A Female to SMPS Straight Female 12" Cable  
Assembly for Ø.047 Flexible Coax

DWG. NO.  
FRSMPS-047-FSSMPS-120

DRAWN  
2022-10-19 15:47:22

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Amphenol:](#)

[FRSMPS-047-FSSMPS-120](#)