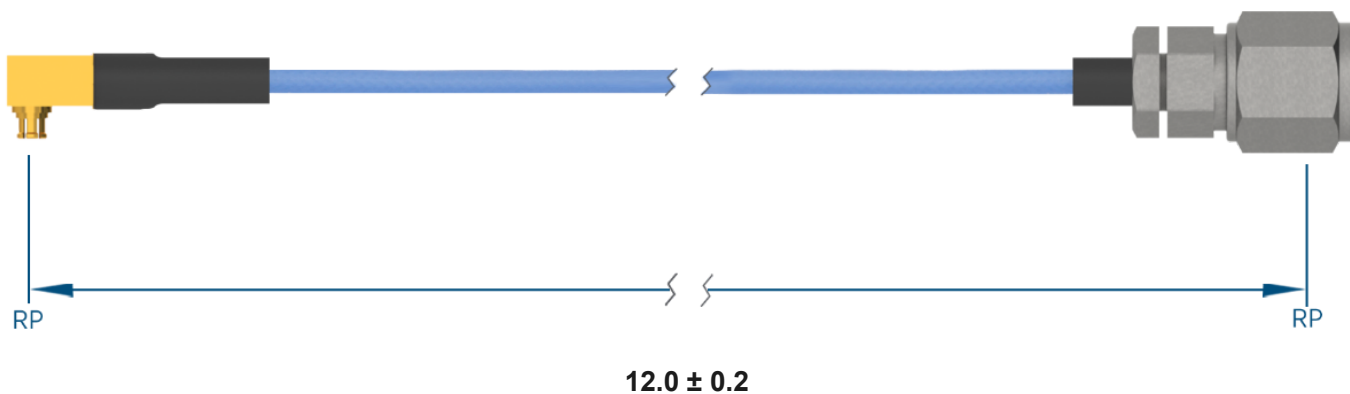


PRODUCT DATA DRAWING

**MATERIAL**

CONNECTORS: SMPS R/A Female (3822-40001)
1.85mm Straight Male (SF3311-60002)

CABLE: Ø.047 Flexible Coax

SHRINK TUBING: M23053/5

PERFORMANCE

IMPEDANCE: 50 Ohms

FREQ. RANGE: DC to 40 GHz

VSWR: 1.3:1 Max, DC to 18.0 GHz
1.5:1 Max, 18.0 + GHz

INSERTION LOSS: 3.27 dB Max

NOTES

1. See individual data drawings for connector specifications
2. Dimensions shown are in inches

**TITLE:**

SMPS R/A Female to 1.85mm Straight Male 12" Cable
Assembly for Ø.047 Flexible Coax

DWG. NO.

FRSMPS-047-MS185-120

DRAWN

2022-10-19 15:54:07

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Amphenol:](#)

[FRSMPS-047-MS185-120](#)