


PRODUCT DATA DRAWING

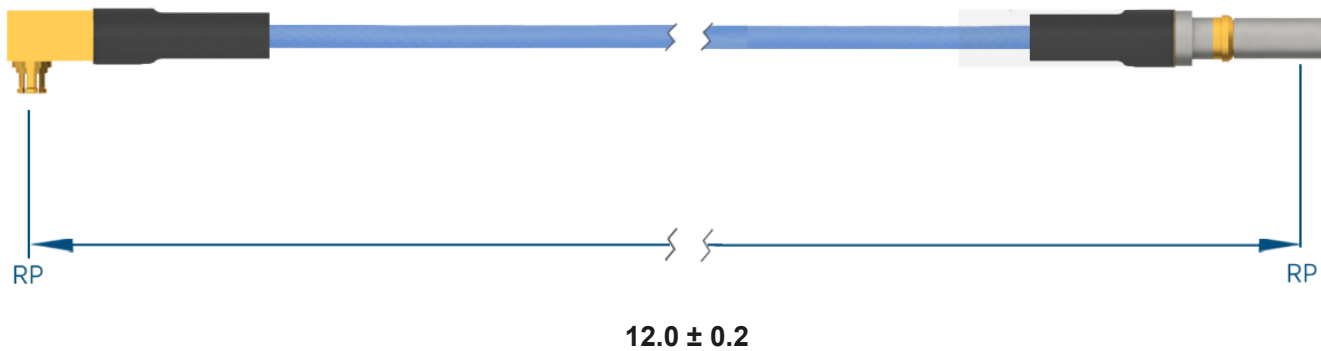

MATERIAL

CONNECTORS: SMPS R/A Female (3822-40001)
VITA 67.3 SMPS Male Plug-In Contact (SF3811-60060)

CABLE: Ø.047 Flexible Coax

SHRINK TUBING: M23053/5

PERFORMANCE

IMPEDANCE: 50 Ohms

FREQ. RANGE: DC to 40 GHz

VSWR: 1.3:1 Max, DC to 18.0 GHz
1.5:1 Max, 18.0 + GHz

INSERTION LOSS: 3.27 dB Max

NOTES

1. See individual data drawings for connector specifications
2. Dimensions shown are in inches



TITLE:

SMPS R/A Female to VITA 67.3 SMPS Male Plug-In
Contact 12" Cable Assembly for Ø.047 Flexible Coax

DWG. NO.

FRSMPS-047-MV67.3SMPS-120

DRAWN

2022-10-19 16:02:51

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Amphenol:](#)

[FRSMPS-047-MV67.3SMPS-120](#)