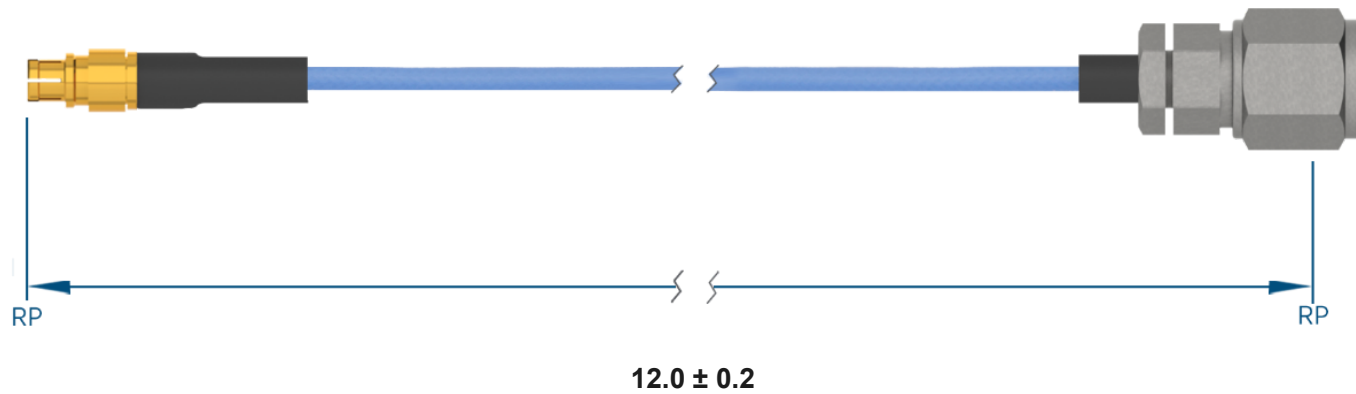


PRODUCT DATA DRAWING

**MATERIAL**

CONNECTORS: SMPM Straight Female (3221-40007)
1.85mm Straight Male (SF3311-60002)

CABLE: Ø.047 Flexible Coax

SHRINK TUBING: M23053/5

PERFORMANCE

IMPEDANCE: 50 Ohms

FREQ. RANGE: DC to 65 GHz

VSWR: 1.3:1 Max, DC to 18.0 GHz
1.5:1 Max, 18.0 + GHz

INSERTION LOSS: 4.60 dB Max

NOTES

1. See individual data drawings for connector specifications
2. Dimensions shown are in inches

**TITLE:**

SMPM Straight Female to 1.85mm Straight Male 12"
Cable Assembly for Ø.047 Flexible Coax

DWG. NO.

FSSMPM-047-MS185-120

DRAWN

2022-10-26 12:28:42

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Amphenol:](#)

[FSSMPM-047-MS185-120](#)