


PRODUCT DATA DRAWING

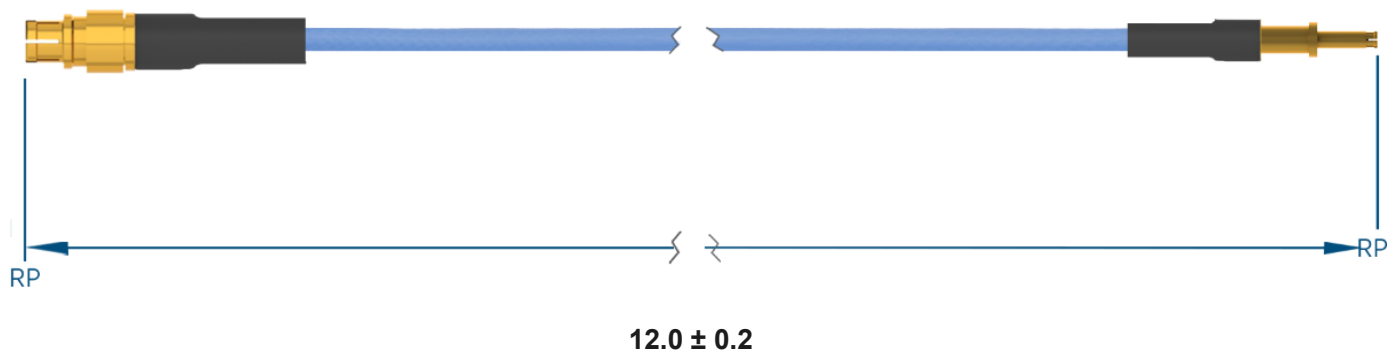

MATERIAL

CONNECTORS: SMPM Straight Female (3221-40007)
 SMPS Size 16 Pin (9921-40001)

CABLE: Ø.047 Flexible Coax

SHRINK TUBING: M23053/5

PERFORMANCE

IMPEDANCE: 50 Ohms

FREQ. RANGE: DC to 65 GHz

VSWR: 1.3:1 Max, DC to 18.0 GHz
 1.5:1 Max, 18.0 + GHz

INSERTION LOSS: 4.60 dB Max

NOTES

1. See individual data drawings for connector specifications
2. Dimensions shown are in inches



TITLE:
 SMPM Straight Female to SMPS Size 16 Pin 12" Cable
 Assembly for Ø.047 Flexible Coax

DWG. NO.
 FSSMPM-047-P16DSMPS-120

DRAWN
 2022-10-26 12:39:06

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Amphenol:](#)

[FSSMPM-047-P16DSMPS-120](#)