


PRODUCT DATA DRAWING

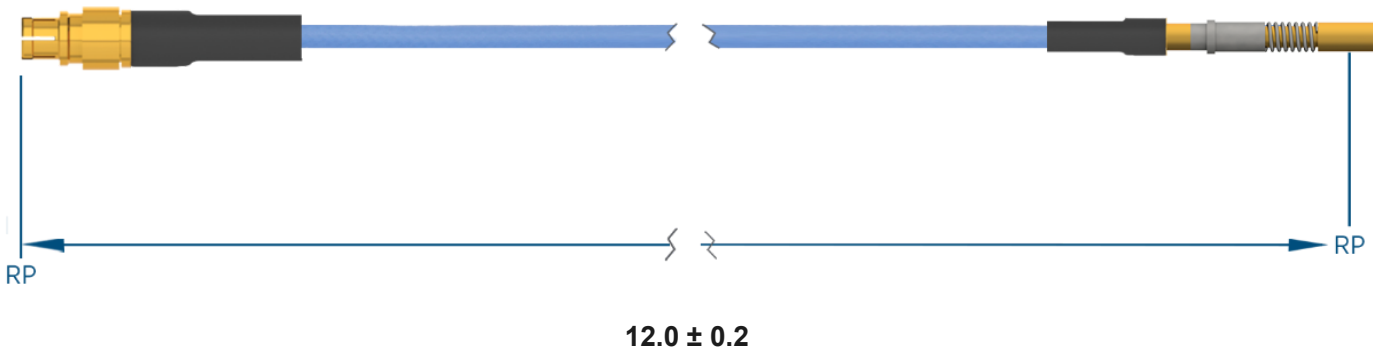

MATERIAL

- CONNECTORS: SMPM Straight Female (3221-40007)  
SMPS Size 16 Socket (SF9911-60001)
- CABLE: Ø.047 Flexible Coax
- SHRINK TUBING: M23053/5

PERFORMANCE

- IMPEDANCE: 50 Ohms
- FREQ. RANGE: DC to 65 GHz
- VSWR: 1.3:1 Max, DC to 18.0 GHz  
1.5:1 Max, 18.0 + GHz
- INSERTION LOSS: 4.60 dB Max

NOTES

- 1. See individual data drawings for connector specifications
- 2. Dimensions shown are in inches



TITLE:  
SMPM Straight Female to SMPS Size 16 Socket 12"  
Cable Assembly for Ø.047 Flexible Coax

DWG. NO.  
FSSMPM-047-S16DSMPS-120

DRAWN  
2022-10-26 12:46:15

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Amphenol:](#)

[FSSMPM-047-S16DSMPS-120](#)