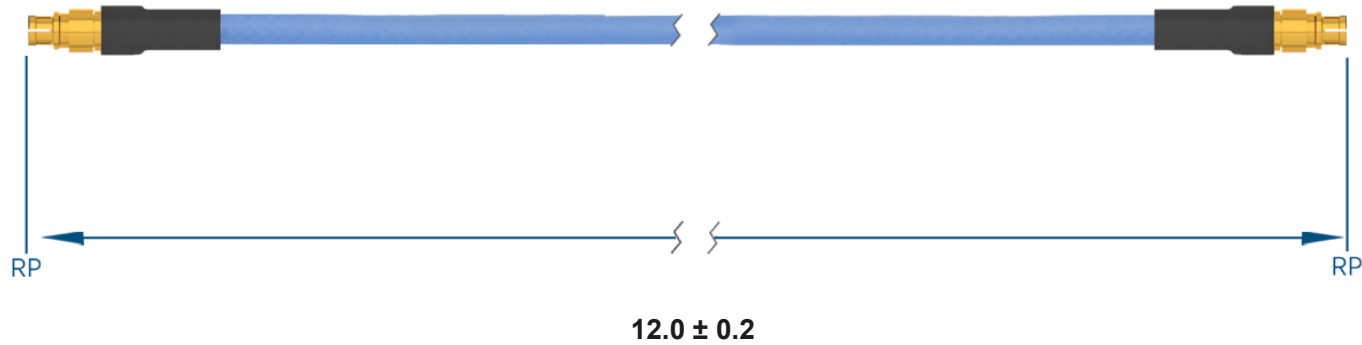


## PRODUCT DATA DRAWING

**MATERIAL**

CONNECTORS: SMPM Straight Female (3221-40006)  
SMPM Straight Female (3221-40006)

CABLE: Ø.085 Flexible Coax

SHRINK TUBING: M23053/5

**PERFORMANCE**

IMPEDANCE: 50 Ohms

FREQ. RANGE: DC to 40 GHz

VSWR: 1.3:1 Max, DC to 18.0 GHz  
1.5:1 Max, 18.0 + GHz

INSERTION LOSS: 2.19 dB Max

**NOTES**

1. See individual data drawings for connector specifications
2. Dimensions shown are in inches

**TITLE:**

SMPM Straight Female to SMPM Straight Female 12"  
Cable Assembly for Ø.085 Flexible Coax

**DWG. NO.**

FSSMPM-085-FSSMPM-120

**DRAWN**

2022-10-26 13:02:57

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Amphenol:](#)

[FSSMPM-085-FSSMPM-120](#)