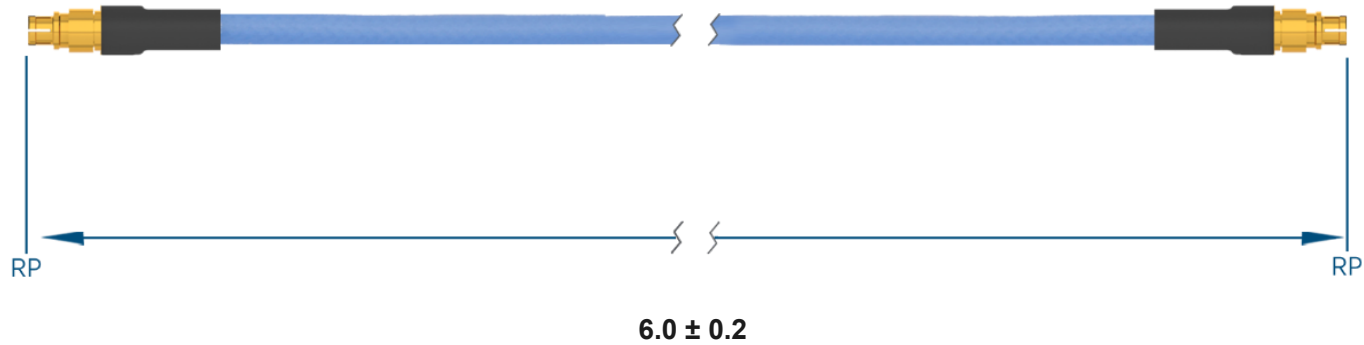


PRODUCT DATA DRAWING

**MATERIAL**

CONNECTORS: SMPM Straight Female (3221-40006)
SMPM Straight Female (3221-40006)

CABLE: Ø.085 Flexible Coax

SHRINK TUBING: M23053/5

PERFORMANCE

IMPEDANCE: 50 Ohms

FREQ. RANGE: DC to 40 GHz

VSWR: 1.4:1 Max, DC to 18.0 GHz
1.6:1 Max, 18.0 + GHz

INSERTION LOSS: 1.35 dB Max

NOTES

1. See individual data drawings for connector specifications
2. Dimensions shown are in inches

**TITLE:**

SMPM Straight Female to SMPM Straight Female 6"
Cable Assembly for Ø.085 Flexible Coax

DWG. NO.

FSSMPM-085-FSSMPM-060

DRAWN

2022-10-26 13:00:31

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Amphenol:](#)

[FSSMPM-085-FSSMP-060](#)