


PRODUCT DATA DRAWING

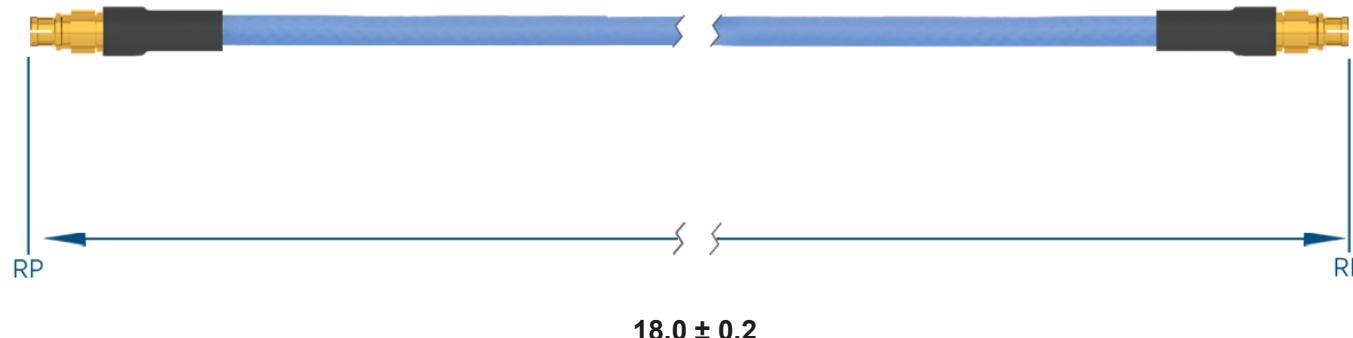

MATERIAL

CONNECTORS: SMPM Straight Female (3221-40006)
SMPM Straight Female (3221-40006)
CABLE: Ø.085 Flexible Coax
SHRINK TUBING: M23053/5

PERFORMANCE

IMPEDANCE: 50 Ohms
FREQ. RANGE: DC to 40 GHz
VSWR: 1.3:1 Max, DC to 18.0 GHz
1.5:1 Max, 18.0 + GHz
INSERTION LOSS: 3.03 dB Max

NOTES

1. See individual data drawings for connector specifications
2. Dimensions shown are in inches



TITLE:
SMPM Straight Female to SMPM Straight Female 18"
Cable Assembly for Ø.085 Flexible Coax

DWG. NO.
FSSMPM-085-FSSMPM-180

DRAWN
2022-10-26 13:01:37

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Amphenol:](#)

[FSSMPM-085-FSSMP-180](#)