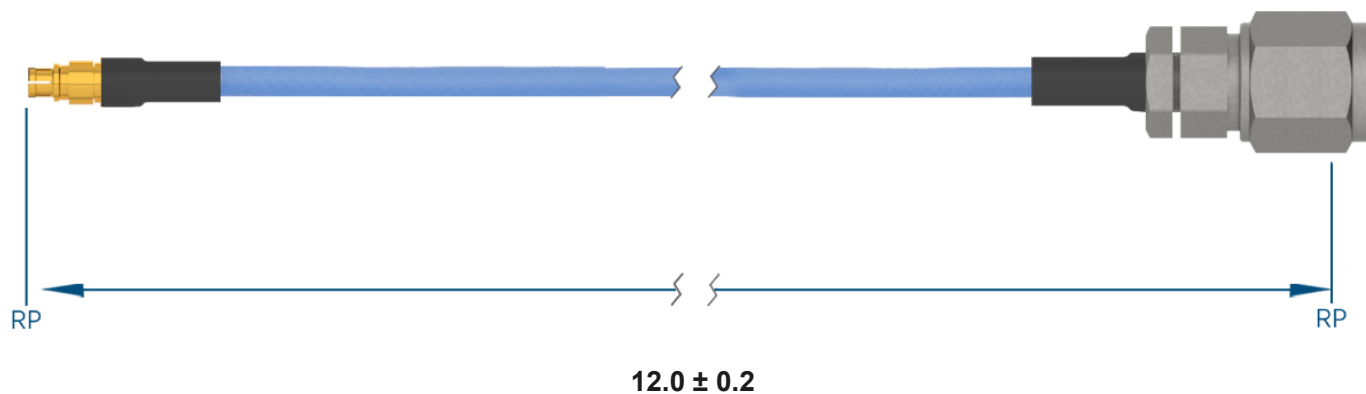


PRODUCT DATA DRAWING

**MATERIAL**

CONNECTORS: SMPM Straight Female (3221-40006)
2.4mm Straight Male (SF1611-60003)

CABLE: Ø.085 Flexible Coax

SHRINK TUBING: M23053/5

PERFORMANCE

IMPEDANCE: 50 Ohms

FREQ. RANGE: DC to 40 GHz

VSWR: 1.3:1 Max, DC to 18.0 GHz
1.5:1 Max, 18.0 + GHz

INSERTION LOSS: 2.19 dB Max

NOTES

1. See individual data drawings for connector specifications
2. Dimensions shown are in inches

**TITLE:**

SMPM Straight Female to 2.4mm Straight Male 12"
Cable Assembly for Ø.085 Flexible Coax

DWG. NO.

FSSMPM-085-MS24-120

DRAWN

2022-10-21 12:06:47

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Amphenol:](#)

[FSSMPM-085-MS24-120](#)