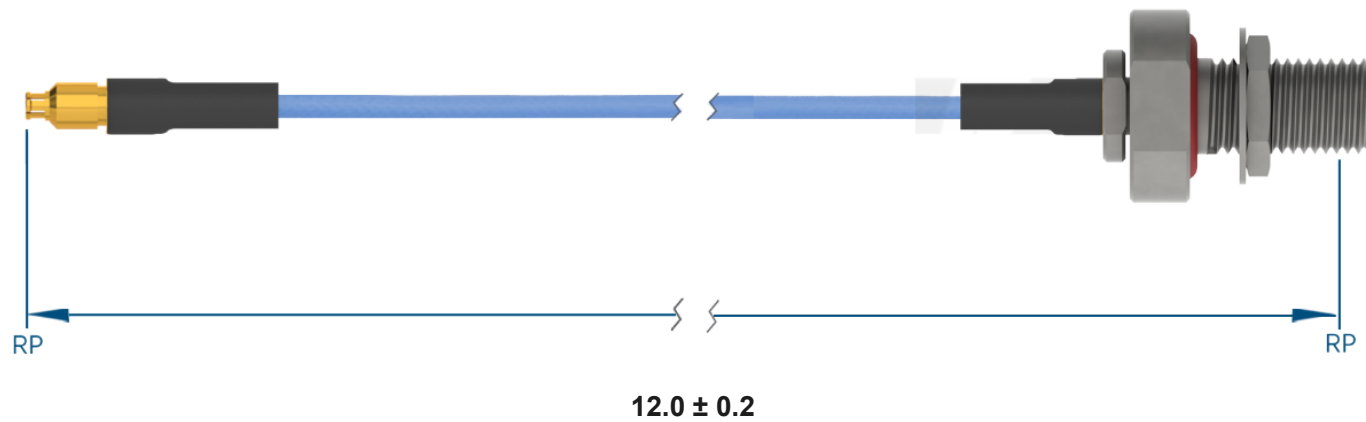


PRODUCT DATA DRAWING

**MATERIAL**

CONNECTORS: SMPS Straight Female (3821-40029)
SMA Bulkhead Female (2944-6001)

CABLE: Ø.047 Flexible Coax

SHRINK TUBING: M23053/5

PERFORMANCE

IMPEDANCE: 50 Ohms

FREQ. RANGE: DC to 18 GHz

VSWR: 1.3:1 Max, DC to 18.0 GHz
1.5:1 Max, 18.0 + GHz

INSERTION LOSS: 2.26 dB Max

NOTES

1. See individual data drawings for connector specifications
2. Dimensions shown are in inches

**TITLE:**

SMPS Straight Female to SMA Bulkhead Female 12"
Cable Assembly for Ø.047 Flexible Coax

DWG. NO.

FSSMPS-047-FBSMA-120

DRAWN

2022-10-21 11:56:50

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Amphenol:](#)

[FSSMPS-047-FBSMA-120](#)