


PRODUCT DATA DRAWING

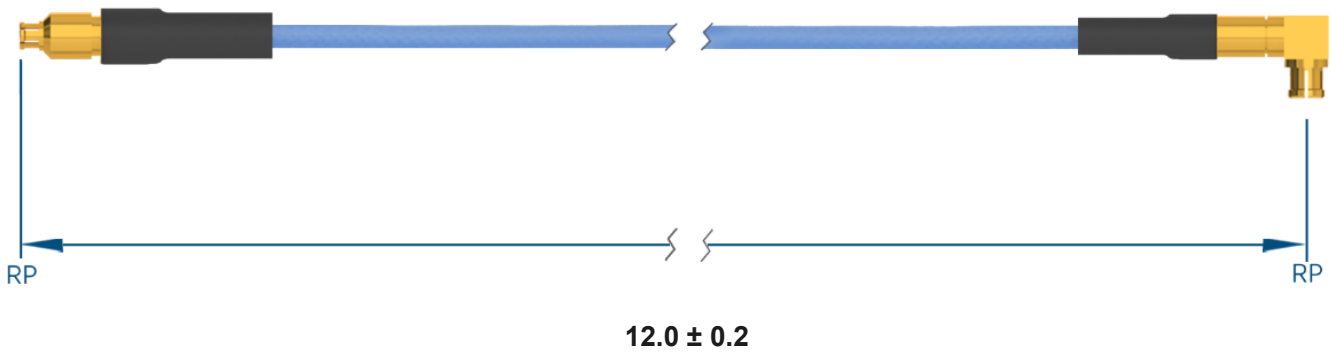

MATERIAL

- CONNECTORS: SMPS Straight Female (3821-40029)  
SMPM R/A Female (3222-40020)
- CABLE: Ø.047 Flexible Coax
- SHRINK TUBING: M23053/5

PERFORMANCE

- IMPEDANCE: 50 Ohms
- FREQ. RANGE: DC to 40 GHz
- VSWR: 1.3:1 Max, DC to 18.0 GHz  
1.5:1 Max, 18.0 + GHz
- INSERTION LOSS: 3.27 dB Max

NOTES

1. See individual data drawings for connector specifications
2. Dimensions shown are in inches



TITLE:

SMPS Straight Female to SMPM R/A Female 12"  
Cable Assembly for Ø.047 Flexible Coax

DWG. NO.

FSSMPS-047-FRSMPPM-120

DRAWN

2022-10-21 11:54:35

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Amphenol:](#)

[FSSMPS-047-FRSMMPM-120](#)