


PRODUCT DATA DRAWING

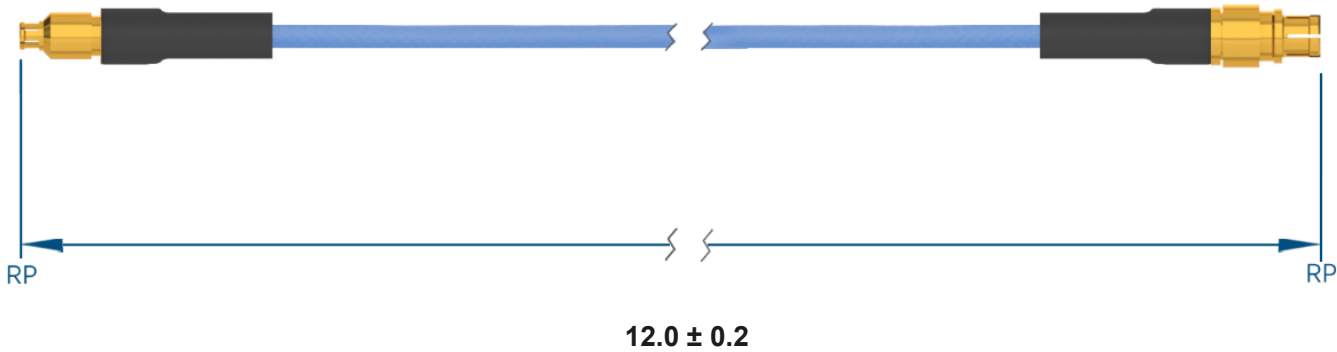

MATERIAL

CONNECTORS: SMPS Straight Female (3821-40029)
SMPM Straight Female (3221-40007)

CABLE: Ø.047 Flexible Coax

SHRINK TUBING: M23053/5

PERFORMANCE

IMPEDANCE: 50 Ohms

FREQ. RANGE: DC to 50 GHz

VSWR: 1.3:1 Max, DC to 18.0 GHz
1.5:1 Max, 18.0 + GHz

INSERTION LOSS: 3.69 dB Max

NOTES

1. See individual data drawings for connector specifications
2. Dimensions shown are in inches



TITLE:

SMPS Straight Female to SMPM Straight Female 12"
Cable Assembly for Ø.047 Flexible Coax

DWG. NO.

FSSMPS-047-FSSMPM-120

DRAWN

2022-10-21 11:52:50

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Amphenol:](#)

[FSSMPS-047-FSSMPM-120](#)