


PRODUCT DATA DRAWING

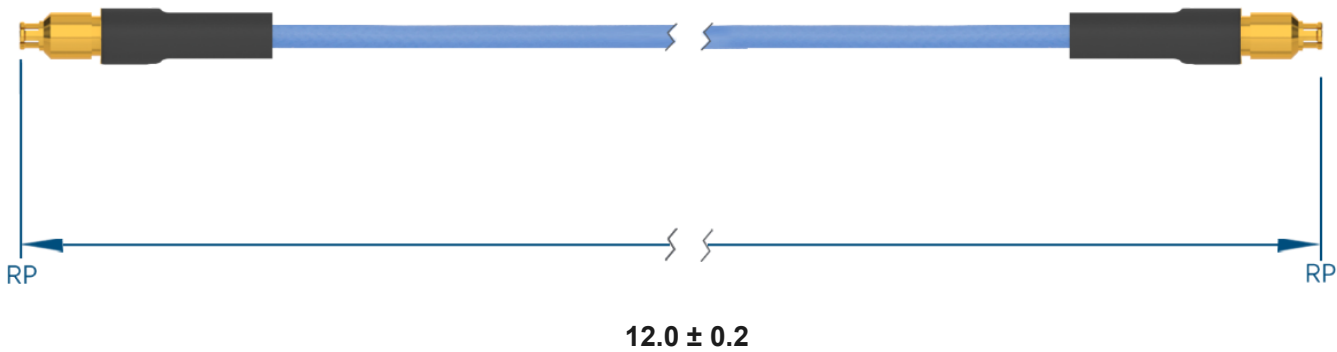

MATERIAL

- CONNECTORS: SMPS Straight Female (3821-40029)
SMPS Straight Female (3821-40029)
- CABLE: Ø.047 Flexible Coax
- SHRINK TUBING: M23053/5

PERFORMANCE

- IMPEDANCE: 50 Ohms
- FREQ. RANGE: DC to 50 GHz
- VSWR: 1.3:1 Max, DC to 18.0 GHz
1.5:1 Max, 18.0 + GHz
- INSERTION LOSS: 3.69 dB Max

NOTES

1. See individual data drawings for connector specifications
2. Dimensions shown are in inches



TITLE:
SMPS Straight Female to SMPS Straight Female 12"
Cable Assembly for Ø.047 Flexible Coax

DWG. NO.
FSSMPS-047-FSSMPS-120

DRAWN
2022-10-21 11:52:03

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Amphenol:](#)

[FSSMPS-047-FSSMPS-120](#)