


PRODUCT DATA DRAWING

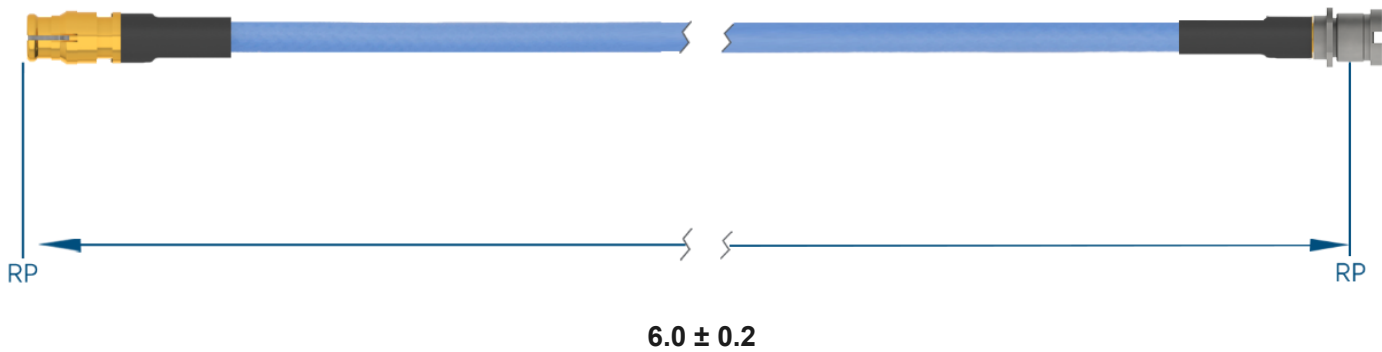

MATERIAL

- CONNECTORS: SMP Straight Female (1221-4009)
SMP Male Bulkhead (SF1211-6061)
- CABLE: Ø.085 Flexible Coax
- SHRINK TUBING: M23053/5

PERFORMANCE

- IMPEDANCE: 50 Ohms
- FREQ. RANGE: DC to 26.5 GHz
- VSWR: 1.4:1 Max, DC to 18.0 GHz
1.6:1 Max, 18.0 + GHz
- INSERTION LOSS: 1.01 dB Max

NOTES

1. See individual data drawings for connector specifications
2. Dimensions shown are in inches



TITLE:	SMP Straight Female to SMP Male Bulkhead 6" Cable Assembly for Ø.085 Flexible Coax
DWG. NO.	FSSMP-085-MBSMP-060
DRAWN	2022-10-26 11:46:22

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Amphenol:](#)

[FSSMP-085-MBSMP-060](#)