


PRODUCT DATA DRAWING

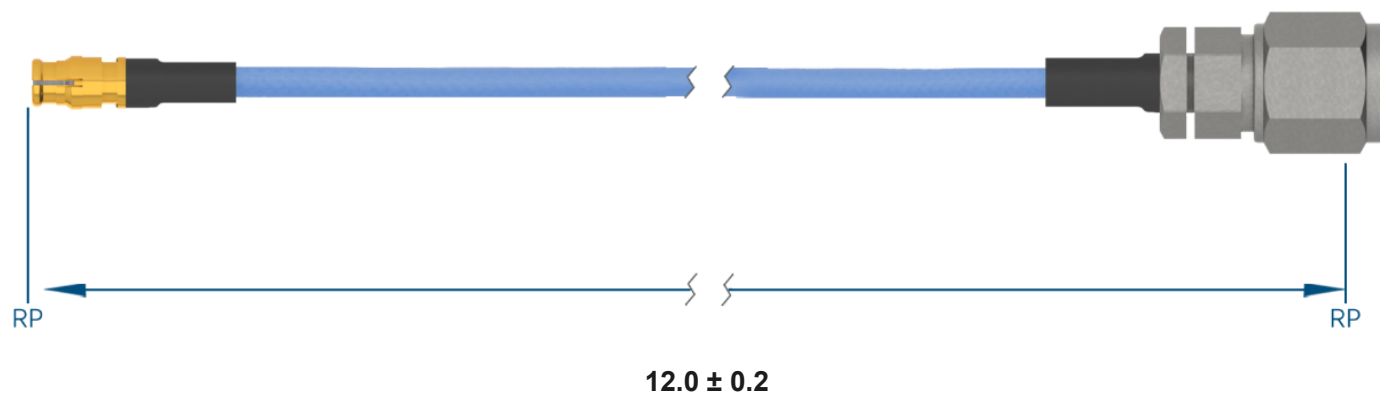

MATERIAL

CONNECTORS: SMP Straight Female (1221-4009)
1.85mm Straight Male (SF3311-60003)

CABLE: Ø.085 Flexible Coax

SHRINK TUBING: M23053/5

PERFORMANCE

IMPEDANCE: 50 Ohms

FREQ. RANGE: DC to 40 GHz

VSWR: 1.3:1 Max, DC to 18.0 GHz
1.5:1 Max, 18.0 + GHz

INSERTION LOSS: 2.19 dB Max

NOTES

1. See individual data drawings for connector specifications
2. Dimensions shown are in inches



TITLE:

SMP Straight Female to 1.85mm Straight Male 12"
Cable Assembly for Ø.085 Flexible Coax

DWG. NO.

FSSMP-085-MS185-120

DRAWN

2022-10-26 11:53:46

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Amphenol:](#)

[FSSMP-085-MS185-120](#)