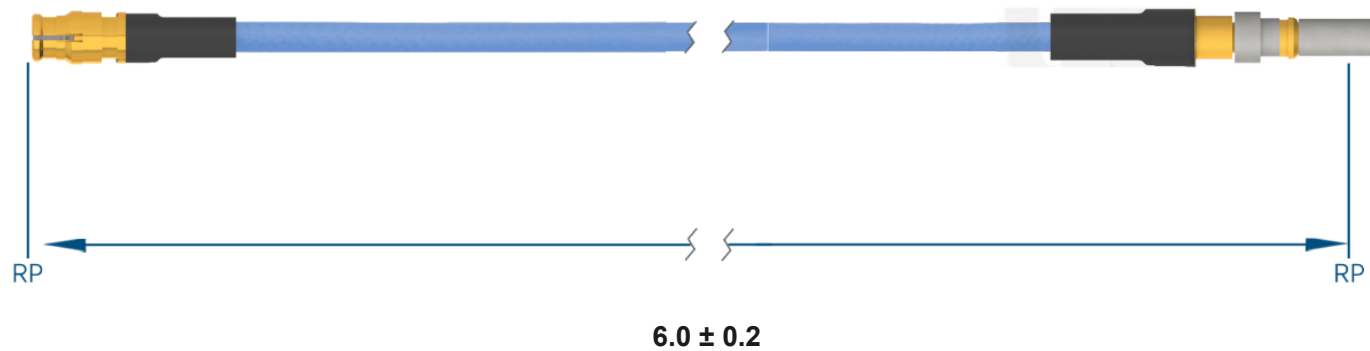


PRODUCT DATA DRAWING

**MATERIAL**

CONNECTORS: SMP Straight Female ([1221-4009](#))
VITA 67.3 SMPS Male Plug-In Contact ([SF3811-60059](#))

CABLE: Ø.085 Flexible Coax

SHRINK TUBING: M23053/5

PERFORMANCE

IMPEDANCE: 50 Ohms

FREQ. RANGE: DC to 40 GHz

VSWR: 1.4:1 Max, DC to 18.0 GHz
1.6:1 Max, 18.0 + GHz

INSERTION LOSS: 1.35 dB Max

NOTES

1. See individual data drawings for connector specifications
2. Dimensions shown are in inches

**TITLE:**

SMP Straight Female to VITA 67.3 SMPS Male Plug-In
Contact 6" Cable Assembly for Ø.085 Flexible Coax

DWG. NO.

FSSMP-085-MV67.3SMPS-060

DRAWN

2022-10-26 12:06:27

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Amphenol:](#)

[FSSMP-085-MV67.3SMPS-060](#)