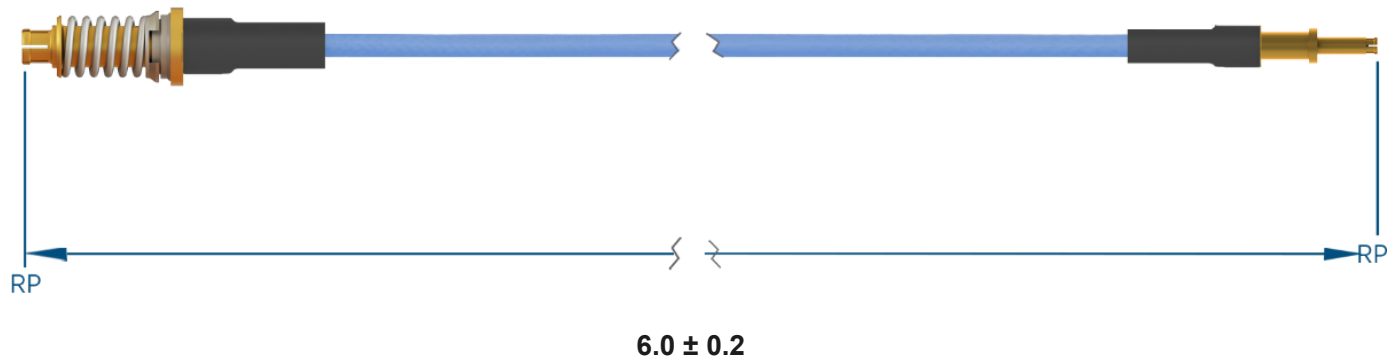


PRODUCT DATA DRAWING

**MATERIAL**

CONNECTORS: VITA 67.1/2 SMPM Plug-in Contact (3221-40019)
SMPS Size 16 Pin (9921-40001)

CABLE: Ø.047 Flexible Coax

SHRINK TUBING: M23053/5

PERFORMANCE

IMPEDANCE: 50 Ohms

FREQ. RANGE: DC to 40 GHz

VSWR: 1.4:1 Max, DC to 18.0 GHz
1.6:1 Max, 18.0 + GHz

INSERTION LOSS: 1.89 dB Max

NOTES

1. See individual data drawings for connector specifications
2. Dimensions shown are in inches

**TITLE:**

VITA 67.1/2 SMPM Plug-in Contact to SMPS Size 16
Pin 6" Cable Assembly for Ø.047 Flexible Coax

DWG. NO.

FV67SMPM-047-P16DSMPS-060

DRAWN

2022-10-18 16:02:12

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Amphenol:](#)

[FV67SMPPM-047-P16DSMPS-060](#)