


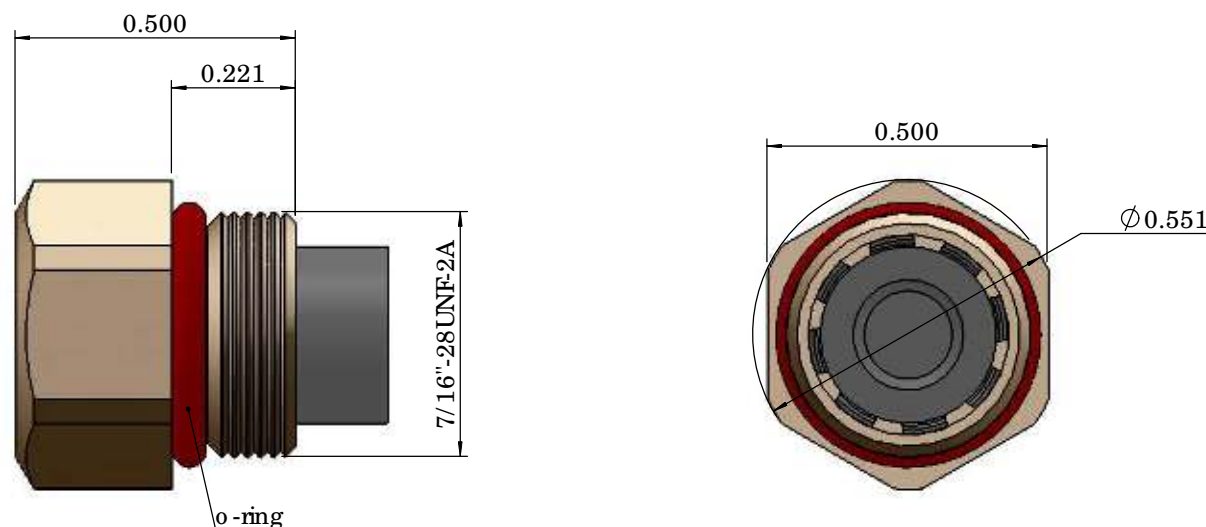

I、 Electric Performance

Gas tube 90V 、 230V 、 350V

II、 Material and plating :

Housing Brass / Spring copper Plating White Bronze2um / Ag5um
 O-ring Silicon rubber

III、 Mechanical Performance & Environment

Screw torque 53.1 in-lbs
 Temp.range -40℃~+85℃
 Weather standard IEC 60068 40 / 085/ 21
 ROHS compliant


Gas tube	Times P/N
90V	IP-G TD
230V	IP-G TD-23
350V	IP-G TD-35

De sc ri p tio n

Gas tube replacement kit

She e t
1/1

Me tric
inc h

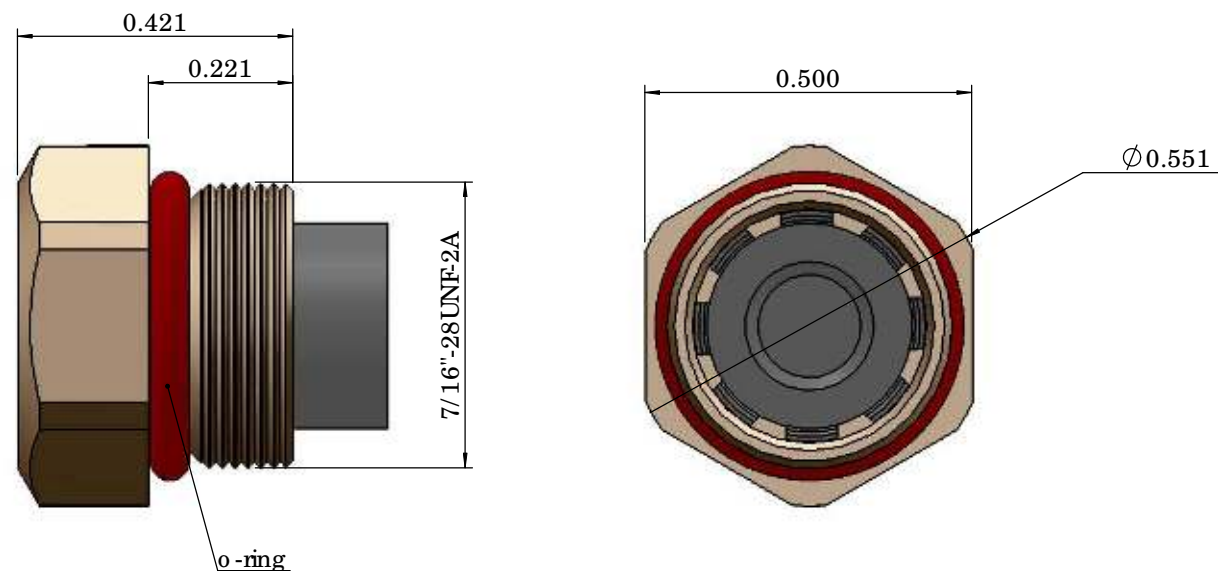

I、 Electric Performance

Gas tube 90V 、 230V 、 350V

II、 Material and plating :

Housing Brass / Spring copper Plating White Bronze2um / Ag5um
 O-ring Silicon rubber

III、 Mechanical Performance & Environment

Screw torque 53.1 in-lbs
 Temp.range -40℃~+85℃
 Weather standard IEC 60068 40 / 085/ 21
 ROHS compliant

Gas tube	Times P/N
90V	IP-GT
230V	IP-GT-23
350V	IP-GT-35

De s c r i p t i o n

Gas tube replacement kit

She e t
1/1

Me t r i c
i n c h

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Amphenol:](#)

[LP-GT](#) [LP-GT-23](#) [LP-GT-35](#) [LP-GTD](#) [LP-GTD-23](#) [LP-GTD-35](#)