


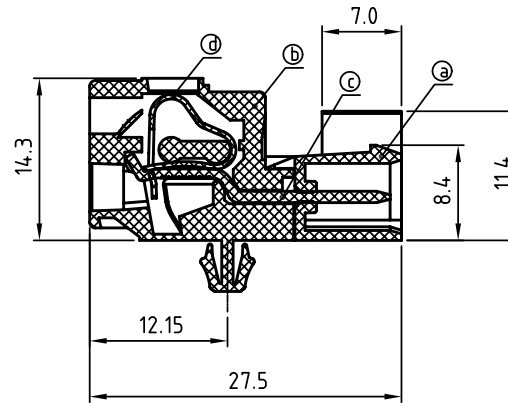
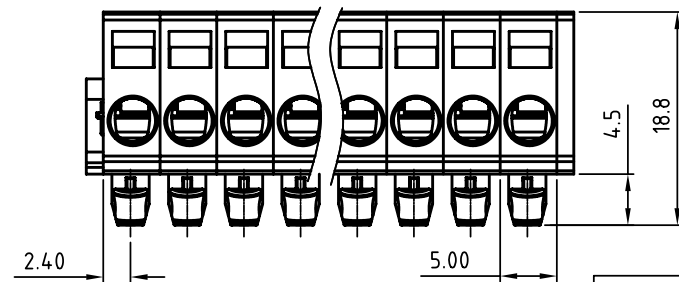
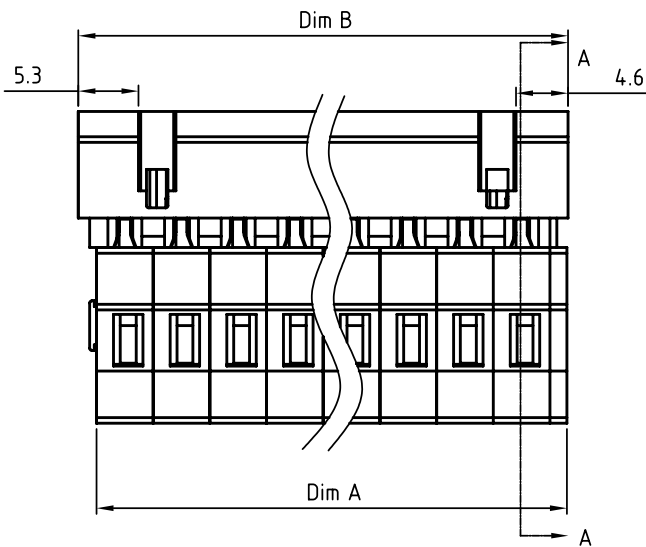
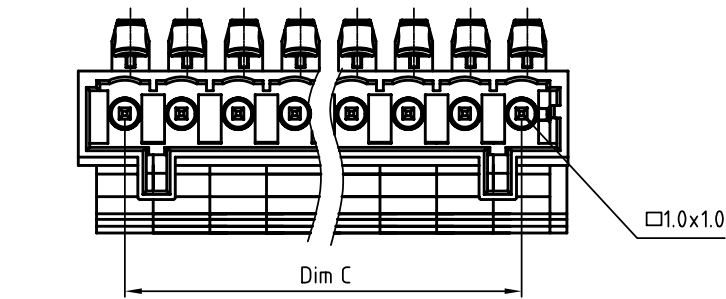
SIGN	DATE	DESCRIPTION	APPROVER
		<b>THIS IS CAD DRAWING, DO NOT REVISE MANUALLY!!!</b>	

Material:

- Item a :Terminal body Thermoplastic (UL94 V-0)
- Item b :Terminal body Thermoplastic (UL94 V-0)
- Item c :Male contact pin: Brass Tin plated
- Item d :Spring clamp: Stainless steel

Electrical

- Voltage rating: 300V
- Current rating: 8A
- Wire range:
- Solid wire(AWG): 12-28
- Stranded wire(AWG): 12-28
- Wire strip length: 8-9mm
- Withstanding Voltage: 1.6KV
- Operating temperature: -40°C to +105°C
- Safety Approval: 



SECTION A-A

NB xx 7 0 x 5 xxxx G

02 2 poles  
03 3 poles  
...  
24 24 poles

0 Black  
5 Green  
(RAL6018/T)  
6 Blue  
8 Grey  
(RAL7035/D)

RoHS  
Pb<40,000ppm

0000 Standard @ Logo  
000A Standard ANY Logo  
Any special item by  
customer request,  
please contact sales  
department.

 
N = Number of poles  
Dim A=Nx5.0+1.5  
Dim B=Nx5.0+3.2  
Dim C=(N-1)x5.0

	Dim A	Dim B	Dim C
2-6p	±0.20	±0.20	±0.20
7-12p	±0.25	±0.25	±0.25
13-18p	±0.30	±0.30	±0.30
19-24p	±0.40	±0.40	±0.40

**ANYTEK**

**CUSTOMER COPY**

ALL RIGHTS RESERVED. REPRODUCTION OR ISSUE TO THIRD PARTIES IN ANY FORM WHATSOEVER IS NOT PERMITTED WITHOUT WRITTEN AUTHORITY FROM THE PROPRIETOR. PROPERTY OF ANYTEK TECHNOLOGY CO., LTD

TITLE		NB 5.0mm series With hook holder with snap-in mounting feet					
PART NO.	NBxx70x5xxxxG			DWG NO.	8NB0008		
APPROVED	CHECKED	DESIGNED	DRAWN	CUST NO.			
		runner	runner			UNIT: mm	X. ±0.50
		2007.12.04	2007.12.04			SCALE: 2/1	X.X ±0.30
				SHEET: 01/01	REV.: B		X.XX ±0.10
							X° ±1°

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

## Amphenol:

<a href="#"><u>NB0270850000G</u></a>	<a href="#"><u>NB0370850000G</u></a>	<a href="#"><u>NB0470850000G</u></a>	<a href="#"><u>NB0570850000G</u></a>	<a href="#"><u>NB0670850000G</u></a>	<a href="#"><u>NB0770850000G</u></a>
<a href="#"><u>NB0870850000G</u></a>	<a href="#"><u>NB0970850000G</u></a>	<a href="#"><u>NB1070850000G</u></a>	<a href="#"><u>NB1170850000G</u></a>	<a href="#"><u>NB1270850000G</u></a>	<a href="#"><u>NB1370850000G</u></a>
<a href="#"><u>NB1470850000G</u></a>	<a href="#"><u>NB1570850000G</u></a>	<a href="#"><u>NB1670850000G</u></a>	<a href="#"><u>NB1770850000G</u></a>	<a href="#"><u>NB1870850000G</u></a>	<a href="#"><u>NB1970850000G</u></a>
<a href="#"><u>NB2070850000G</u></a>	<a href="#"><u>NB2170850000G</u></a>	<a href="#"><u>NB2270850000G</u></a>	<a href="#"><u>NB2370850000G</u></a>	<a href="#"><u>NB2470850000G</u></a>	