

LMR® Express Assemblies

Two weeks delivery to your door!



Benefits :


- Corrosion resistant connectors for long life
- IP67 sealed - able to withstand the elements
- Reliable and rugged weather seal boots
- Excellent broadband electrical specs cover a wide variety of applications

A new program to supply standard LMR assemblies to your door within two weeks of purchase.

These assemblies use our very latest connector designs along with our new WSB weather seal boots. Every one of these assemblies are 100% tested for VSWR and IL, protected with dust caps and individually packaged in labeled poly bags. All assemblies will meet a VSWR of 1.25:1 to 2.5 GHz and a 1.35:1 to 6 GHz, aside from the BNC interface which is limited to 2.5 GHz. The assemblies are labeled as factory made by Times along with a Smart Number and a serial number. The current two-week delivery program encompasses our most popular cables as well as our most popular connectors.

Contact your Times Sales Representative for instant pricing.

Smart Part Number Example:

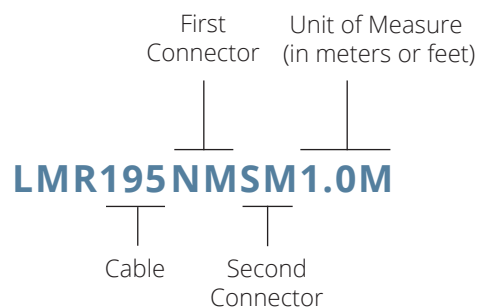

Cable

195	=	LMR-195
195DB	=	LMR-195-DB
195FR	=	LMR-195-FR
240	=	LMR-240
240DB	=	LMR-240-DB
240FR	=	LMR-240-FR
400	=	LMR-400
400DB	=	LMR-400-DB
400FR	=	LMR-400-FR

LMR-195 Connectors

NM	=	N Male
SM	=	SMA Male
BM	=	BNC Male
TM	=	TNC Male

LMR-240 Connectors

NM	=	N Male
SM	=	SMA Male
BM	=	BNC Male
TM	=	TNC Male
QM	=	QMA
NFB	=	N Male Bulkhead
NMR	=	N Male Right Angle
1.0/2.3	=	DIN

LMR-400 Connectors

NM	=	N Male
NF	=	N Female
BM	=	BNC Male
TM	=	TNC Male
SM	=	SMA
NFB	=	N Female Bulkhead
NMR	=	N Male Right Angle

Lead-time for all other cable-connector combinations to be determined at time of request

NOTE: Contact inside sales or your rep for quoting

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Amphenol:

[LDB240NMNM3.0F](#) [LDB400NMNM3.0F](#) [LFR240NMNM3.0F](#) [LFR400NMNM3.0F](#) [LMR195NMNM3.0F](#)
[LMR195NMSM3.0F](#) [LUF400NMNM3.0F](#) [LMR240NMNM3.0F](#) [LMR400NMNM3.0F](#) [LUF195NMNM3.0F](#)
[LUF195NMSM3.0F](#) [LUF240NMNM3.0F](#) [LUF400NFM3.0F](#)