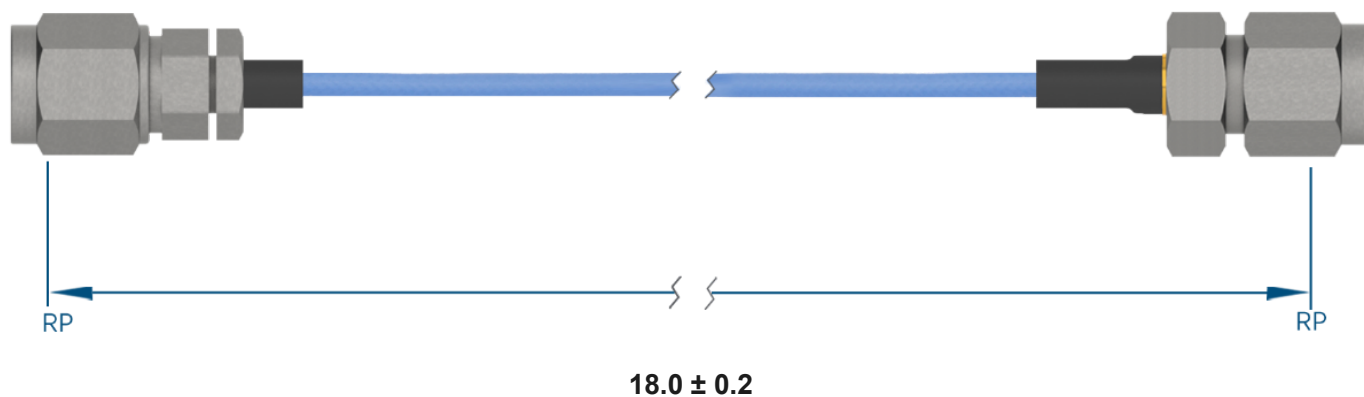


PRODUCT DATA DRAWING

**MATERIAL**

CONNECTORS: 1.85mm Straight Male (SF3311-60002)
2.92mm Straight Male (SF1511-60069)

CABLE: Ø.047 Flexible Coax

SHRINK TUBING: M23053/5

PERFORMANCE

IMPEDANCE: 50 Ohms

FREQ. RANGE: DC to 40 GHz

VSWR: 1.3:1 Max, DC to 18.0 GHz
1.5:1 Max, 18.0 + GHz

INSERTION LOSS: 4.65 dB Max

NOTES

1. See individual data drawings for connector specifications
2. Dimensions shown are in inches

**TITLE:**

1.85mm Straight Male to 2.92mm Straight Male 18"
Cable Assembly for Ø.047 Flexible Coax

DWG. NO.

MS185-047-MS292-180

DRAWN

2022-10-18 11:34:38

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Amphenol:](#)

[MS185-047-MS292-180](#)