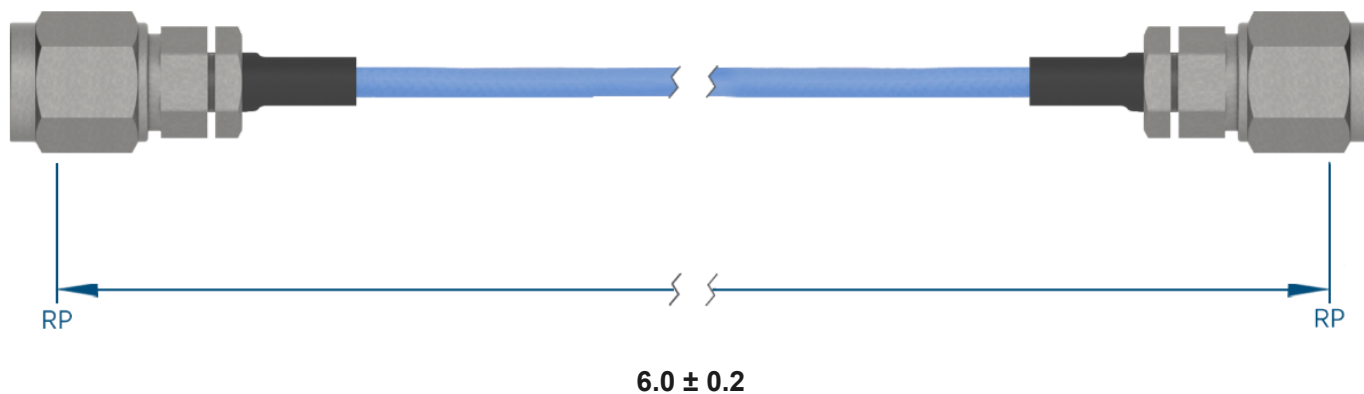


PRODUCT DATA DRAWING

**MATERIAL**

CONNECTORS: 1.85mm Straight Male (SF3311-60003)
2.4mm Straight Male (SF1611-60003)

CABLE: Ø.085 Flexible Coax

SHRINK TUBING: M23053/5

PERFORMANCE

IMPEDANCE: 50 Ohms

FREQ. RANGE: DC to 50 GHz

VSWR: 1.4:1 Max, DC to 18.0 GHz
1.6:1 Max, 18.0 + GHz

INSERTION LOSS: 1.47 dB Max

NOTES

1. See individual data drawings for connector specifications
2. Dimensions shown are in inches

**TITLE:**

1.85mm Straight Male to 2.4mm Straight Male 6" Cable
Assembly for Ø.085 Flexible Coax

DWG. NO.

MS185-085-MS24-060

DRAWN

2022-10-18 11:21:14

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Amphenol:](#)

[MS185-085-MS24-060](#)