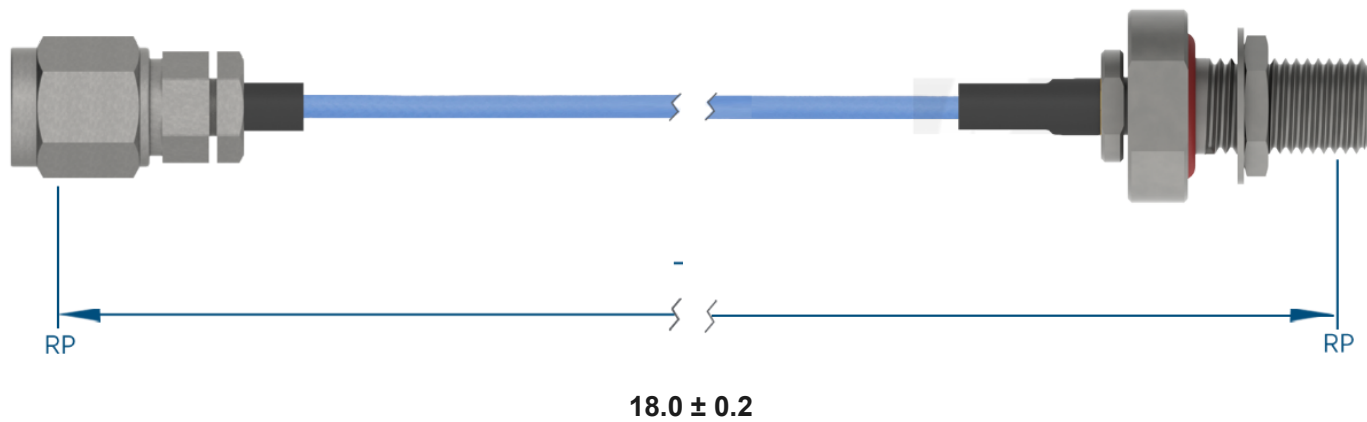


## PRODUCT DATA DRAWING

**MATERIAL**

CONNECTORS: 2.4mm Straight Male (SF1611-60001)  
SMA Bulkhead Female (2944-6001)

CABLE: Ø.047 Flexible Coax

SHRINK TUBING: M23053/5

**PERFORMANCE**

IMPEDANCE: 50 Ohms

FREQ. RANGE: DC to 18 GHz

VSWR: 1.3:1 Max, DC to 18.0 GHz  
1.5:1 Max, 18.0 + GHz

INSERTION LOSS: 3.22 dB Max

**NOTES**

1. See individual data drawings for connector specifications
2. Dimensions shown are in inches

**TITLE:**

2.4mm Straight Male to SMA Bulkhead Female 18"  
Cable Assembly for Ø.047 Flexible Coax

**DWG. NO.**

MS24-047-FBSMA-180

**DRAWN**

2022-10-18 11:11:38

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Amphenol:](#)

[MS24-047-FBSMA-180](#)