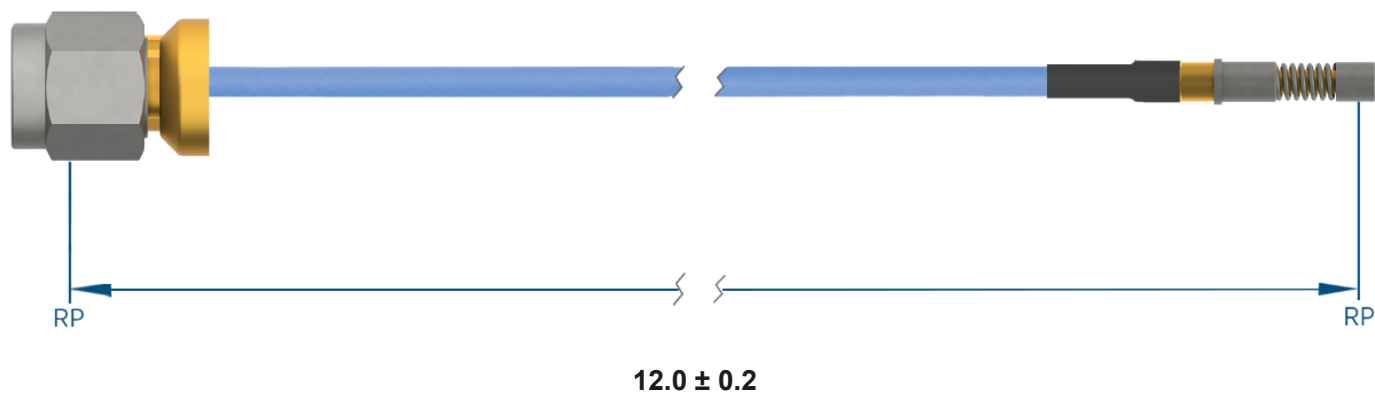


PRODUCT DATA DRAWING

**MATERIAL**

CONNECTORS: SMA Low Profile Male (2911-61000)
SMPM Size 12 Socket (SF3211-6004)

CABLE: Ø.085 Flexible Coax

SHRINK TUBING: M23053/5

PERFORMANCE

IMPEDANCE: 50 Ohms

FREQ. RANGE: DC to 18 GHz

VSWR: 1.3:1 Max, DC to 18.0 GHz
1.5:1 Max, 18.0 + GHz

INSERTION LOSS: 1.30 dB Max

NOTES

1. See individual data drawings for connector specifications
2. Dimensions shown are in inches

**TITLE:**

SMA Low Profile Male to SMPM Size 12 Socket 12"
Cable Assembly for Ø.085 Flexible Coax

DWG. NO.

MSLPSMA-085-S12DSMPM-120

DRAWN

2022-10-17 15:40:50

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Amphenol:](#)

[MSLPSMA-085-S12DSMPM-120](#)