


PRODUCT DATA DRAWING

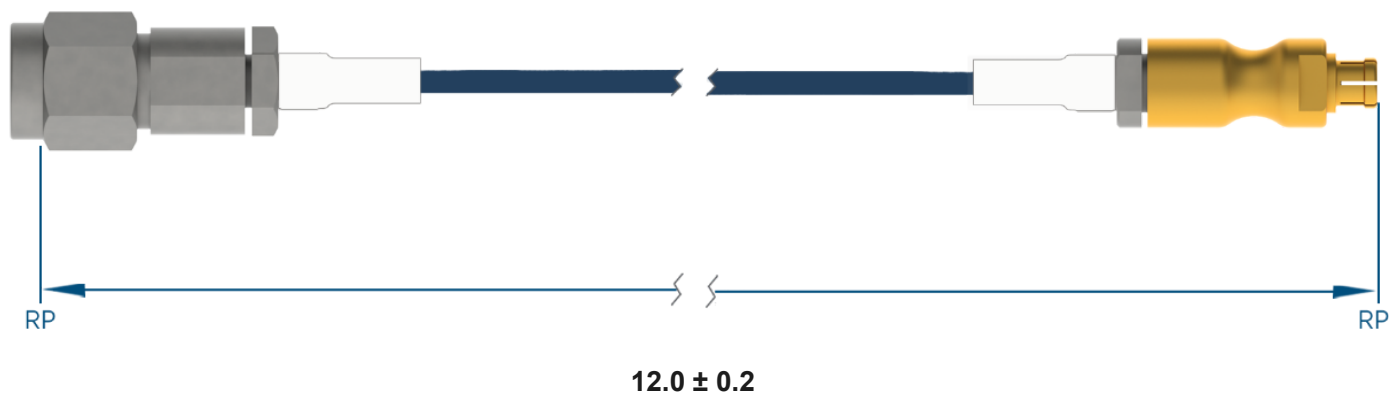

MATERIAL

CONNECTORS: SMA Straight Male ([SF2911-60966](#))
SMPM Straight Female ([3221-40128](#))

CABLE: Ø.047 SuperFlex Coax

SHRINK TUBING: M23053/5-103-0

PERFORMANCE

IMPEDANCE: 50 Ohms

FREQ. RANGE: DC to 18 GHz

VSWR: 1.3:1 Max, DC to 18.0 GHz
1.5:1 Max, 18.0 + GHz

INSERTION LOSS: 1.54 dB Max

NOTES

1. See individual data drawings for connector specifications
2. Dimensions shown are in inches



TITLE:

SMA Straight Male to SMPM Straight Female 12"
Cable Assembly for Ø.047 SuperFlex Coax

DWG. NO.

MSSMA-047SF-FSSMPM-120

DRAWN

2022-10-17 15:15:20

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Amphenol:](#)

[MSSMA-047SF-FSSMPM-120](#)