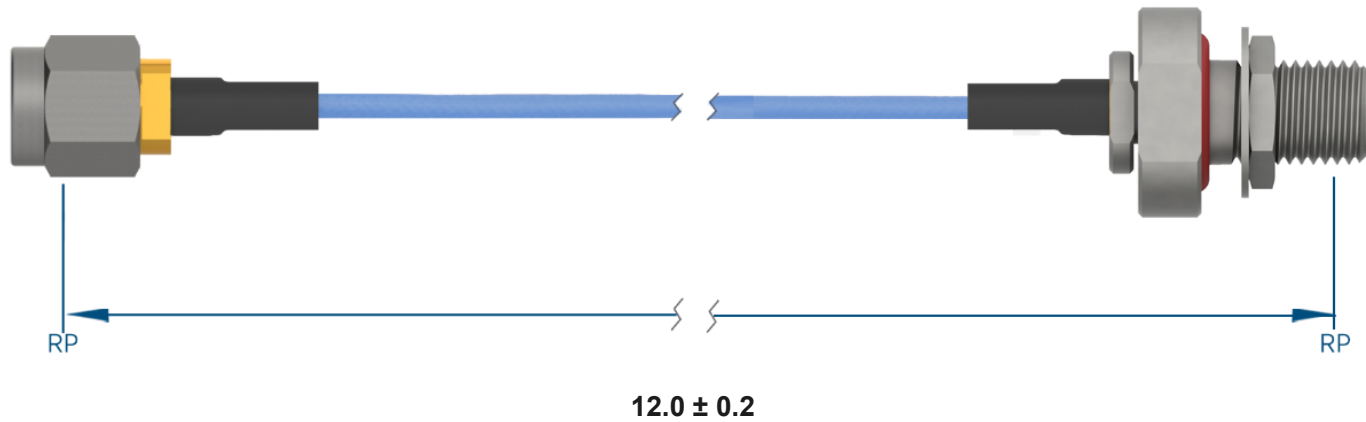


## PRODUCT DATA DRAWING

**MATERIAL**

CONNECTORS: SMA Straight Male (SF2911-60172)  
2.92mm Bulkhead Female (SF1521-60045)

CABLE: Ø.047 Flexible Coax

SHRINK TUBING: M23053/5

**PERFORMANCE**

IMPEDANCE: 50 Ohms

FREQ. RANGE: DC to 18 GHz

VSWR: 1.3:1 Max, DC to 18.0 GHz  
1.5:1 Max, 18.0 + GHz

INSERTION LOSS: 2.26 dB Max

**NOTES**

1. See individual data drawings for connector specifications
2. Dimensions shown are in inches

**TITLE:**

SMA Straight Male to 2.92mm Bulkhead Female 12"  
Cable Assembly for Ø.047 Flexible Coax

**DWG. NO.**

MSSMA-047-FB292-120

**DRAWN**

2022-10-17 15:37:28

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Amphenol:](#)

[MSSMA-047-FB292-120](#)