


PRODUCT DATA DRAWING

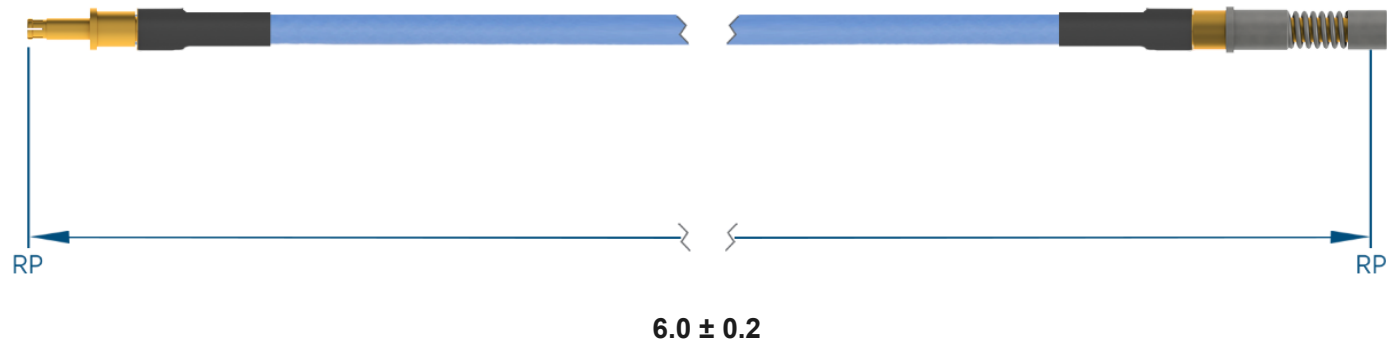

MATERIAL

CONNECTORS: SMPM Size 12 Pin (3221-4002)
SMPM Size 12 Socket (SF3211-6004)

CABLE: Ø.085 Flexible Coax

SHRINK TUBING: M23053/5

PERFORMANCE

IMPEDANCE: 50 Ohms

FREQ. RANGE: DC to 65 GHz

VSWR: 1.4:1 Max, DC to 18.0 GHz
1.6:1 Max, 18.0 + GHz

INSERTION LOSS: 1.78 dB Max

NOTES

1. See individual data drawings for connector specifications
2. Dimensions shown are in inches



TITLE:

SMPM Size 12 Pin to SMPM Size 12 Socket 6" Cable
Assembly for Ø.085 Flexible Coax

DWG. NO.

P12DSMPM-085-S12DSMPM-060

DRAWN

2022-10-17 14:23:24

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Amphenol:](#)

[P12DSMPM-085-S12DSMPM-060](#)