

# Amphenol

## Advanced Sensors

PRODUCT SPECIFICATION  RV-1866	Originated by: John R. Lukie, Jr. THM Ref. No. RV-1866	PAGE 1 of 1 DATE: 04/30/2015
CUSTOMER:  Catalog	CUSTOMER SPECIFICATION No. N/A	

### DESCRIPTION:

TURBIDITY SENSOR CONNECTOR MATE -  
WIRE TO BOARD CRIMP TERMINAL

### SPECIFICATION


Terminal Mate For:  
(use with RV-1865 housing)

Amphenol Advanced Sensors Turbidity Sensors; TSD-10, TST-10, TSW-10  
and Turbidity / Temperature Sensor

Material: Phosphor bronze, tin – plated  
Voltage Rating: AC/DC 250V  
Current Rating: AC/DC 3A  
Temperature Rating: -25°C to +85°C  
Wire Size: #22 to #28 AWG  
Application Housing: RV-1865

### OUTLINE DRAWING

Dimensions are in millimeters  
(not to scale)

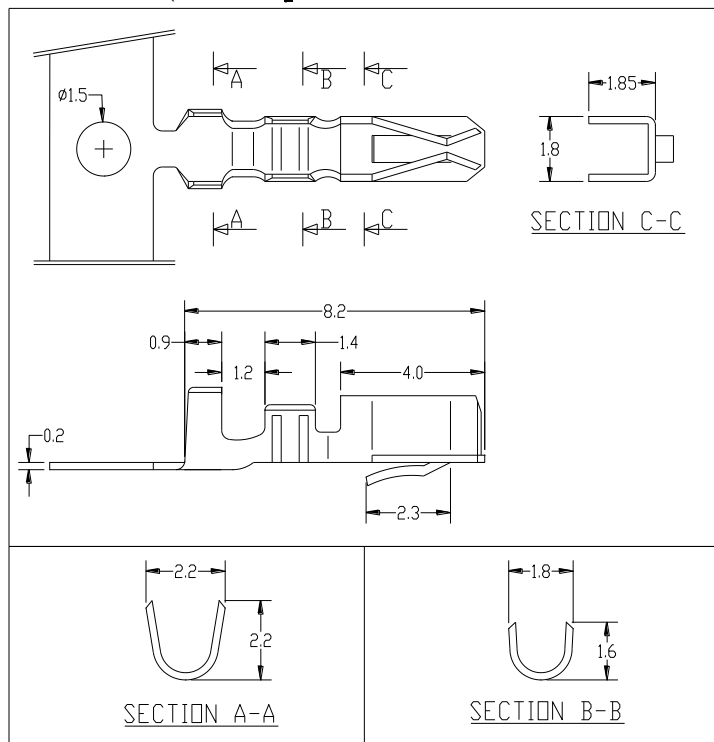

967 WINDFALL RD, ST MARYS, PA 15857 Ph (814) 834-9140 Fx (814) 781-7969

The information contained in this document is proprietary to Amphenol Advanced Sensors and shall not be disclosed in whole or in part, in any form or for any reason except as expressly stated in writing by Amphenol Advanced Sensors.

Form 1018 Rev 00

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Amphenol:](#)

[RV-1866](#)